

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0513820700

Status:


Active

Overview:

MicroClasp Wire-to-Board System

Description:

2.00mm Pitch MicroClasp Wire-to-Board Receptacle Housing, Positive Lock, Single Row, 7 Circuits, White

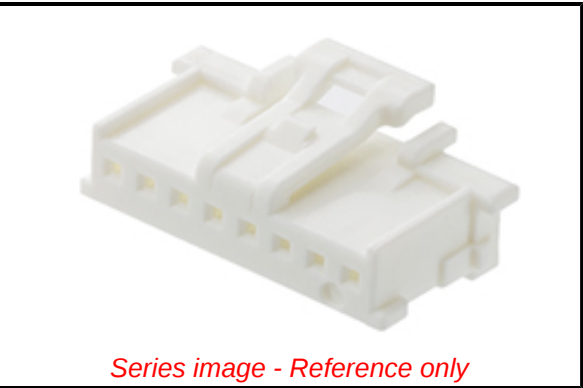

Documents:

3D Model

Drawing (PDF)

Product Specification PS-51382-004-001 (PDF)

Packaging Specification 513829200-200 (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	51382
Application	Signal, Wire-to-Board
Overview	MicroClasp Wire-to-Board System
Product Name	MicroClasp
UPC	800756632292
Physical	
Circuits (maximum)	7
Color - Resin	White
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	372.100/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Stackable	No
Temperature Range - Operating	-25° to +85°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	513829200-200
Product Specification	PS-51382-004-001
Sales Drawing	SD-51382-002

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/88/2018 (15	
January 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

51382 Series

Mates With

55932 Vertical Header, 55935 Right Angle Header

Use With

56134 Terminal

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION