

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0527450997

Status:


Active

Overview:

FFC-FPC (SMT)

Description:

Easy-On FFC/FPC Connector, 0.50mm Pitch, Slider Series, Right-Angle, Top Contact, 2.00mm Height, 9 Circuits, Gold Plating

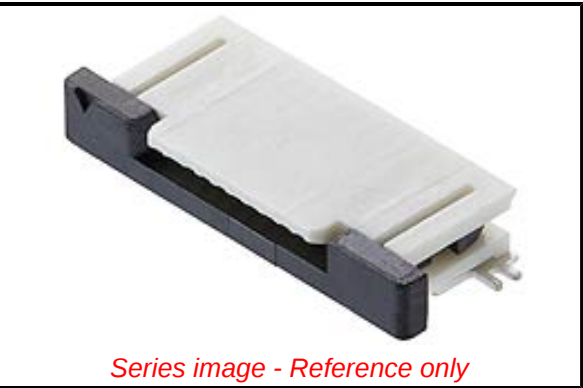

Documents:	
3D Model	Application Specification AS-52745-001-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-52745-002-001 (PDF)
Product Specification PS-52745-051-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	FFC/FPC Connectors
Series	52745
Datasheet Order No	987651-8732, 987651-8736_ZH, 987651-8768_DE, 987651-8772_JA, 987651-8776_KO, 987651-8780_ES
Overview	FFC-FPC (SMT)
Product Guide Order No	987651-8061
Product Name	Easy-On
Series Name	Slider
UPC	822348250479
Physical	
Actuator Type	Slider
Circuits (Loaded)	9
Color - Resin	Black, White
Contact Position	Top
Durability (mating cycles max)	20
Flammability	94V-0
Mated Height	2.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	149.126/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +85°C
Wire/Cable Type	FFC/FPC
Electrical	
Current - Maximum per Contact	0.5A
Voltage - Maximum	50V
Material Info	
Reference - Drawing Numbers	
Application Specification	AS-52745-001-001
Packaging Specification	SPK-52745-002-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per -ED/88/2018 (15 January 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

52745 Series

This document was generated on 03/20/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION