

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191310042](#)  
**Status:** **Active**  
**Overview:** Solderless Terminals  
**Description:** InsulKrimp Block Spade Tongue Terminal for 18 to 22 AWG Wire, Stud Size 6 (M3.5), Length 6.35mm

**Documents:**

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)  
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-19902-011-001 \(PDF\)](#)

**Agency Certification**

CSA LR18689  
 UL E32244

**General**

Product Family Ring and Spade Terminals  
 Series [19131](#)  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 Overview [Solderless Terminals](#)  
 Product Name InsulKrimp  
 Type Spade Block  
 UPC 800753101654

**Physical**


Barrel Type Closed  
 Color - Resin Natural  
 Flammability 94V-0  
 Insulation PVC  
 Material - Plating Mating Tin  
 Net Weight 0.660/g  
 Packaging Type Bag  
 Plating min - Mating 2.540µm  
 Plating min - Termination 2.540µm  
 Stud Size 5-6 (M3-3.5)  
 Termination Interface: Style Crimp or Compression  
 Wire Insulation Diameter 3.70mm max.  
 Wire Size AWG 18, 20, 22  
 Wire Size mm<sup>2</sup> 0.35-0.80

**Material Info**

Engineering Number AA-2118-06X

**Reference - Drawing Numbers**

Product Specification PS-19902-009-001, PS-19902-011-001, PS-19902-013-001  
 Sales Drawing AACD20302

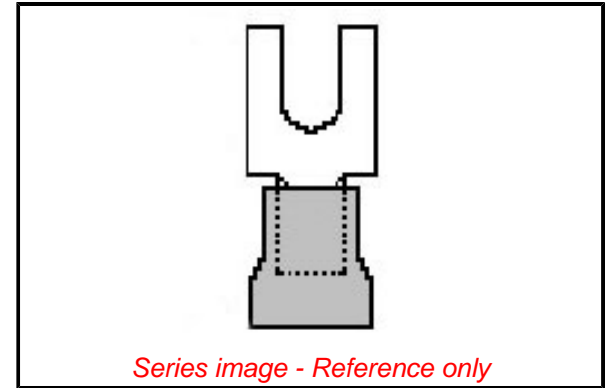

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/01/2018 (15  
 January 2018)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[19131 Series](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

Description	Product #
PremiumGrade Hand Crimp Tool	<a href="#">640010100</a>
Hand Crimp Tool	<a href="#">640010300</a>
Crimp Head for the AT-200 Pneumatic Hand Tool	<a href="#">640050100</a>
Crimp Head for the AT-200 Pneumatic Hand Tool	<a href="#">640050300</a>