

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191390018

Status:


Active

Overview:

Solderless Terminals

Description:

Avikrimp Block Spade Terminal for 18-22 AWG Wire, Stud Size 6 (M3.5), Width 6.22mm

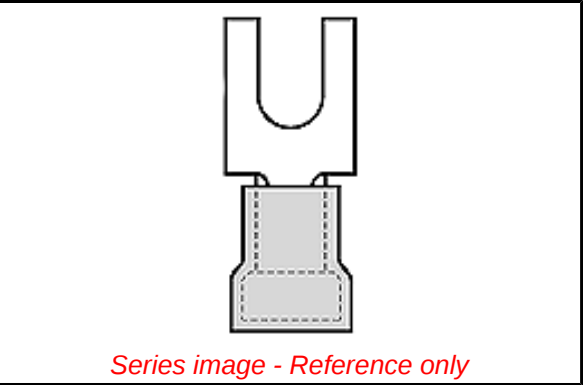

Documents:	
Drawing (PDF)	Product Specification PS-19902-013-001 (PDF)
Product Specification PS-19902-011-001 (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19139
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	Avikrimp
Type	Spade Block
UPC	800753102620
Physical	
Barrel Type	Closed
Flammability	94V-2
Insulation	Nylon (PA)
Material - Plating Mating	Tin
Net Weight	0.758/g
Packaging Type	Bag
Stud Size	6 (M3.5)
Wire Insulation Diameter	3.56mm
Wire Size AWG	18, 20, 22
Wire Size mm²	0.25-1.50
Electrical	
Voltage - Maximum	600V
Material Info	
Engineering Number	AA-838-06
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19139-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/88/2018 (15	
January 2019)	
Halogen-Free	
Status	
Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19139 Series

Application Tooling FAQ	
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.	
Global	
Description	Product #
PremiumGrade Hand	640010100
Crimp Tool	
Crimp Head for the	640050100
AT-200 Pneumatic	
Hand Tool	

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION