


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0039012186](#)
Status: **Active**
Overview: [Mini-Fit Jr. Power Connectors](#)
Description: Mini-Fit Jr. Plug Housing, Dual Row, 18 Circuits, UL 94V-0, with Panel Mounting Ears, Natural

Documents:

| | |
|--|---|
| 3D Model | Application Specification AS-5557-001-001 (PDF) |
| Drawing (PDF) | Packaging Specification PK-5559-001-001 (PDF) |
| Product Specification PS-45750-001-001 (PDF) | RoHS Certificate of Compliance (PDF) |
| Product Specification PS-5556-001-001 (PDF) | |

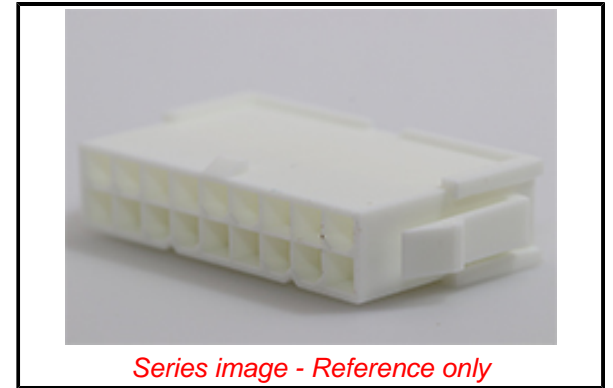

Series image - Reference only

Agency Certification

| | |
|-----|---------|
| CSA | LR19980 |
| UL | E29179 |

General

| | |
|----------------|--|
| Product Family | Crimp Housings |
| Series | 5559 |
| Application | Power, Wire-to-Board, Wire-to-Wire |
| Comments | Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information. |
| Comments | Current = 13A max. per circuit when header is mated to a receptacle loaded with 45750 series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information. |

Overview

| | |
|--------------|---|
| Product Name | Mini-Fit Jr. Power Connectors |
| UPC | Mini-Fit Jr. 800754441568 |

Physical

| | |
|-------------------------------|----------------|
| Breakaway | No |
| Circuits (maximum) | 18 |
| Color - Resin | Natural |
| Flammability | 94V-0 |
| Gender | Plug |
| Glow-Wire Capable | No |
| Material - Resin | Nylon |
| Net Weight | 5.420/g |
| Number of Rows | 2 |
| Packaging Type | Bag |
| Panel Mount | Yes |
| Pitch - Mating Interface | 4.20mm |
| Pitch - Termination Interface | 4.20mm |
| Polarized to Mating Part | Yes |
| Stackable | No |
| Temperature Range - Operating | -40° to +105°C |

Electrical

| | |
|-------------------------------|-------|
| Current - Maximum per Contact | 13.0A |
|-------------------------------|-------|

Solder Process Data

| | |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[5559](#) Series

Mates With

Dual Row Receptacle Housing [5557](#)

Use With

[5558](#) , [30490](#) Male Terminal, [46012](#) Mini-Fit Plus Crimp Terminal

Material Info

Engineering Number

5559-18P-210

Reference - Drawing Numbers

Application Specification

AS-5557-001-001

Packaging Specification

PK-5559-001-001

Product Specification

PS-45750-001-001, PS-5556-001-001

Sales Drawing

SD-5559-NP-000

This document was generated on 03/13/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION