

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0423751863](#)
Status: **Active**
Description: KK 100 Hdr Assy Bkwy 10 Ckt Tin

Documents:

[3D Model](#) [Packaging Specification PK-40873-0041-001 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-10-07-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family PCB Headers
 Series [42375](#)
 Application Tooling Part Link 11-20-1230
 Product Name KK 254
 UPC 800753813328

Physical

Flammability 94V-0
 Net Weight 0.868/g

Electrical

Voltage - Maximum 500V


Solder Process Data

Duration at Max. Process Temperature (seconds) 005
 Lead-freeProcess Capability WAVE
 Max. Cycles at Max. Process Temperature 001
 Process Temperature max. C 235

Material Info

Reference - Drawing Numbers

Packaging Specification PK-40873-0041-001
 Product Specification PS-10-07-001
 Sales Drawing SD-42375-001

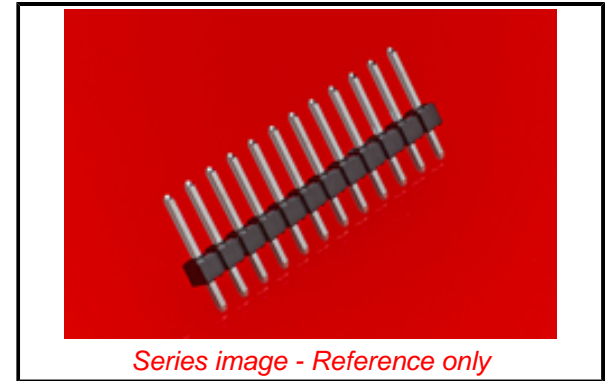

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/88/2018 (15
 January 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[42375 Series](#)