

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190990016**
Status: **Active**
Overview: Solderless Terminals
Description: InsulKrimp Snap Spade for 18-22 AWG Wire, Stud Size 10 (M5), Mylar Tape Carrier, Red

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-015-001 \(PDF\)](#)
[Product Specification PS-19902-009-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Ring and Spade Terminals
 Series 19099
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview Solderless Terminals
 Product Name InsulKrimp
 Type Spade Snap
 UPC 800753088900

Physical


Barrel Type Closed
 Color - Resin Red
 Flammability 94V-0
 Insulation PVC
 Material - Plating Mating Tin
 Net Weight 0.701/g
 Packaging Type Adhesive Tape on Reel
 Stud Size 10 (M5)
 Wire Insulation Diameter 4.40mm max.
 Wire Size AWG 18, 20, 22
 Wire Size mm² 0.25-1.50

Material Info

Engineering Number AA-2715-10XT

Reference - Drawing Numbers

Product Specification PS-19902-009-001, PS-19902-011-001, PS-19902-015-001
 Sales Drawing AACD20503

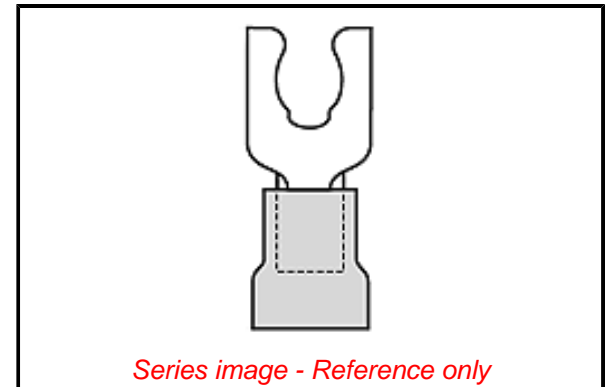

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/01/2018 (15
 January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19099 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description

Product #

ATP Crimp Dies for the Tape Crimp Module and ATP-101 & 301 Press	<u>192880023</u>
Mini-Mac Applicator	<u>638851300</u>