


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5014610691](#)
Status: **Active**
Overview: FFC-FPC (SMT)
Description: 0.50mm Pitch Easy-On Back Flip FPC Connector, Right-Angle, Surface Mount, Bottom Contact Style, 0.80mm Mated Height, 6 Circuits

Documents:

3D Model	Application Specification AS-501461-003-001 (PDF)
Drawing (PDF)	Packaging Specification SPK-501461-001-001 (PDF)
Product Specification PS-501461-005-001 (PDF)	RoHS Certificate of Compliance (PDF)

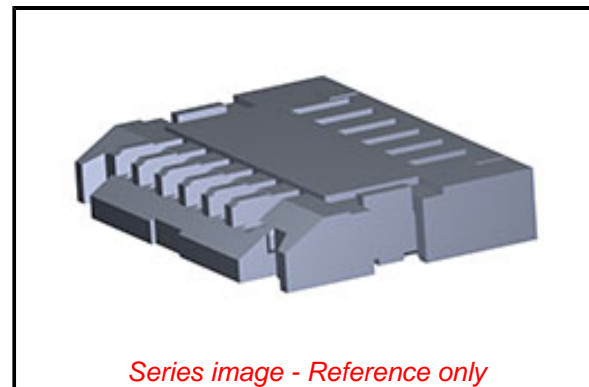

General

Product Family	FFC/FPC Connectors
Series	501461
Overview	FFC-FPC (SMT)
Product Name	Easy-On
UPC	887191456218

Physical

Actuator Type	Flip
Circuits (Loaded)	6
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	0.80mm
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	20.547/mg
Number of Rows	1
Orientation	Right Angle
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Packaging Type	Embossed Tape on Reel
Pitch - Mating Interface	0.50mm
Polarized to PCB	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire/Cable Type	FPC only

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Application Specification	AS-501461-003-001
Packaging Specification	SPK-501461-001-001
Product Specification	PS-501461-005-001
Sales Drawing	5014610001-000, 5014611004-000

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/88/2018 (15
January 2019)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[501461 Series](#)