

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0391002502](#)
Status: **Active**
Overview: Eurostyle Two-Screw Barrier Strips
Description: 15.00mm Pitch Beau Eurostyle Two-Screw Terminal Strips, 2 Circuits

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Terminal Blocks
Series	39100
Application	Wire-to-Wire
Component Type	One Piece
Overview	Eurostyle Two-Screw Barrier Strips
Product Name	Eurostyle Two Screw
Type	Barrier Strip
UPC	78172545258

Physical

Circuits (Loaded)	2
Circuits (maximum)	2
Color - Resin	White
Entry Angle	Horizontal
Lock to Mating Part	None
Material - Metal	Stainless Steel
Material - Resin	Nylon
Net Weight	18.400/g
Number of Rows	2
Orientation	Vertical
PCB Retention	Yes
Panel Mount	Mounting Holes Between Circuit
Pitch - Mating Interface	15.00mm
Pitch - Termination Interface	15.00mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40° to +105°C
Wire Size AWG	10, 12, 14, 6, 8

Electrical


Current - Maximum per Contact	63.0A
Voltage - Maximum	600V

Material Info

Engineering Number	M800-04-02-5-M1
--------------------	-----------------

Reference - Drawing Numbers

Sales Drawing	SD-39100-017
---------------	--------------

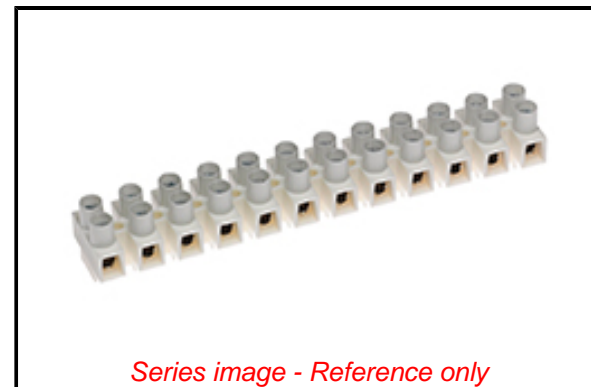

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - ED/88/2018 (15 January 2019)

Lead

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

[39100 Series](#)