

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0191930097](#)  
**Status:** **Active**  
**Overview:** [VersaKrimp Terminals and Splices](#)  
**Description:** VersaKrimp Ring Tongue Terminal for 10-12 AWG Wire

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Product Specification PS-19902-013-001 (PDF)</a>
<a href="#">Product Specification PS-19902-011-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**Agency Certification**

CSA	LR18689
UL	E32244

**General**

Product Family	Ring and Spade Terminals
Series	<a href="#">19193</a>
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	<a href="#">VersaKrimp Terminals and Splices</a>
Product Name	VersaKrimp
Type	Ring
UPC	800755049312

**Physical**


Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Net Weight	3.116/g
Packaging Type	Bag
Stud Size	3/8" (M9)
Wire Size AWG	10, 12
Wire Size mm <sup>2</sup>	3.30-5.00

**Material Info**

Engineering Number	C-301-38
--------------------	----------

**Reference - Drawing Numbers**

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19193-022

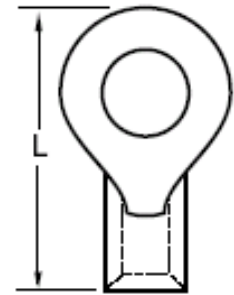

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Not Relevant**

For more information, please visit [Contact US](#)

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

**Search Parts in this Series**

[19193 Series](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

PremiumGrade Hand Crimp Tool	<a href="#">640030100</a>
Crimp Head for the AT-200 Pneumatic Hand Tool	<a href="#">640070100</a>