

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1720631312](#)  
**Status:** **Active**  
**Overview:** [Mega-Fit Power Connectors](#)  
**Description:** Mega-Fit Female Crimp Terminal, 12 AWG 30µ" Gold (Au) Plating, Reel

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Application Specification AS-76823-100-001 (PDF)</a>
<a href="#">Product Specification PS-76823-100-001 (PDF)</a>	<a href="#">Packaging Specification PK-76823-001 (PDF)</a>
<a href="#">Product Specification TS-76823-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification TS-76823-100-001 (PDF)</a>	<a href="#">Product Literature (PDF)</a>

**General**

Product Family	Crimp Terminals
Series	<a href="#">172063</a>
Application	Power, Wire-to-Board
Crimp Quality Equipment	Yes
Overview	<a href="#">Mega-Fit Power Connectors</a>
Product Literature Order No	987650-5401
Product Name	Mega-Fit
UPC	887191559056

**Physical**

Gender	Female
Material - Metal	Copper Alloy
Material - Plating Mating	Gold
Material - Plating Termination	Matte Tin
Net Weight	0.348/g
Packaging Type	Reel
Plating min - Mating	0.762µm
Plating min - Termination	2.540µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	4.35mm (0.171")
Wire Size AWG	12
Wire Size mm²	N/A

**Electrical**

Current - Maximum per Contact	23.0A
Voltage - Maximum	600V


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Application Specification	AS-76823-100-001
Packaging Specification	PK-76823-001
Product Specification	PS-76823-100-001, TS-76823-001-001, TS-76823-100-001
Sales Drawing	SD-76823-0100-001

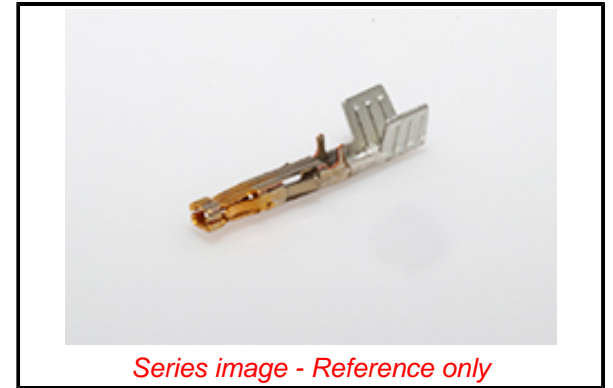

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[172063](#) Series

**Use With**

Mega-Fit Receptacle Housing [171692](#) ,  
[170001](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Extractor Tool for [638240800](#)

Mega-Fit Series

Terminals

Hand Crimp Tool [638257100](#)

for Mega-Fit Crimp

Terminals, AWG

Wires

Hand Crimp Tool [638274900](#)

for Mega-Fit Crimp

Terminals, mm<sup>2</sup>  
Wires  
FineAdjust Applicator [639023400](#)  
for Mega-Fit Female  
Terminals

This document was generated on 04/18/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**