

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190710153

Status:

Active

Overview:

Solderless Terminals

Description:

InsulKrimp Ring Tongue Terminal for 8 AWG Wire

Documents:

Drawing (PDF)


Product Specification PS-19902-009-001 (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19071
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	Solderless Terminals
Product Name	InsulKrimp
Type	Ring
UPC	800753071230
Physical	
Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-0
Insulation	PVC
Material - Plating Mating	Tin
Net Weight	3.611/g
Packaging Type	Bag
Stud Size	5/16" (M8)
Wire Insulation Diameter	6.70mm max.
Wire Size AWG	8
Material Info	
Engineering Number	D-651-56X
Reference - Drawing Numbers	
Product Specification	PS-19902-009-001, PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19071-002

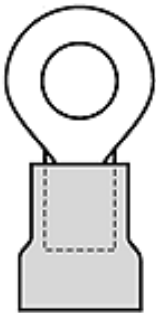

Series image - Reference only

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/88/2018 (15	
January 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19071 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Manual Putt Pump	192860117
Hydraulic System,	
Die set required	
Die Set (large) for	192890001
the HHLS Hydraulic	
Crimper	
Hydraulic Dieless	638161700
Crimping Tool	
Hand Crimp Tool	640013900
Crimp Tool Kit for 8	640017670
AWG Insulated Ring	
Terminals	

This document was generated on 03/28/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION