

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0191410056
Status: Active
Overview: Solderless Terminals
Description: Krimptite Spade Tongue Terminal for 14-16 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
CSA LR18689
UL E32244

General
Product Family Ring and Spade Terminals
Series 19141
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview Solderless Terminals
Product Name Krimptite
Type Spade
UPC 800755086508

Physical
Barrel Type Closed
Insulation None
Material - Plating Mating Tin
Net Weight 0.558/g
Packaging Type Bag
Plating min - Mating 4.064µm
Plating min - Termination 4.064µm
Stud Size 5-6 (M3-3.5)
Wire Size AWG 14, 16
Wire Size mm² 1.30-2.00

Material Info
Engineering Number BB-124-06

Reference - Drawing Numbers
Product Specification PS-19902-011-001, PS-19902-013-001
Sales Drawing BBCD10302, SD-19141-001

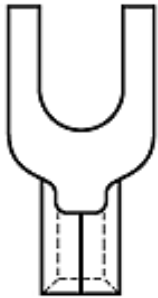

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Not Contained Per
-ED/88/2018 (15
January 2019)
Halogen-Free
Status
Low-Halogen
For more information, please visit [Contact US](#)

China ROHS Green Image
ELV Not Relevant
RoHS Phthalates Not Contained

Search Parts in this Series
19141 Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
PremiumGrade Hand	640030100
Crimp Tool	
Crimp Head for the	640070100
AT-200 Pneumatic	
Hand Tool	