

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0191930329

Status:

Active

Overview:

VersaKrimp Terminals and Splices

Description:

VersaKrimp Ring Tongue Terminal for 1/0 AWG Wire

Documents:


Drawing (PDF)

Product Specification PS-19902-011-001 (PDF)

Product Specification PS-19902-013-001 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR18689
UL	E32244
General	
Product Family	Ring and Spade Terminals
Series	19193
Crimp Quality Equipment	Yes
Mil-Spec	N/A
Overview	VersaKrimp Terminals and Splices
Product Name	VersaKrimp
Type	Ring
UPC	800755051988
Physical	
Barrel Type	Closed - Brazed
Insulation	None
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	20.860/g
Packaging Type	Bag
Plating min - Mating	2.540µm
Plating min - Termination	2.540µm
Stud Size	7/16" (M11)
Termination Interface: Style	Crimp or Compression
Wire Size AWG	1
Material Info	
Engineering Number	H-380-76
Reference - Drawing Numbers	
Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19193-008

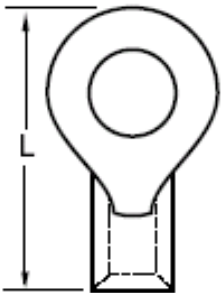

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

Green Image

REACH SVHC

Not Contained Per

January 2019)

Not Contained

Halogen-Free

Not Contained

Status

Not Contained

Low-Halogen

Not Contained

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

19193 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Manual Putt Pump Hydraulic System, Die set required	192860117
Die Set (large) for the HHLS Hydraulic Crimper	192900011
Hydraulic Dieless Crimping Tool	638161700
Square "Din" Style Die Set for BCL and VersaKrimp Un-insulated Ring Tongue Terminals	640038070

This document was generated on 04/15/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION