


LOKJAC Category 6 patch panel (SF24LJ)

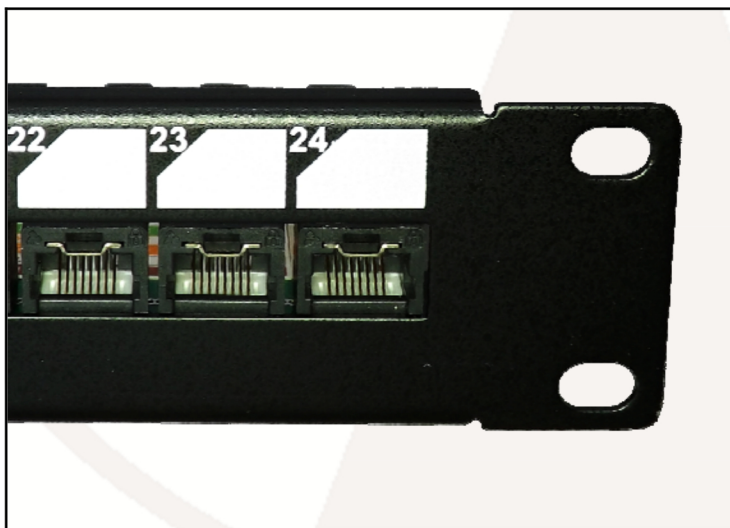

LOKJAC Category 6 patch panel (SF24LJ)

Our locking Category 6 patch panel offers a solution for almost any Category 6 locking requirement. The locking mechanism ensures safety and security, but the locking bars also provide control by preventing unauthorised access to unused ports.

Features

- High performance data throughput, meets Category 6 data transfer rates at permanent link level
- Compliant with IEC60512-99-001 – suitable for use with IEEE 802.3at (PoE+) applications
- Locked securely into place with LOKJAC key, with easy to use lock and release mechanism
- Locking bar blocks unauthorized access to unused ports
- Can be terminated with either 110 or LSA+ type tools
- Mounts to any standard 19-inch rack, cabinet or wall bracket
- Clear numbering on the front provides a quick, easy way to identify cable run
- High quality metal rear cable management
- Robust and high quality metal construction
- Each panel supplied with key, caged nut set and cable ties

Specifications

- Weight: 1.08kg
- Dimensions: 482 x 115.4 x 44mm
- Colour: Black
- Material:
 - Panel: Cold rolled steel (SPCC)
 - Jack: 8P8C 50µ"/1.27µm gold plated
 - PCB: FR-4/ UL-94V0
 - IDC Body: Fireproof ABS UL-94V0
 - IDC Pin: Bronze & Tinned
 - Lock Bar: Cold rolled steel (SPCC)
 - Key: Cold rolled steel (SPCC) and PVC moulding

Packaging: Packed in individual white box

EAN: 5055386507389

Commodity Code: 85177090