


Multiconductor Unshielded Cable



Specifications

Wire Size	: 18 AWG
No. of Conductor	: 2 Core
Conductor Material	: Stranded Bare Copper
Conductor Construction	: 16/0.254BS±0.008 (No./mm)
Conductor Stranded Diameter	: 1.17mm
Insulation Material	: CL2 105°C 32 PVC
Insulation Nom. Thickness	: 0.42mm (Ref.)
Insulation Diameter	: 2mm ±0.1mm
Insulation Colour	: Red and Black
Filler Material	: PET
Jacket Material	: CL2 105°C 55P PVC
Jacket Min. Thickness	: 0.46mm
Jacket Nom. Thickness	: 0.57mm (Ref.)
Jacket O.D	: 5.2mm ±0.2mm
Colour	: White

Diagram

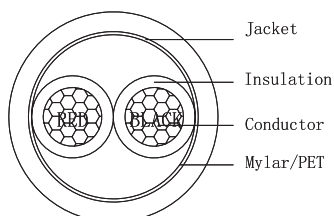

Part Number Table

Description	Part Number
Multiconductor Unshielded Cable, 2 Conductor, 18 AWG	24-15500