



# Einhell

# CLASSIC

Petrol Lawn Mower

**GC-PM 40 S**

**Item No.: 3404820**

Ident No.: 11018

Bar Code: 4006825638363



The Einhell GC-PM 40 S petrol lawn mower is a powerful lawn mower recommended for lawns up to 1,000 m<sup>2</sup> in size. You can engage and disengage power to the rear wheels. You decide whether and when you need additional assistance. The petrol lawn mower from Einhell has a central 7-level cutting height adjustment facility for settings of 25 to 60 millimeters. The ergonomic folding long handle makes it more comfortable to work with and also makes it easier to stow away. The large grass catch basket has a fill level indicator and two handles for easy emptying, and the attractive and sturdy plastic housing is very light in weight and offers impressive maneuverability.

## Features & Benefits

- 1 cylinder Einhell 4-stroke engine (OHV)
- Disengageable rear-wheel drive
- Central cutting height adjustment, 7 levels
- Elegant, sturdy plastic housing for excellent maneuverability
- Low weight for good maneuverability
- Catch basket with filling level indicator and 2 emptying handles
- Ergonomic folding long handle
- Recommended for lawn areas up to 1,000 m<sup>2</sup>

## Technical Data

- Engine	four-stroke, air cooled
- Engine displacement	99 cm <sup>3</sup>
- Power	1.2 kW
- Working speed	2900 min <sup>-1</sup>
- Capacity of fuel tank	1 L
- Cutting width	40 cm
- Cutting height adjustment	7 settings   25-75 mm   central
- Capacity of catch bag	45 L
- Wheel diameter front	178 mm
- Wheel diameter rear	203 mm

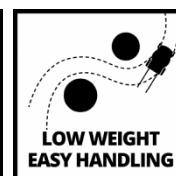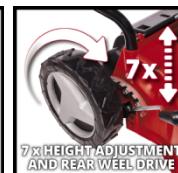

## Logistic Data

- Product weight	21.7 kg
- Gross weight single packaging	24.8 kg
- Dimensions single packaging	705 x 540 x 420 mm
- Pieces per export carton	1 Pieces
- Dimensions export carton	700 x 530 x 405 mm
- Container quantity (20"/40"/40"HC)	175   365   438

## Available as special accessories

Ersatzmesser GC-PM 40  
Lawn Mower Accessory  
Item No.: 3405850  
Bar Code: 4006825638806  
Einhell Accessory

