


## KAC1H48

operating head 45 x 45 mm - black color - black handle - 2 - 0 - 1

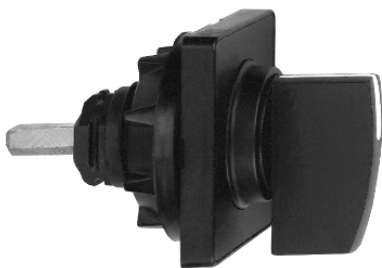

### Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KAC
Product compatibility	Front mounting bodies 12 and 20 A by Ø 22 mm hole
Cam switch head type	With front plate 45 x 45 mm
Type of operator	Black handle, length = 35 mm
Rotary handle padlocking	Without
Presentation of legend	With mat black legend, 2 - 0 - 1
Switching angle	45 °

### Complementary

Mechanical durability	1000000 cycles
CAD overall width	45 mm
CAD overall height	45 mm
CAD overall depth	77 mm
Length	35 mm
Product weight	0.012 kg

### Environment


protective treatment	TC
ambient air temperature for operation	-25...55 °C
ambient air temperature for storage	-40...70 °C
shock resistance	30 gn conforming to IEC 68-2-27
vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP65 conforming to IEC 529 IP65 conforming to NF C 20-010

### Contractual warranty

Warranty period	18 months
-----------------	-----------


### Operating Head

For Ø 22 mm/0.87 in. Hole, Front Mounting Body

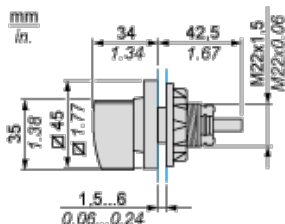

### Operating Head

Panel Cut-out

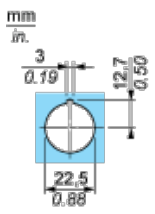

## Marking

