

KAXZ1C12  
operating head with bezel Ø 28.5 mm, metal - black  
long handle



Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KAX
Product compatibility	Front mounting bodies 12 and 20 A by Ø 22 mm hole
Cam switch head type	With bezel Ø 28.5 mm, metal
Type of operator	Black long handle
Rotary handle padlocking	Without
Presentation of legend	With mat black legend

Complementary

Mechanical durability	1000000 cycles
CAD overall width	29 mm
CAD overall height	34 mm
CAD overall depth	25 mm
Product weight	0.04 kg

Environment


protective treatment	TC
ambient air temperature for operation	-25...55 °C
ambient air temperature for storage	-40...70 °C
shock resistance	30 gn conforming to IEC 68-2-27
vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP65 conforming to IEC 529 IP65 conforming to NF C 20-010

Contractual warranty

Warranty period	18 months
-----------------	-----------

Operating Head

For Ø 22 mm/0.87 in. Hole, Front Mounting Body

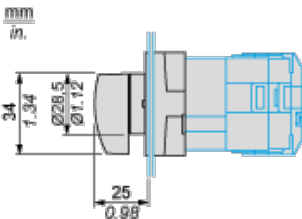

Operating Head

Panel Cut-out

mm  
in.

