



Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KBE
Product compatibility	Rear mounting bodies 12 and 20 A by 4 holes
Cam switch head type	With front plate 45 x 45 mm
Type of operator	Black handle, length = 35 mm
Rotary handle padlocking	Without
Presentation of legend	With metallic legend

Complementary

Mechanical durability	1000000 cycles
CAD overall width	45 mm
CAD overall height	45 mm
CAD overall depth	60 mm
Length	35 mm
Product weight	0.029 kg

Environment


protective treatment	TC
ambient air temperature for operation	-25...55 °C
ambient air temperature for storage	-40...70 °C
shock resistance	30 gn conforming to IEC 68-2-27
vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP40 conforming to IEC 529 IP40 conforming to NF C 20-010

Contractual warranty

Warranty period	18 months
-----------------	-----------

Operating Head

For 4 Hole, Rear Mounting Body

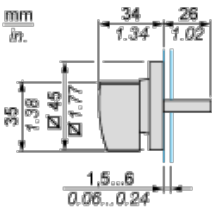

Operating Head

Panel Cut-out

