



Main

Range of product	Harmony Series K
Product or component type	Cam switch operating head
Component name	KDG
Product compatibility	Front mounting bodies 12 and 20 A by multifixing
Cam switch head type	With front plate 45 x 45 mm
Type of operator	Black handle, length = 35 mm
Rotary handle padlocking	Without
Presentation of legend	Without

Complementary

Mechanical durability	1000000 cycles
CAD overall width	45 mm
CAD overall height	45 mm
CAD overall depth	34 mm
Length	35 mm
Product weight	0.01 kg

Environment


protective treatment	TC
ambient air temperature for operation	-25...55 °C
ambient air temperature for storage	-40...70 °C
shock resistance	30 gn conforming to IEC 68-2-27
vibration resistance	5 gn, 10...150 Hz conforming to IEC 68-2-6
IP degree of protection	IP40 conforming to IEC 529 IP40 conforming to NF C 20-010

Contractual warranty

Warranty period	18 months
-----------------	-----------

Operating Head


For "Multi-Fixing", Front Mounting Body

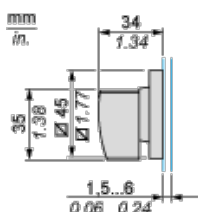

Operating Head

Panel Cut-out (1)

The information provided in this documentation contains general descriptions and/or technical characteristics of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.

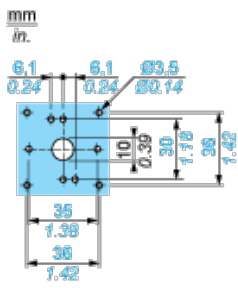

- (1) \varnothing 10 mm/0.39 in. central hole for operating shaft access. 2 or 4 holes for cam switch fixings (choice made by installer).