



Main

Range of product	Zelio Count
Product or component type	Hour counter
Display type	Mechanical
Size	48 x 48 mm
Display digits	7 digit(s)
Reset	Without
Technology type	Electromechanical

Complementary

[Us] rated supply voltage	115 V AC (Us +/- 10 %) at 50 Hz
Power consumption in VA	0.56 VA
Backup time	Permanent
Counting mode	Adding 1/100 of an hour
Time range	0...99 999.99 h
Input function	Enable
Input type	Contact
Mounting mode	Flush-mounted
Mounting support	Panel mounting
Fixing mode	By self-locking clamp
Connections - terminals	Screw terminal block
Height	48 mm
Product weight	0.06 kg
Width	48 mm
Character size	5 mm

Environment

standards	EN 50081-2 EN 50082-2 VDE 0435
product certifications	UR
IP degree of protection	IP65 conforming to EN/IEC 60529
ambient air temperature for operation	-10...50 °C
ambient air temperature for storage	-25...70 °C
vibration resistance	3 gn (f = 10...150 Hz) conforming to EN/IEC 60068-2-6
shock resistance	30 gn for 11 ms conforming to EN/IEC 60068-2-27
electrical shock protection class	Class II conforming to EN/IEC 60536


Contractual warranty

Warranty period	18 months
-----------------	-----------


Electromechanical and Electronic Totalizing Timers

Timers with Mechanical Display

XBKH7000000•M

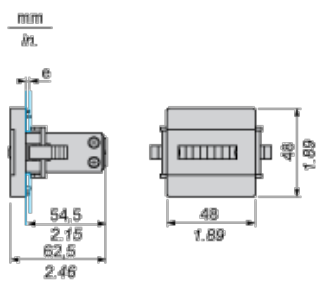


Flush-Mounting

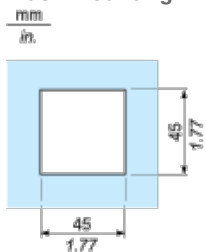

Timers with LCD Display

XBKH81000033E

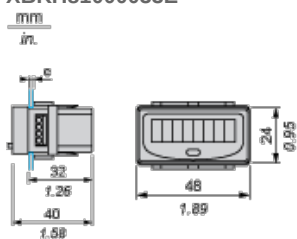

Flush-Mounting

