

Individual subrack components

Side panels and flanges

Side panels for Ripac ECO



Attachment holes for 160/220 mm PCB installation. Continuous pitch pattern of holes top and bottom for cover attachment.



Accessories:
Mounting flanges
see page 143

Material:
1.5 mm sheet steel


Surface finish:
Zinc-plated

Supply includes:
1 side panel

D (T) mm	a mm	Packs of	Max. board depth mm	Height (U) Model No. RP	
				3	6
175	150	1	160	3688.100	3688.102
235	210	1	220	3688.101	3688.103

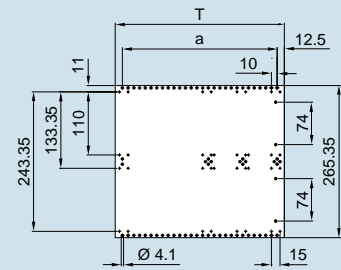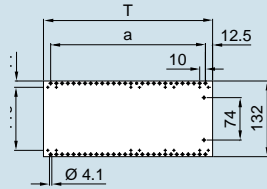

482.6 mm (19") mounting flanges

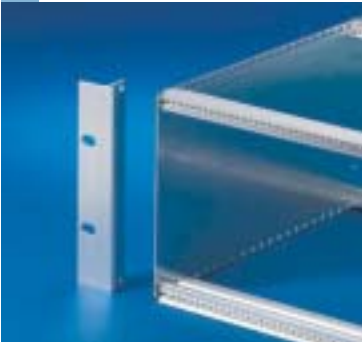

To fit Ripac ECO subracks.


Material:
Extruded aluminium

Surface finish:
Clear chromated


Supply includes:
1 flange

Accessories:
EMC gaskets, vertical
see page 146

U	P. of	Model No. RP
3	1	3688.110
6	1	3688.111

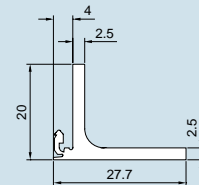

Handles for subracks

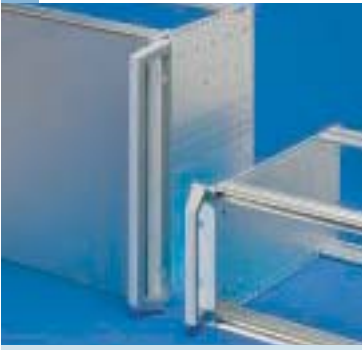

The handles are mounted on the flanges via handle holes.

Material:
Die-cast aluminium

Surface finish:
Spray-finished, silver-grey

Supply includes:
2 handles, assembly parts

U	P. of	Model No. RP
3	2	3636.010
4	2	3636.010
6	2	3666.010
7	2	3666.010