



### Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	General purpose




### Complementary

Electrical connection	7/8"16 UN, 3 pins straight female connector
Cable connector fixing	Screw-on
Collar material	Metal
Status LED	Without
Cable length	5 m
Cable outer diameter	5 mm
Cable composition	3 x 0.5 mm <sup>2</sup>
Wire insulation material	PUR
[Ue] rated operational voltage	250 V AC
[In] rated current	6 A
Contact resistance	5000 µOhm
Insulating resistance	1 GΩ
Product weight	0.42 kg

### Environment

IP degree of protection	IP67
Product certifications	cULus
Ambient air temperature for operation	-35...90 °C (static) -5...90 °C (flexing)
Ambient air temperature for storage	-35...100 °C


## Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0726 - Schneider Electric declaration of conformity <a href="#"> Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold <a href="#">Reference not containing SVHC above the threshold</a>
Product environmental profile	Available <a href="#"> Product Environmental Profile</a>
Product end of life instructions	Available <a href="#"> End of Life Information</a>

## Contractual warranty

Warranty period	18 months
-----------------	-----------

## Dimensions

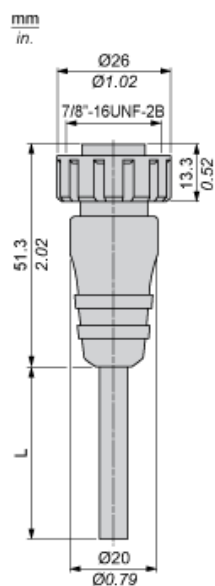


L : Length of cable

---

## Connections and Schemes

---

### Connector

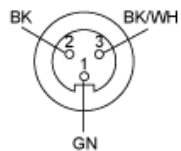

GN : Green

BK : Black

BK/WH : Black / White