




Product Data Sheet

Jumbo Max Min Thermometer and Hygrometer with Clock

White moulded case with two displays for indoor temperature and humidity or outdoor temperature. Complete with 2m long cable for the outdoor probe, hanging hook and stand.

Product Specifications

| | |
|----------------------------------|--|
| Temperature Range: | Indoor: -10 to +50°C&F Outdoor: -50 to +70°C&F |
| Humidity Range: | 20 to 99% RH |
| Divisions: | 0.1°C |
| Accuracy: | +/- 1°C between -10 and 70°C otherwise +/- 2°C +/- 5%RH |
| Battery: | 1.5 volt (AAA) or equivalent x 1 piece |
| CE: | Approved |
| ROHS/WEEE: | Approved |
| Hazard Information (SDS): | See www.brannan.co.uk for information |
| Product Material: | ABS |
| Probe: | 2m cable with stainless steel probe |
| Product Weight: | Packaged - 145g Unpackaged - 121g (incl. battery & probe) |
| Product Dimensions: | Display - 60mm x 80mm Product Unpackaged - 103mm x 98mm x 21mm Product Packaged - 164mm x 126mm x 40mm |
| Display Paper Weight: | 3g (incl. instruction sheet) |
| Display Card Dimensions: | 153mm x 113mm |
| PVC Clam Pack Weight: | 21g |
| PVC Clam Pack Dimensions: | 164mm x 126mm x 40mm |

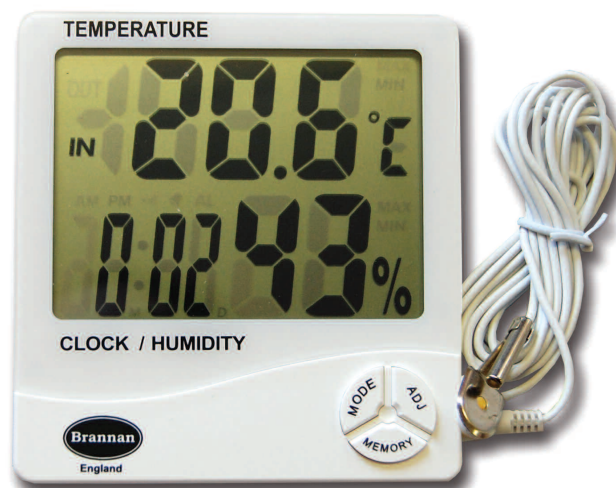

| Description | Barcode | Product No |
|------------------------------|-----------------|------------|
| Jumbo Electronic Thermometer | 5 011405 124210 | 12/421/3 |