

The logo for COAST, featuring the word "COAST" in a bold, italicized, white sans-serif font with a registered trademark symbol, set against a black rectangular background.

Part Number: HL8R

Description: Head Lamp

The HL8R has all of the great features of the HL8 but adds a separate, rechargeable battery pack and higher output. The rechargeable pack can be charged on or off the headlamp using a micro USB. Users also possess the ability to switch to the alkaline battery pack with ease. Equipped with our Pure Beam Focusing System and Twist Focus Technology, you can quickly shift from an ultra wide flood to a long reaching spot with transition halo for full viewing even in spot mode. It has high output, medium output, and low output modes easily controllable with the light control dial on the side of the front making it adaptable for all sorts of needs regarding brightness and run time.

With Coast's commitment to quality, the HL8R Headlamp is impact resistant, weather resistant and its LED is virtually unbreakable. The HL8R Headlamp is backed by Coast's lifetime warranty against defects in materials and workmanship. Tested and rated to ANSI/FL1 standards.




Specifications:

- **BATTERY LOCATION:** Back
- **BATTERY TYPE:** 1 x Lithium Ion / 4 x AA (Alkaline)
- **BEAM DISTANCE (HIGH):** 702 ft / 214 m
- **BEAM DISTANCE (LOW):** 390 ft / 119 m
- **BEAM DISTANCE (MEDIUM):** 180 ft / 55 m
- **INCLUDED:** 1 x Li Ion Pack | 4 x AA Batteries | Light Output Control Dial | 3' Battery Extension Cord | Hardhat Clips

- **LIGHT OUTPUT (HIGH):** 800 Lumens
- **LIGHT OUTPUT (LOW):** 50 Lumens
- **LIGHT OUTPUT (MEDIUM):** 245 Lumens
- **RUNTIME (HIGH):** 4 h 15 min
- **RUNTIME (LOW):** 12 h
- **RUNTIME (MEDIUM):** 62 h

- **WEIGHT:** 12.3 oz / 349 g

Features:

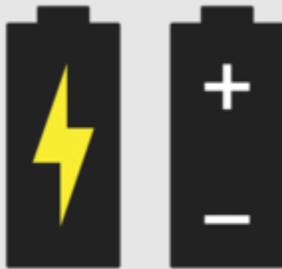

DUAL POWER

Options to stay ready. With COAST Dual Power technology, you have the choice to power your light with USB-rechargeable batteries or with standard alkaline batteries.



FLEX CHARGE

Power up on your terms. Lights with COAST Flex Charge technology feature a rechargeable battery that can be recharged either inside or outside the light. A simple USB connection to either AC or DC ensures you can always get juice.



HARDHAT COMPATIBLE

Rugged enough for the outside of the hardhat. COAST headlamps with Hardhat Compatible design include clips for attaching the light to the hat.




HIGH|MEDIUM|LOW

Control your light power with the push of a button. Cycle between full light, medium light and low light options.




HINGED BEAM

Up, down, or straight ahead. All COAST headlamps feature a hinged, tilting head so that you can adjust the light's direction and see right where you're looking.

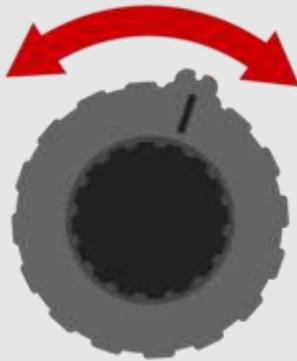

LIGHT CONTROL DIAL

Adjust light intensity to meet your need. COAST headlamps featuring a Light Control Dial allow you to fine-tune light output with one hand by simply turning the knob positioned on the side of the headlamp bezel.

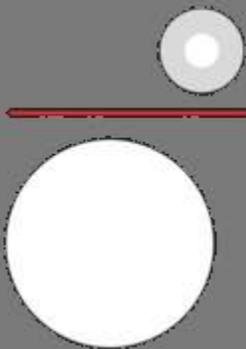

PURE-BEAM FOCUSING OPTIC

Pack two powerful beams into one and seamlessly transition—with no halos or hot spots—between short and long-range viewing. COAST's patented focusing technology adapts to your need. The Ultra View Flood

beam delivers edge-to-edge clarity in a broad circle of light up to 11.5 feet / 3.5 meters across, and the Bulls-Eye Spot beam sends a sharp ray of light at a distance of up to 1151 feet / 351 meters, with a transitional halo around the spot to increase the effective viewing area.



TWIST FOCUS

Dial in the shape of light you need for the situation. COAST's Twist Focus system makes it easy to move between spot and flood beams by simply rotating the head of the flashlight.



WATER RESISTANCE

Don't worry about the weather. COAST lights that have passed the IPX4-level water resistance test are splash-resistant and built with durable materials that stand up to nature.