



Part Number: HP7R

Description: Flashlight

The HP7R Flashlight is the ultimate light for any law enforcement official or serious professional by combining our Long Range Optic System with Slide Focus and a lightweight aluminum body. With our Flex Charge Dual Power system, this light harnesses either lithium or alkaline power and using a micro USB. A USB insert on the battery and tail cap allows for the recharging of the batteries either in or out of the light. With high, strobe and low modes with the slide focus, this light is immediately adaptable to a variety of situations.

With Coast's commitment to quality, the HP7R Flashlight is impact resistant, weather resistant and its LED is virtually unbreakable. The HP7R Flashlight is backed by Coast's lifetime warranty against defects in materials and workmanship. Tested and rated to ANSI/FL1 standards.



Specifications:

- **BATTERY TYPE:** 1 x Lithium Ion / 4 x AAA (Alkaline)
- **BEAM DISTANCE (HIGH):** 1154 ft / 352 m
- **BEAM DISTANCE (LOW):** 364 ft / 111 m
- **INCLUDED:** 2 x Li Ion Batteries | 4 x AAA Batteries | AC+DC with USB adapters | Wall mount + Speed clip | Heavy-duty sheath | Lanyard

- **LENGTH:** 6.125 in / 15.6 cm
- **LIGHT OUTPUT (HIGH):** 300 Lumens
- **LIGHT OUTPUT (LOW):** 30 Lumens
- **RUNTIME (HIGH):** 7 h
- **RUNTIME (LOW):** 33 h


- **WEIGHT:** 7.2 oz / 204 g

Features:



• **BEAM LOCK**

Set the beam to stay how you like it. COAST Beam Lock technology makes our Slide Focusing system even more valuable, with the option to lock the beam in place on spot, flood, or anywhere in between. Twisting the head of the light to the left locks the beam in place, and twisting it back to the right releases the slide mechanism back into motion.

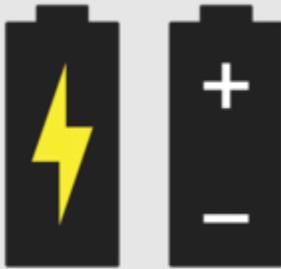

• **DUAL POWER**

Options to stay ready. With COAST Dual Power technology, you have the choice to power your light with USB-rechargeable batteries or with standard alkaline batteries.




FLEX CHARGE

Power up on your terms. Lights with COAST Flex Charge technology feature a rechargeable battery that can be recharged either inside or outside the light. A simple USB connection to either AC or DC ensures you can always get juice.




HIGH|STROBE|LOW

Control your light power with the push of a button. Cycle between full light, strobe and low light options.

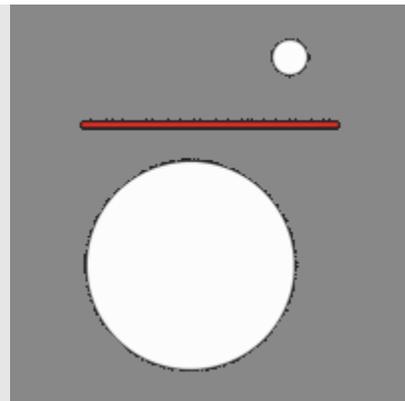

LONG RANGE FOCUSING OPTIC

See clearly near and far. With the Long Range Focusing Optic, the power to illuminate and scan nearfield objects combines with a piercing light that goes the full distance. The X-Range Spot beam shines COAST's longest beam, lighting objects at up to 2762 feet / 842 meters. The Broad View Flood beam delivers an even, sweeping circle of light up to 7.5 feet / 2.3 meters in diameter at a distance of 6 feet / 1.8 meters.

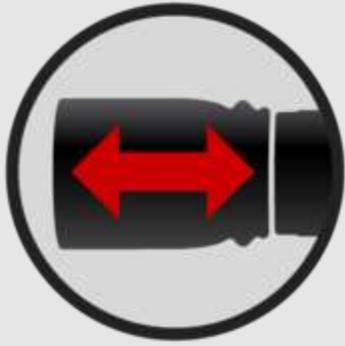

SLIDE FOCUS

One-handed beam control. COAST's Slide Focus system enables you to seamlessly transition between spot and flood beam with the push or pull your finger. Responsive beam-shape control allows you to operate your light with a single hand and keep the other hand free.



WATER RESISTANCE

Don't worry about the weather. COAST lights that have passed the IPX4-level water resistance test are splash-resistant and built with durable materials that stand up to nature.