




ES5160.CR.BGS

High precision Ergo-tek Slim Cutters - Extra Large Oval head, semi-flush. OAL: 125 mm. ESD safe

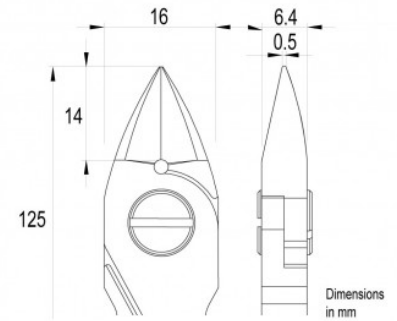

Very strong and durable, for intensive cutting operations

High precision Cutters & Pliers leaflet

Documents

Grip handle material TDS

Product Details

Market - MEDICAL DEVICE	yes
Market - LIFE SCIENCE & MICROSCOPY	yes
Market - ELECTRONICS	yes
Market - WATCHMAKING & JEWELRY	yes
Category	High Precision Cutters
Kit	no
ESD safe	yes
Body material	100Cr6
Grip handle material	Ergo-tek Slim - TPE + PP

Head shape	Oval
Head width (mm - in) - C	16.00 - 0.63
Size/type	Extra Large
Cutting edges	Semi-Flush
OAL (mm - in) - A	125.00 - 4.921
B (mm - in)	14.00 - 0.551
Head thickness (mm - in) - D	6.40 - 0.252
F (mm - in)	0.50 - 0.02
Cutting capacity soft (mm)	0.4-2.0
Cutting capacity soft (AWG)	26-12
Cutting capacity medium (mm)	0.3-1.6
Cutting capacity medium (AWG)	29-14
Cutting capacity hard (mm)	0.05-0.9
Cutting capacity hard (AWG)	44-19
Net weight (g-lb)	89 - 0.196
RoHS compliant	yes



© 2019 IDEAL-TEK SA

via Giuseppe Motta 4, 6828 Balerna - Switzerland

T +41 91 683 32 29 - F +41 91 683 03 71 - E info@ideal-tek.com