




249SVR.SA.1

Plastic replaceable tip tweezers - PVDF - tips: straight, strong, thick. OAL: 130mm. ESD safe

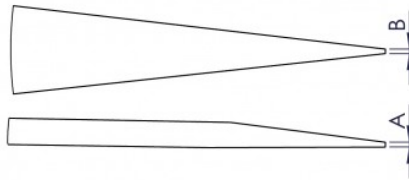

Strong tips

OAL 5" 130 mm

B 0.079" 2.0 mm

A 0.040" 1.0 mm

Documents

 Tip material TDS

 Body material TDS

Product Details

Market - MEDICAL DEVICE	yes
Market - LIFE SCIENCE & MICROSCOPY	yes
Market - ELECTRONICS	yes
Market - WATCHMAKING & JEWELRY	yes
Category	Plastic Replaceable Tip Tweezers
Kit	no
Tip style	249

Tip type characteristic	thick, strong
Bent / angled / curved tip (y/n)	no
Reverse action	no
Handle serration(y/n)	no
Tip serration (y/n)	no
Locking system	no
ESD safe	yes
Body material	SA
Tip material	SV
Product OAL (mm - in)	130.00 - 5.118
Product width (mm - in)	10.00 - 0.394
Product height (mm - in)	15.00 - 0.591
Tip length (mm - in)	40.00 - 1.575
Tip thickness A (mm - in)	1.00 - 0.039
Tip width B (mm - in)	2.00 - 0.079
Tip opening gap (mm - in)	10.00 - 0.394
Net weight (g-lb)	18 - 0.04
RoHS compliant	yes



© 2019 IDEAL-TEK SA

via Giuseppe Motta 4, 6828 Balerna - Switzerland

T +41 91 683 32 29 - F +41 91 683 03 71 - E info@ideal-tek.com