




272CFR.SA.1

Plastic replaceable tip tweezers - Carbon fiber - tips: straight, flat, squared. OAL: 130mm ESD safe

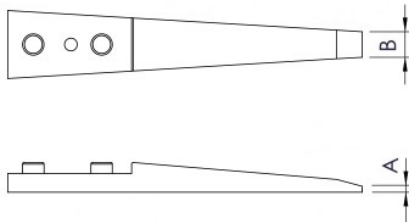

Flat squared tips

OAL 5" 130 mm
B 0.118" 3.0 mm
A 0.028" 0.7 mm

Documents

Tip material TDS

Body material TDS

Product Details

| | |
|-------------------------|-----|
| Market - MEDICAL DEVICE | yes |
|-------------------------|-----|

| | |
|------------------------------------|----------------------------------|
| Market - LIFE SCIENCE & MICROSCOPY | yes |
| Market - ELECTRONICS | yes |
| Market - WATCHMAKING & JEWELRY | yes |
| Category | Plastic Replaceable Tip Tweezers |
| Kit | no |
| Tip style | 272 |
| Tip type characteristic | flat, squared |
| Bent / angled / curved tip (y/n) | no |
| Reverse action | no |
| Handle serration(y/n) | no |
| Locking system | no |
| ESD safe | yes |
| Body material | SA |
| Tip material | CF |
| Product OAL (mm - in) | 130.00 - 5.118 |
| Product width (mm - in) | 10.00 - 0.394 |
| Product height (mm - in) | 18.00 - 0.709 |
| Tip length (mm - in) | 40.00 - 1.575 |
| Tip thickness A (mm - in) | 0.70 - 0.028 |
| Tip width B (mm - in) | 3.00 - 0.118 |
| Tip opening gap (mm - in) | 8 - 0.315 |
| Net weight (g-lb) | 18 - 0.04 |
| RoHS compliant | yes |



© 2019 IDEAL-TEK SA

via Giuseppe Motta 4, 6828 Balerna - Switzerland

T +41 91 683 32 29 - F +41 91 683 03 71 - E info@ideal-tek.com