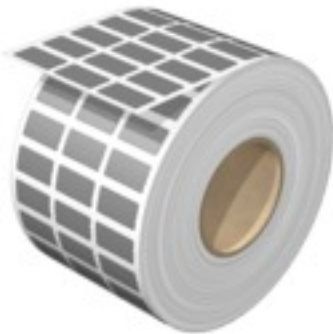


ESG
ESG 9/17 MM GR**Weidmüller Interface GmbH & Co. KG**
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com**Guaranteed long service life: ESG**

The multi-colour and multi-format labels have a strong adhesive layer to ensure the best possible adhesion to the underlying surface. Double laminated polyester makes the basic material very thin and yet extremely tear-resistant.

Your benefits with MultiMark

- Double laminated polyester
- Can be used with equipment from many manufacturers
- Device markers with a familiar design

General ordering data

Type	ESG 9/17 MM GR
Order No.	2005230000
Version	ESG, Device markers, 9 x 17 mm, grey
GTIN (EAN)	4050118390629
Qty.	3,000 pc(s).
compatible printer	2430920000 2448870000

Data sheet

ESG ESG 9/17 MM GR

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Technical data

Dimensions and weights

Width	17 mm	Width (inches)	0.669 inch
Height	9 mm	Height (inches)	0.354 inch
Depth	0.1 mm	Depth (inches)	0.004 inch
Net weight	0.13 g		

General data

Adhesive	Acrylate adhesive	Approval acc. to UL 969	Yes
Colour	grey	Halogen	No
Material	Polyester	Number per roll	3,000
Operating temperature range	-40... 120 °C	UL 94 flammability rating	V-0
Version	Self-adhesive, halogen-free	Width	17 mm

Classifications

ETIM 6.0	EC001288	eClass 6.2	27-14-91-29
eClass 9.0	27-40-06-29	eClass 9.1	27-40-06-29

Approvals

ROHS	Conform
------	---------

Downloads


Engineering Data	EPLAN, WSCAD, Zuken E3.S
Engineering Data	STEP

Data sheet

ESG
ESG 9/17 MM GR

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Drawings

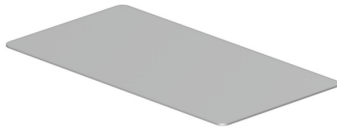

**ESG
ESG 9/17 MM GR**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Accessories

Ink ribbons THM MMP



These printers produce excellent printing results thanks to the thermal transfer technique. Different materials and the user-friendly printing system under Windows optimise marking efforts.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
RIBBON MM 76/360 SW	2005080000	Ink ribbon	4050118389951	1 pc(s).

Accessories / replacement parts



Our marking systems can be used to quickly and reliably label connector markers, conductor and cable markers, device markers and labels. The M-Print® PRO software enables rapid and easy identification of your electrical equipment. You can design, label and order your marking materials professionally and quickly. Frames, barcodes, graphics or photos are easily incorporated. The versatile data conversion routines enable quick and flexible data integration. The Weidmüller PrintJet ADVANCED, MCP Plus and MCP Basic printers and the THM series printers are available for printing.

General ordering data

Type	Order No.	Version	GTIN (EAN)	Qty.
THM MMP ROLLER 115	1357420000		4050118160314	1 pc(s).