



Main

| | |
|------------------------------------|----------------------------------------------------------------------------------|
| Accessory / separate part category | Cabling accessories |
| Accessory / separate part type | Connector |
| Electrical connection | Elbowed male connector M12, 4 pins |
| Collar material | Plastic |
| Status LED | Without |
| Cable connection | Screw terminal / wire size $\leq 0.75 \text{ mm}^2$ / clamping capacity 3...6 mm |

Complementary

| | |
|--------------------------------|---------------------------|
| Cable gland type | Pg 7 |
| Cable connector fixing | Screw-on |
| [Ue] rated operational voltage | 125 V AC 150 V DC |
| [In] rated current | 3 A |
| Enclosure material | Plastic |
| Insulating resistance | $> 1000 \text{ G}\Omega$ |
| Contact resistance | $\leq 8000 \mu\text{Ohm}$ |
| Product weight | 0.025 kg |

Environment

| | |
|---------------------------------------|-------------|
| IP degree of protection | IP67 |
| Ambient air temperature for operation | -40...85 °C |


Offer Sustainability

| | |
|------------------------|---------------------------------------------------------------------------------------------------------------------------------------|
| RoHS (date code: YYWW) | Compliant - since 0545 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity |
|------------------------|---------------------------------------------------------------------------------------------------------------------------------------|

Contractual warranty

| | |
|-----------------|-----------|
| Warranty period | 18 months |
|-----------------|-----------|

Dimensions

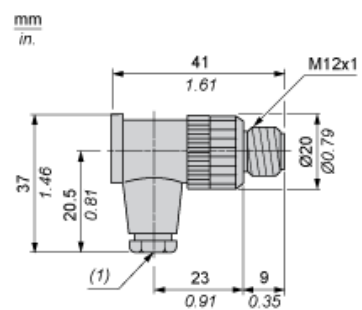

Connections and Schemes

