

Rittal RiCase – external mounting

Front door, vertically hinged



For mechanical protection of built-in control components.

- Optional right-hand or left-hand hinges
- With security lock


Material:

Frame section: Extruded aluminium section, spray finished in RAL 7035
 Corner pieces: Die-cast aluminium, spray finished in RAL 7035
 Window: Smoked acrylic

Supply includes:

1 front door, assembly parts

For enclosure width	W (B) mm	H (U)	Model No. RC
269.2 mm (1 1/2 19")	289	3	3751.300
269.2 mm (1 1/2 19")	289	4	3751.310
482.6 mm (19")	503	3	3751.320
482.6 mm (19")	503	4	3751.330
482.6 mm (19")	503	6	3751.340
482.6 mm (19")	503	7	3751.350

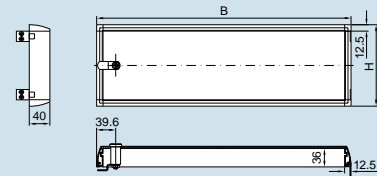

Aluminium front door, vertically hinged



For mechanical protection of built-in control components.

- Optional right-hand or left-hand hinges
- With security lock


Material:

Frame section: Extruded aluminium section, spray finished in RAL 7035
 Corner pieces: Die-cast aluminium, spray finished in RAL 7035
 Aluminium plate

Supply includes:

1 front door, assembly parts

For enclosure width	W (B) mm	H (U)	Model No. RC
482.6 mm (19")	503	3	3751.360
482.6 mm (19")	503	4	3751.370
482.6 mm (19")	503	6	3751.380

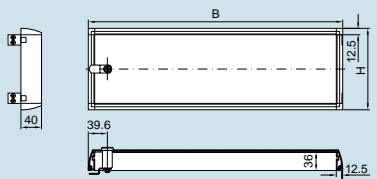

Front door for tower



For mechanical protection of built-in control components.

- Optional right-hand or left-hand hinges
- With security lock


Material:

Frame section: Extruded aluminium section, spray finished in RAL 7035
 Corner pieces: Die-cast aluminium, spray finished in RAL 7035
 Window: Smoked acrylic

Supply includes:

1 front door, assembly parts

For enclosure width	W (B) mm	H (U)	Model No. RC
482.6 mm (19")	503	3	3751.390
482.6 mm (19")	503	4	3751.430

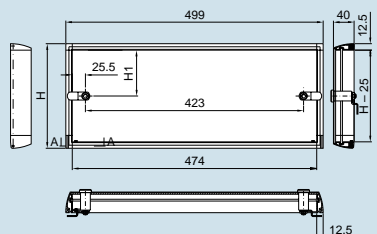

Tower feet



For vertical orientation of enclosures. May be retrofitted.

Material:

Plastic to UL 94-V0, self-extinguishing, RAL 5018/5012/7030

Supply includes:

4 tower feet, assembly parts

Colour RAL	P. of	Model No. RC
5018	1 set	3751.850
5012	1 set	3751.852
7030	1 set	3751.854



RAL5018

RAL5012

RAL7030