

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1731130067](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT High-Density D-Sub Connector, Female, Straight, Solder Cup, Gold Plating, 78 Circuits

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	D-Sub Products
Series	173113
Brochure Order No	987651-9941
Exclude SD Check	Yes
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	High Density
UPC	889056324502

Physical


Circuits (Loaded)	78
Circuits (maximum)	78
Color - Resin	Black
Durability (mating cycles max)	50
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	20.000/g
Number of Rows	4
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Tray
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.08mm
Pitch - Termination Interface	2.08mm
Plating - Contact	Gold over Nickel
Plating - Shell	Nickel
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +105°C
Termination Style	Solder Cup
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	22

Electrical

Current - Maximum per Contact	3.0A
-------------------------------	------

Material Info

Engineering Number	CT50-78S
--------------------	----------

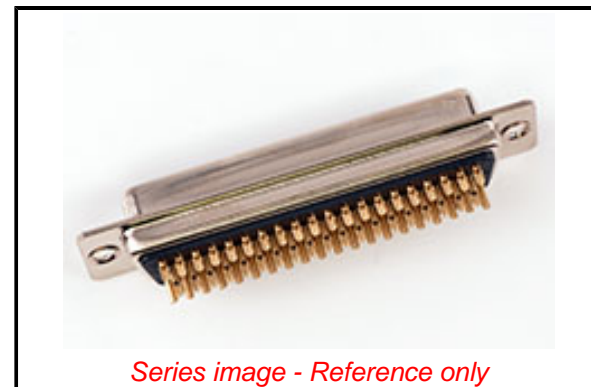

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

For more information, please visit [Contact US](#)

China ROHS

Not Reviewed

ELV

Not Relevant

RoHS Phthalates

Not Reviewed

Search Parts in this Series

173113 Series

Mates With

FCT High-Density D-Sub, Size 5, 78 Position, Plug

This document was generated on 06/21/2019

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION