


## GRIP-B/200

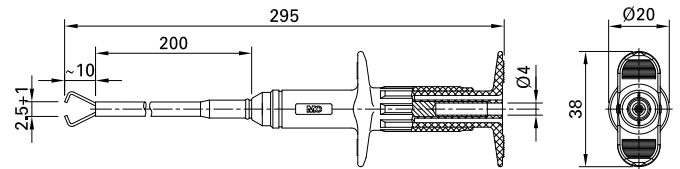

Item number 66.9118-\*

With flexible shaft and spring wire grabber (stainless steel) for a good contact to pins and wires in inaccessible places. Especially suitable for measuring voltages. The shaft is silicone insulated and guarantees good heat resistance and flexibility even at low temperatures.

Ø 4 mm rigid socket in handle accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve. Version with different shaft lengths is available.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT II, 1 A
Base material electrical contact	Edelstahl
Colours *	21 22 23
Opening width	2.5 mm
Test accessory acc. to	IEC EN 61010-031
Length of shaft / clip	200 mm/295 mm
Approvals	UL, CE