

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

2064610800

Status:


Active

Overview:

Micro-Fit Connector System

Description:

Micro-Fit+ Receptacle Housing, Dual Row, 8 Circuits, UL 94V-0, Black

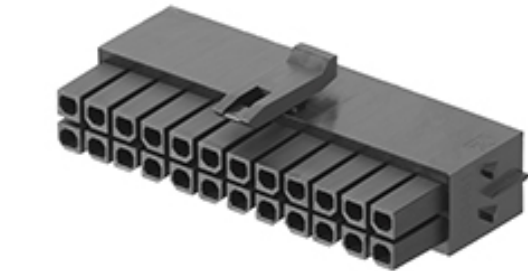

Series image - Reference only

Documents:

Drawing (PDF)

Product Specification 2064600000-PS-000 (PDF)

Packaging Specification 2064610000-PK-000 (PDF)

Test Summary 2064600000-TS-000 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
UL	E29179
General	
Product Family	Crimp Housings
Series	206461
Application	Power, Wire-to-Board
Datasheet Order No	987651-9552
Overview	Micro-Fit Connector System
Product Name	Micro-Fit+
UPC	191130004034
Physical	
Circuits (maximum)	8
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	0.896/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	3.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C
Material Info	
Reference - Drawing Numbers	
Packaging Specification	2064610000-PK-000
Product Specification	2064600000-PS-000
Sales Drawing	2064610000-SD-000
Test Summary	2064600000-TS-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per	
-ED/88/2018 (15	
January 2019)	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

206461 Series

Mates With

Micro-Fit+ Header 206832

Use With

Micro-Fit+ Female Terminal 206460

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION