

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2064612000](#)
Status: **Active**
Overview: [Micro-Fit Connector System](#)
Description: [Micro-Fit+ Receptacle Housing, Dual Row, 20 Circuits, UL 94V-0, Black](#)

Documents:

[Drawing \(PDF\)](#) [Test Summary 2064600000-TS-000 \(PDF\)](#)
[Product Specification 2064600000-PS-000 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Packaging Specification 2064610000-PK-000 \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
 Series [206461](#)
 Application Power, Wire-to-Board
 Datasheet Order No 987651-9552
 Overview [Micro-Fit Connector System](#)
 Product Name Micro-Fit+
 UPC 191130004775


Physical

Circuits (maximum) 20
 Color - Resin Black
 Flammability 94V-0
 Gender Receptacle
 Glow-Wire Capable Yes
 Keying to Mating Part None
 Lock to Mating Part Yes
 Material - Resin Nylon
 Net Weight 1.992/g
 Number of Rows 2
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 3.00mm
 Polarized to Mating Part Yes
 Temperature Range - Operating -40° to +105°C

Material Info

Reference - Drawing Numbers

Packaging Specification 2064610000-PK-000
 Product Specification 2064600000-PS-000
 Sales Drawing 2064610000-SD-000
 Test Summary 2064600000-TS-000

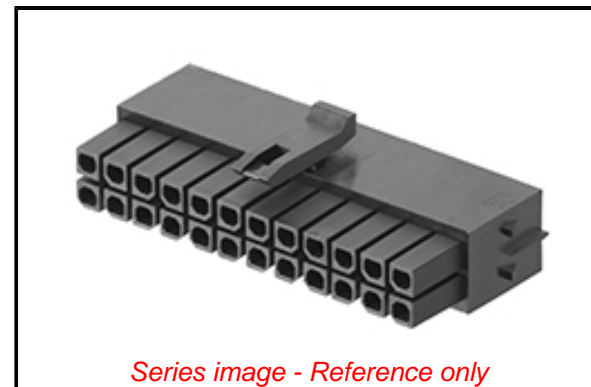

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/88/2018 (15
 January 2019)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[206461](#) Series

Mates With

Micro-Fit+ Header [206832](#)

Use With

Micro-Fit+ Female Terminal [206460](#)