


90° HDMI female to female keystone coupler

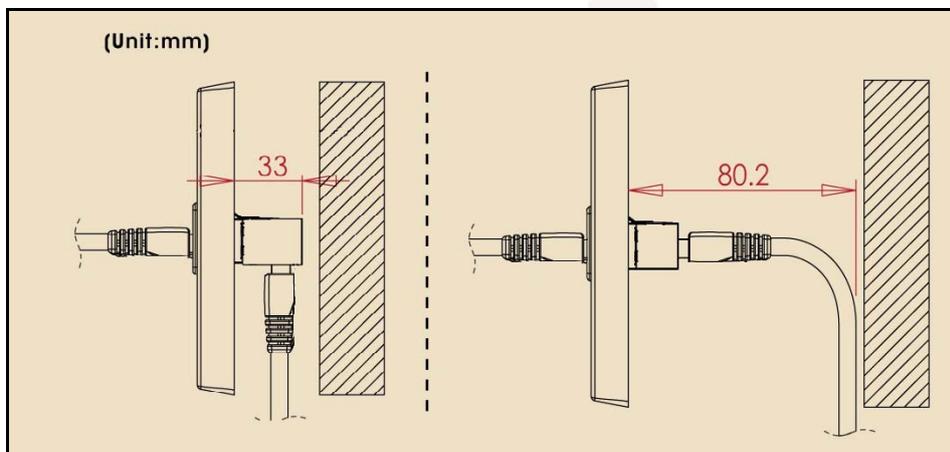

90° HDMI female to female keystone coupler (KCHD90bk, KCHD90wh)

High performance HDMI female to female keystone coupler ideal for use in limited space

Features

- Slim and very compact design enables use in panels or faceplates where width or depth are restricted
- Keystone style HDMI Female/Female coupler
- HDMI High Speed compatible, supports HDMI 1.4 and 2.0
- Gold plated connectors and contacts for maximum signal quality and integrity
- Designed to fit industry standard keystone outlets and patch panels

Specifications

- Weight: 10g approx.
- Dimensions: 38 x 16.5 x 20.8mm
- Colour: black, white
- Material:
 - Housing: high-impact Acrylonitrile Butadiene Styrene (ABS resin), UL 94V-0 rated
 - Shell: copper alloy
 - Contacts: 0.38µm/15µ" gold plated copper alloy
 - PCB: UL 94V-0 rated

Packaging: packed in individual polybags then in bags of 20

Commodity code: 85444290







EAN: KCHD90bk: 5055386507501

KCHD90wh: 5055386507518



ROHS Compliant

Code: KCHD90whep
KCHD90bkep

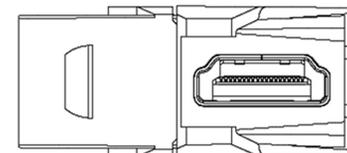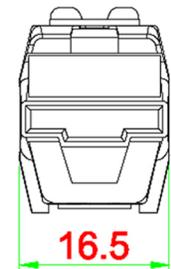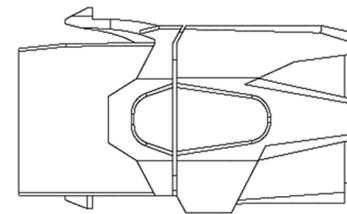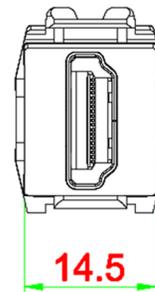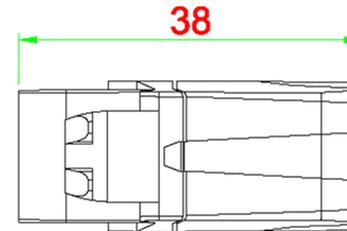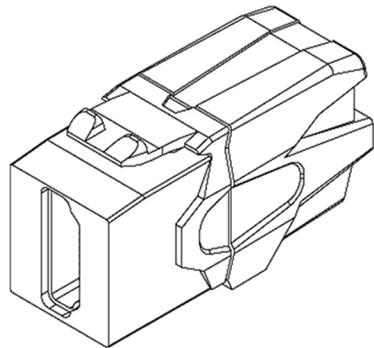

Materials:

Housing : High-impact Acrylonitrile Butadiene Styrene
 (ABS resin), UL 94 V-0 rated

HDMI

Shell : Copper alloy, t=0.5 mm (0.02 in)
 Contacts : Copper alloy, t=0.2 mm (0.01 in),
 plated with 0.38 μ m (15 μ in)
 thick hard gold on contact area

Insulator : High-impact plastic, UL 94 V-0 rated

PCB : FR4, t=1.6 mm (0.063 in), UL 94 V-0 rated

TOLERANCE: · ± 1 · X ± 0.2 · XX ± 0.15