





SUPER BRIGHT 4750 LUMEN



ALSO SHOWING THE SLR-2500/1300 MODELS

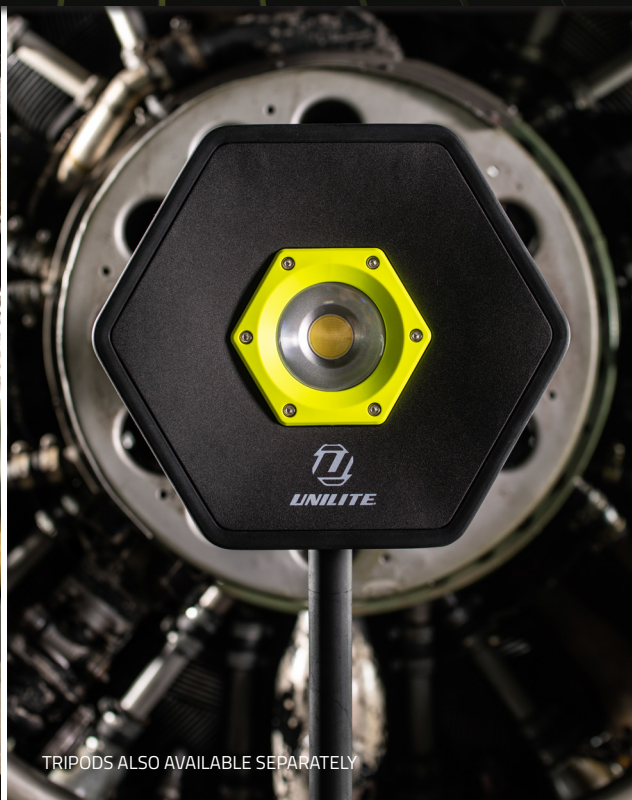

TRIPODS ALSO AVAILABLE SEPARATELY

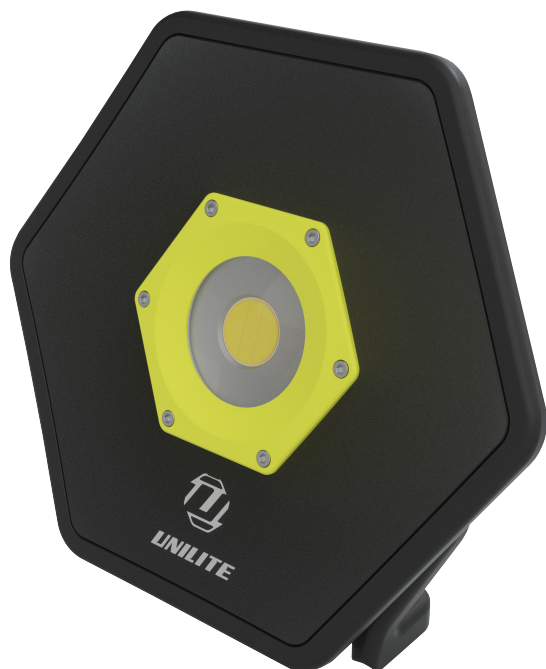

4750
LUMEN
OUTPUT

1.5-6
HOURS
RUNTIME

80
METRE
BEAM RANGE


IP65
DUST + WATER
RESISTANCE

SLR-4750 - INDUSTRIAL SITE LIGHT

- Super bright 4750 Lumen white COB LED
- Dual power - rechargeable & mains
- Power bank function
- Super tough aluminium structure
- IK07 shock resistant
- IP65 dust+water Resistant
- Mains multi-country charger included
- 4.5 Hours charge time



180° ADJUSTABLE HANDLE/STAND

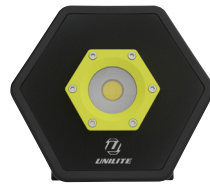

TOUGH ALUMINIUM STRUCTURE

BATTERY 11.1v 5200mAh Li-ion Rechargeable Battery
WEIGHT 1135g
DIMENSIONS 60 x 261 x 237mm