



METEOR SERIES 3 – Triple CCT LED Batten Light B Standard

Slimline batten light, **linkable** via open end cap design and mains loop in/out.

Opal polycarbonate diffuser, low flicker driver.

Available in 2ft, 4ft, 5ft and 6ft lengths.

Single or triple CCT versions. Matt white or silver finish.

Linkable



Features

- Size = low profile (36mm), 78mm batten width
- Housing = aluminium
- Diffuser = opal polycarbonate
- PCB = fibre
- Fitting = surface or suspended mount, linkable
- Driver = low flicker
- Colour Temp = single or switchable

 
Options

- CCT switch = single or triple CCT
(switch located on outside of driver)
- Housing Colour = matt white or matt silver finish
- Length = 2ft, 4ft, 5ft or 6ft

Specifications

- LED type = SMD2835
- CRI = >80
- CCT = 3000K, 4000K, 6000K
single or switchable
- Power Factor = >0.90
- Colour Index = Ra>80
- Input Voltage = AC220-240V 50/60Hz
- Operating Voltage = DC72V
- IP Rating = IP20
- Life Span = 35,000 hours
- Warranty = 3 years

Product Size	CCT		LM/W		
	Single	Rated Power	3000K/4000K/6000K		
2ft/600x78x36mm	T	20W	80	100	90
4ft/1200x78x36mm	T	40W	80	100	90
5ft/1500x78x36mm	T	50W	80	100	90
6ft/1800x78x36mm	T	60W	80	100	90
2ft/600x78x36mm	S	20W	90	100	100
4ft/1200x78x36mm	S	40W	90	100	100
5ft/1500x78x36mm	S	50W	90	100	100
6ft/1800x78x36mm	S	60W	90	100	100



20W = 600 40W = 1200 50W = 1500 60W = 1800





METEOR SERIES 3 – Triple CCT LED Batten Light B Standard

Order Code

MET3B ST 4 XK 45 W

01 02 03 04 05 06


- 01. Product series
- 02. Type (ST = Standard)
- 03. Length (4 = 4ft, 5 = 5ft, 6 = 6ft)
- 04. CCT (3K = 3000K only, 4K = 4000K only, 6K = 6000K only, XK = switchable between 3K/4K/6K)
- 05. Rated Power in W (30, 35, 45, 55 or 65)
- 06. Finish Colour (W = matt white, S = matt silver)



CCT
Switch



Surface Screw or
Suspended Hook Mount

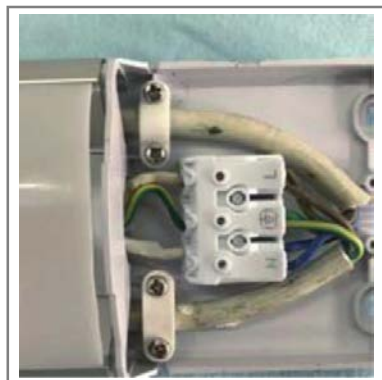

Linking via push in terminal block, mains loop in and out
and 3 –way terminal block on driver