


Technical Data

Part Number: XN16P

Product Group: CCTV

Product Type: NVR

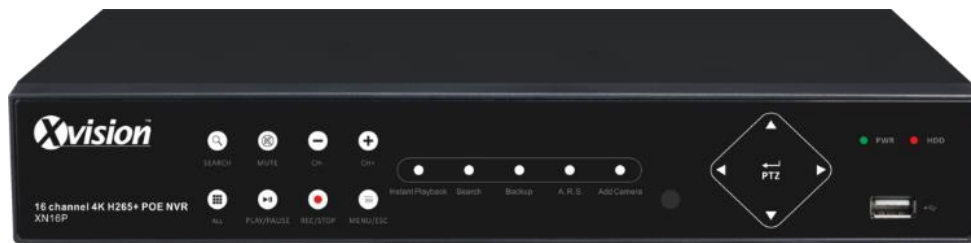

Xvision 16 Camera HD-IP 8MP (4K) H265+ NVR with built in 16 Port PoE Switch

Model: XN16P	
IP Cameras Supported	X2C, X4C, X5C, Onvif
IP Camera Channels	16 Channel
Compression	H264/H265+
Maximum Recording Resolution	8MP (4K)
Recording Bandwidth	168Mbps
Live/Playback	8MP - 2 Channel 5MP - 3 Channel 4MP - 4 Channel 2MP - 8 Channel
Video Output	1 x HDMI (4K), 1 x VGA
Display Split	1/4/6/8/9/10/13/14/16
Recording Mode	Continuous/Manual/Motion
Ethernet	RJ45 10/100M

Technical Data

Internal Hard Drive	2 SATA HDD, up to 6TB (Max 12TB)
ESata	No
PoE Ports	Yes - 16 Port
Alarm Input/Outputs	No
RS485	No
USB Interface	3 x USB For Mouse, Backup, Upgrade
Controls	IR Remote, USB Mouse, Touch Panel
Dropbox Support	Yes - Motion Activated Events
Email Alerts	Yes
Power Supply	DC 48V
Dimensions (WxHxD)	300x53x227mm