


## Data sheet | Item number: 2216-1307

3-conductor ground terminal block; 16 mm<sup>2</sup>; with test port; side and center marking; for DIN-rail 35 x 15 and 35 x 7.5; Push-in CAGE CLAMP®; 16,00 mm<sup>2</sup>; green-yellow



[www.wago.com/2216-1307](http://www.wago.com/2216-1307)

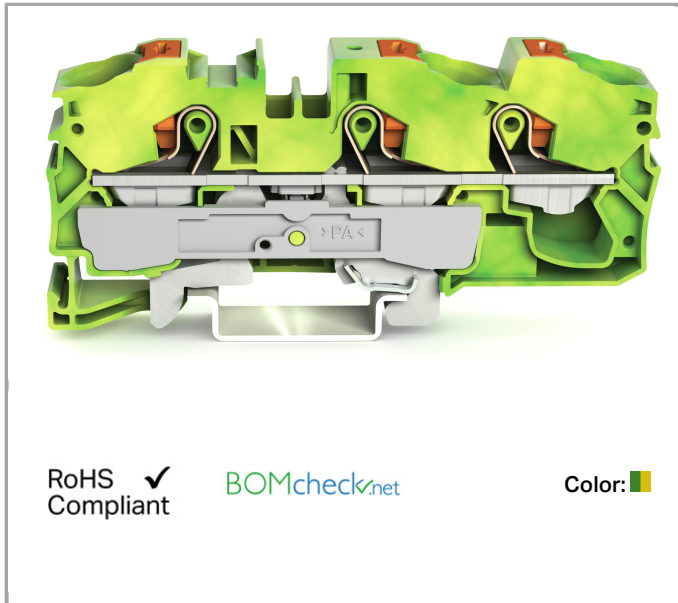

RoHS  
Compliant

BOMcheck.net

Color:

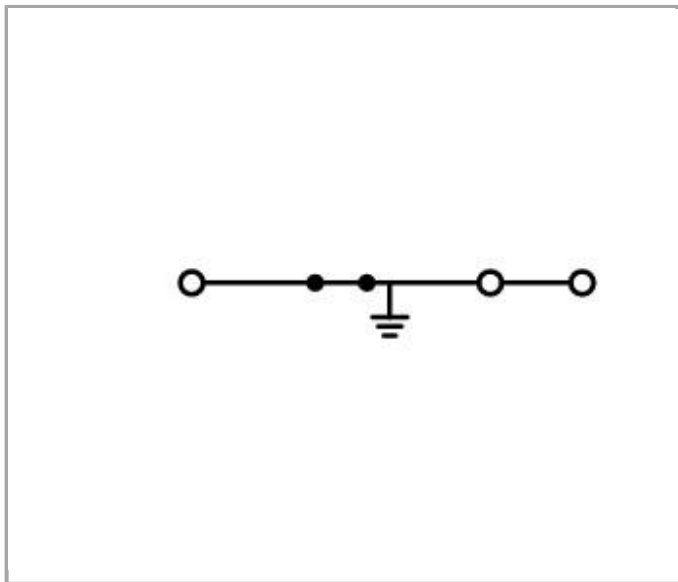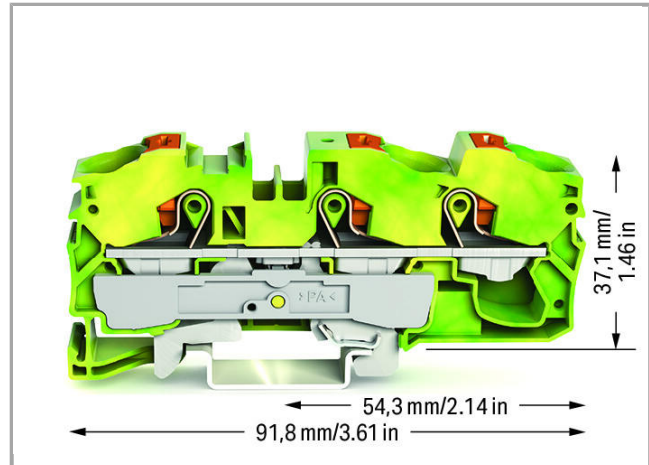

### Item description

#### Safety information 1:

15 mm high DIN-35 rails shall be used for a current load higher than 76 A!



## Data

### Connection data

|                                      |                                                                                                                                   |
|--------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------|
| Connection technology                | Push-in CAGE CLAMP®                                                                                                               |
| Actuation type                       | Push-in<br>Push-button                                                                                                            |
| Connectable conductor materials      | Copper                                                                                                                            |
| Nominal cross section                | 16 mm²                                                                                                                            |
| Solid conductor                      | 0.5 ... 16 mm² / 20 ... 6 AWG                                                                                                     |
| Solid conductor, push-in termination | 2.5 ... 16 mm² / 14 ... 6 AWG                                                                                                     |
| Fine-stranded conductor              | 0.5 ... 25 mm² / 20 ... 4 AWG                                                                                                     |
| Strip length                         | 18 ... 20 mm / 0.71 ... 0.79 inch                                                                                                 |
| Note (conductor cross-section)       | Depending on the conductor characteristic, a conductor with a smaller cross section can also be inserted via push-in termination. |
| Total number of connection points    | 3                                                                                                                                 |
| Total number of potentials           | 1                                                                                                                                 |
| Number of levels                     | 1                                                                                                                                 |
| Type of wiring                       | Front-entry wiring                                                                                                                |
| Number of jumper slots               | 2                                                                                                                                 |

### Geometrical Data

|                                       |                      |
|---------------------------------------|----------------------|
| Width                                 | 12 mm / 0.472 inch   |
| Height from upper-edge of DIN-35 rail | 37.1 mm / 1.461 inch |
| Depth                                 | 91.8 mm / 3.622 inch |

### Mechanical data

|                  |                     |
|------------------|---------------------|
| Design           | horizontal          |
| Type of mounting | DIN-35 rail         |
| Marking level    | Center/side marking |

### Material Data

|                     |                      |
|---------------------|----------------------|
| Color               | green-yellow         |
| Insulating material | Polyamide 66 (PA 66) |
| Weight              | 48.002 g             |

### Commercial data

|                    |               |
|--------------------|---------------|
| Country of origin  | DE            |
| GTIN               | 4055143732802 |
| Customs Tariff No. | 85369010000   |

## Approvals / Certificates

### Ex-Approvals

| Logo                                                                             | Approval                                              | Additional Approval Text | Certificate name                                             |
|----------------------------------------------------------------------------------|-------------------------------------------------------|--------------------------|--------------------------------------------------------------|
|  | <b>AEx</b><br>Underwriters Laboratories Inc.          | UL 60079                 | E185892                                                      |
|  | <b>ATEX</b><br>Physikalisch Technische Bundesanstalt  | EN 60079-0               | PTB 18<br>ATEX<br>1009 U                                     |
|  | <b>IECEX</b><br>Physikalisch Technische Bundesanstalt | IEC 60079                | IECEX PTB<br>18.0016U<br>(Ex eb IIC<br>Gb and EX<br>eb I Mb) |

### Country specific Approvals

| Logo                                                                               | Approval                                     | Additional Approval Text | Certificate name |
|------------------------------------------------------------------------------------|----------------------------------------------|--------------------------|------------------|
|   | <b>CCA</b><br>DEKRA Certification B.V.       | EN 60947                 | NTR NL<br>7669   |
|  | <b>CSA</b><br>DEKRA Certification B.V.       | C22.2                    | 70175032         |
|  | <b>KEMA/KEUR</b><br>DEKRA Certification B.V. | EN 60947                 | 71-<br>102881    |

### Ship Approvals

| Logo                                                                               | Approval                                                | Additional Approval Text | Certificate name         |
|------------------------------------------------------------------------------------|---------------------------------------------------------|--------------------------|--------------------------|
|  | <b>ABS</b><br>American Bureau of Shipping               | -                        | 19-<br>HG1866350-<br>PDA |
|  | <b>DNV GL</b><br>Det Norske Veritas, Germanischer Lloyd | -                        | TAE00003JT               |
|                                                                                    | <b>LR</b><br>Lloyds Register                            | -                        | 19/20050                 |



## UL-Approvals

| Logo                                                                             | Approval                                | Additional Approval Text | Certificate name |
|----------------------------------------------------------------------------------|-----------------------------------------|--------------------------|------------------|
|  | cURus<br>Underwriters Laboratories Inc. | C22.2 No. 158            | 4788362287       |

## Compatible products

## tools



Item no.: 210-721

Operating tool; Blade: 5.5 x 0.8 mm; with a partially insulated shaft

[www.wago.com/210-721](http://www.wago.com/210-721)

## Carrier rail



Item no.: 210-114

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; unslotted; similar to EN 60715

[www.wago.com/210-114](http://www.wago.com/210-114)

Item no.: 210-118

Steel carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715

[www.wago.com/210-118](http://www.wago.com/210-118)

Item no.: 210-196

Aluminum carrier rail; 35 x 8.2 mm; 1.6 mm thick; 2 m long; unslotted; similar to EN 60715; silver-colored

[www.wago.com/210-196](http://www.wago.com/210-196)

Item no.: 210-197

Steel carrier rail; 35 x 15 mm; 1.5 mm thick; 2 m long; slotted; similar to EN 60715

[www.wago.com/210-197](http://www.wago.com/210-197)

Item no.: 210-198

Copper carrier rail; 35 x 15 mm; 2.3 mm thick; 2 m long; unslotted; according to EN 60715; copper-colored

[www.wago.com/210-198](http://www.wago.com/210-198)

## General accessories



Item no.: 2016-100

Finger guard; touchproof cover protects unused conductor entries; yellow

[www.wago.com/2016-100](http://www.wago.com/2016-100)

## check



Item no.: 2009-174

Test plug adapter; for 4 mm Ø test plugs; for testing TOPJOB®S rail-mounted terminal blocks; gray

[www.wago.com/2009-174](http://www.wago.com/2009-174)

Item no.: 2009-182

Testing tap; for max. 2.5 mm²; tool-free connection for individual test wires 0.08 - 2.5 mm; gray

[www.wago.com/2009-182](http://www.wago.com/2009-182)

|                                                                                    |                                                                                                                                                                                            |                                                                                  |
|------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------|
|    | <b>Item no.: 2016-511</b><br>Modular TOPJOB®S connector; modular; for jumper contact slot; 1-pole; 16,00 mm <sup>2</sup> ; gray                                                            | <a href="http://www.wago.com/2016-511">www.wago.com/2016-511</a>                 |
|    | <b>Item no.: 2016-549</b><br>Spacer module; modular; e.g., for bridging commoned terminal blocks; gray                                                                                     | <a href="http://www.wago.com/2016-549">www.wago.com/2016-549</a>                 |
| <b>End plate</b>                                                                   |                                                                                                                                                                                            |                                                                                  |
|    | <b>Item no.: 2016-1391</b><br>End and intermediate plate; 1 mm thick; gray                                                                                                                 | <a href="http://www.wago.com/2016-1391">www.wago.com/2016-1391</a>               |
|    | <b>Item no.: 2016-1392</b><br>End and intermediate plate; 1 mm thick; orange                                                                                                               | <a href="http://www.wago.com/2016-1392">www.wago.com/2016-1392</a>               |
| <b>Jumper</b>                                                                      |                                                                                                                                                                                            |                                                                                  |
|    | <b>Item no.: 2016-402</b><br>Push-in type jumper bar; insulated; 2-way; Nominal current 76 A; light gray                                                                                   | <a href="http://www.wago.com/2016-402">www.wago.com/2016-402</a>                 |
|    | <b>Item no.: 2016-403</b><br>Push-in type jumper bar; insulated; 3-way; Nominal current 76 A; light gray                                                                                   | <a href="http://www.wago.com/2016-403">www.wago.com/2016-403</a>                 |
|    | <b>Item no.: 2016-404</b><br>Push-in type jumper bar; insulated; 4-way; Nominal current 76 A; light gray                                                                                   | <a href="http://www.wago.com/2016-404">www.wago.com/2016-404</a>                 |
|    | <b>Item no.: 2016-405</b><br>Push-in type jumper bar; insulated; 5-way; Nominal current 76 A; light gray                                                                                   | <a href="http://www.wago.com/2016-405">www.wago.com/2016-405</a>                 |
|  | <b>Item no.: 2016-405/011-000</b><br>Star point jumper; insulated; 3-way (1-3-5); IN = IN terminal block; light gray                                                                       | <a href="http://www.wago.com/2016-405/011-000">www.wago.com/2016-405/011-000</a> |
|  | <b>Item no.: 2016-433</b><br>Push-in type jumper bar; insulated; from 1 to 3; Nominal current 76 A; light gray                                                                             | <a href="http://www.wago.com/2016-433">www.wago.com/2016-433</a>                 |
|  | <b>Item no.: 2016-434</b><br>Push-in type jumper bar; insulated; from 1 to 4; Nominal current 76 A; light gray                                                                             | <a href="http://www.wago.com/2016-434">www.wago.com/2016-434</a>                 |
|  | <b>Item no.: 2016-435</b><br>Push-in type jumper bar; insulated; from 1 to 5; Nominal current 76 A; light gray                                                                             | <a href="http://www.wago.com/2016-435">www.wago.com/2016-435</a>                 |
|  | <b>Item no.: 2016-499</b><br>Step-down jumper; insulated; from 16/10 mm <sup>2</sup> to 10/6/4/2.5 mm <sup>2</sup> ; Nominal current 57 A; light gray                                      | <a href="http://www.wago.com/2016-499">www.wago.com/2016-499</a>                 |
|  | <b>Item no.: 210-123</b><br>Wire commoning chain; insulated; 50 connections                                                                                                                | <a href="http://www.wago.com/210-123">www.wago.com/210-123</a>                   |
| <b>ferrule</b>                                                                     |                                                                                                                                                                                            |                                                                                  |
|  | <b>Item no.: 216-210</b><br>Ferrule; Sleeve for 16 mm <sup>2</sup> / AWG 6; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; blue    | <a href="http://www.wago.com/216-210">www.wago.com/216-210</a>                   |
|  | <b>Item no.: 216-284</b><br>Ferrule; Sleeve for 1.5 mm <sup>2</sup> / AWG 16; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; black | <a href="http://www.wago.com/216-284">www.wago.com/216-284</a>                   |
|  | <b>Item no.: 216-286</b><br>Ferrule; Sleeve for 2.5 mm <sup>2</sup> / AWG 14; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; blue  | <a href="http://www.wago.com/216-286">www.wago.com/216-286</a>                   |
|                                                                                    | <b>Item no.: 216-287</b><br>Ferrule; Sleeve for 4 mm <sup>2</sup> / AWG 12; insulated; electro-tin plated; electrolytic copper; gastight                                                   | <a href="http://www.wago.com/216-287">www.wago.com/216-287</a>                   |



crimped; acc. to DIN 46228, Part 4/09.90; gray



**Item no.: 216-288**

Ferrule; Sleeve for 6 mm<sup>2</sup> / AWG 10; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; yellow

[www.wago.com/216-288](http://www.wago.com/216-288)



**Item no.: 216-289**

Ferrule; Sleeve for 10 mm<sup>2</sup> / AWG 8; insulated; electro-tin plated; electrolytic copper; gastight crimped; acc. to DIN 46228, Part 4/09.90; red

[www.wago.com/216-289](http://www.wago.com/216-289)

**Marking accessories**



**Item no.: 2009-110**

Marking strips; on reel; not stretchable; plain; snap-on type; white

[www.wago.com/2009-110](http://www.wago.com/2009-110)



**Item no.: 2009-115**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; white

[www.wago.com/2009-115](http://www.wago.com/2009-115)



**Item no.: 2009-115/000-002**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; yellow

[www.wago.com/2009-115/000-002](http://www.wago.com/2009-115/000-002)



**Item no.: 2009-115/000-006**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; blue

[www.wago.com/2009-115/000-006](http://www.wago.com/2009-115/000-006)



**Item no.: 2009-115/000-007**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; gray

[www.wago.com/2009-115/000-007](http://www.wago.com/2009-115/000-007)



**Item no.: 2009-115/000-012**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; orange

[www.wago.com/2009-115/000-012](http://www.wago.com/2009-115/000-012)



**Item no.: 2009-115/000-017**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; light green

[www.wago.com/2009-115/000-017](http://www.wago.com/2009-115/000-017)



**Item no.: 2009-115/000-023**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; green

[www.wago.com/2009-115/000-023](http://www.wago.com/2009-115/000-023)



**Item no.: 2009-115/000-024**

WMB-Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; violet

[www.wago.com/2009-115/000-024](http://www.wago.com/2009-115/000-024)



**Item no.: 2009-145**

Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; white

[www.wago.com/2009-145](http://www.wago.com/2009-145)



**Item no.: 2009-145/000-002**

Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; yellow

[www.wago.com/2009-145/000-002](http://www.wago.com/2009-145/000-002)



**Item no.: 2009-145/000-005**

Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; red

[www.wago.com/2009-145/000-005](http://www.wago.com/2009-145/000-005)



**Item no.: 2009-145/000-006**

Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; blue

[www.wago.com/2009-145/000-006](http://www.wago.com/2009-145/000-006)

|                                                                                    |                                                                                                                                       |                                                                                  |
|------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------|
|    | <b>Item no.: 2009-145/000-007</b><br>Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; gray   | <a href="http://www.wago.com/2009-145/000-007">www.wago.com/2009-145/000-007</a> |
|    | <b>Item no.: 2009-145/000-012</b><br>Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; orange | <a href="http://www.wago.com/2009-145/000-012">www.wago.com/2009-145/000-012</a> |
|    | <b>Item no.: 2009-145/000-023</b><br>Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; green  | <a href="http://www.wago.com/2009-145/000-023">www.wago.com/2009-145/000-023</a> |
|    | <b>Item no.: 2009-145/000-024</b><br>Mini-WSB Inline; for Smart Printer; on reel; stretchable 5 - 5.2 mm; plain; snap-on type; violet | <a href="http://www.wago.com/2009-145/000-024">www.wago.com/2009-145/000-024</a> |
|    | <b>Item no.: 2009-191</b><br>Group marker carrier                                                                                     | <a href="http://www.wago.com/2009-191">www.wago.com/2009-191</a>                 |
|    | <b>Item no.: 2009-192</b><br>Group marker carrier                                                                                     | <a href="http://www.wago.com/2009-192">www.wago.com/2009-192</a>                 |
|    | <b>Item no.: 2009-193</b><br>Group marker carrier                                                                                     | <a href="http://www.wago.com/2009-193">www.wago.com/2009-193</a>                 |
|   | <b>Item no.: 2009-198</b><br>Adaptor                                                                                                  | <a href="http://www.wago.com/2009-198">www.wago.com/2009-198</a>                 |
|  | <b>Item no.: 248-501</b><br>Miniature WSB Quick marking system; plain; Marker width 5 mm; 10 strips with 10 markers per card          | <a href="http://www.wago.com/248-501">www.wago.com/248-501</a>                   |
|  | <b>Item no.: 248-501/000-002</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; yellow                      | <a href="http://www.wago.com/248-501/000-002">www.wago.com/248-501/000-002</a>   |
|  | <b>Item no.: 248-501/000-005</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                       | <a href="http://www.wago.com/248-501/000-005">www.wago.com/248-501/000-005</a>   |
|  | <b>Item no.: 248-501/000-006</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                       | <a href="http://www.wago.com/248-501/000-006">www.wago.com/248-501/000-006</a>   |
|  | <b>Item no.: 248-501/000-007</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                       | <a href="http://www.wago.com/248-501/000-007">www.wago.com/248-501/000-007</a>   |
|  | <b>Item no.: 248-501/000-012</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                       | <a href="http://www.wago.com/248-501/000-012">www.wago.com/248-501/000-012</a>   |
|  | <b>Item no.: 248-501/000-017</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                       | <a href="http://www.wago.com/248-501/000-017">www.wago.com/248-501/000-017</a>   |
|  | <b>Item no.: 248-501/000-023</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                       | <a href="http://www.wago.com/248-501/000-023">www.wago.com/248-501/000-023</a>   |

|                                                                                    |                                                                                                                                                           |                                                                                  |
|------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------------------------------------------------------------|----------------------------------------------------------------------------------|
|    | <b>Item no.: 248-501/000-024</b><br>Mini-WSB marking card; as card; not stretchable; plain; snap-on type; white                                           | <a href="http://www.wago.com/248-501/000-024">www.wago.com/248-501/000-024</a>   |
|    | <b>Item no.: 793-501</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                        | <a href="http://www.wago.com/793-501">www.wago.com/793-501</a>                   |
|    | <b>Item no.: 793-501/000-002</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-002">www.wago.com/793-501/000-002</a>   |
|    | <b>Item no.: 793-501/000-005</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-005">www.wago.com/793-501/000-005</a>   |
|    | <b>Item no.: 793-501/000-006</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-006">www.wago.com/793-501/000-006</a>   |
|    | <b>Item no.: 793-501/000-007</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-007">www.wago.com/793-501/000-007</a>   |
|    | <b>Item no.: 793-501/000-012</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-012">www.wago.com/793-501/000-012</a>   |
|   | <b>Item no.: 793-501/000-017</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-017">www.wago.com/793-501/000-017</a>   |
|  | <b>Item no.: 793-501/000-023</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-023">www.wago.com/793-501/000-023</a>   |
|  | <b>Item no.: 793-501/000-024</b><br>WMB marking card; as card; not stretchable; plain; snap-on type; white                                                | <a href="http://www.wago.com/793-501/000-024">www.wago.com/793-501/000-024</a>   |
|  | <b>Item no.: 793-5501</b><br>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; white          | <a href="http://www.wago.com/793-5501">www.wago.com/793-5501</a>                 |
|  | <b>Item no.: 793-5501/000-002</b><br>WMB marking card; as card; for terminal block width 5 - 17.5 mm; stretchable 5 - 5.2 mm; plain; snap-on type; yellow | <a href="http://www.wago.com/793-5501/000-002">www.wago.com/793-5501/000-002</a> |
|  | <b>Item no.: 793-5501/000-005</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; red                                          | <a href="http://www.wago.com/793-5501/000-005">www.wago.com/793-5501/000-005</a> |
|  | <b>Item no.: 793-5501/000-006</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; blue                                         | <a href="http://www.wago.com/793-5501/000-006">www.wago.com/793-5501/000-006</a> |
|  | <b>Item no.: 793-5501/000-007</b><br>WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; gray                                         | <a href="http://www.wago.com/793-5501/000-007">www.wago.com/793-5501/000-007</a> |



**Item no.: 793-5501/000-012**

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; orange

[www.wago.com/793-5501/000-012](http://www.wago.com/793-5501/000-012)**Item no.: 793-5501/000-017**

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; light green

[www.wago.com/793-5501/000-017](http://www.wago.com/793-5501/000-017)**Item no.: 793-5501/000-023**

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; green

[www.wago.com/793-5501/000-023](http://www.wago.com/793-5501/000-023)**Item no.: 793-5501/000-024**

WMB marking card; as card; stretchable 5 - 5.2 mm; plain; snap-on type; violet

[www.wago.com/793-5501/000-024](http://www.wago.com/793-5501/000-024)**Downloads****Documentation****Bid Text**

2216-1307

docx  
15.1 kB[Download](#)**Additional Information**

Technical explanations

Apr 3, 2019

pdf  
2.1 MB[Download](#)**CAD/CAE-Data****CAD data**

3D Download 2216-1307

URL

[Download](#)**EPLAN**

EPLAN Data Portal

[Download](#)

Subject to changes.

WAGO Kontakttechnik GmbH &amp; Co. KG

Hansastr. 27

32423 Minden

Phone: +49571 887-0 | Fax: +49571 887-169

Email: [info.de@wago.com](mailto:info.de@wago.com) | Web: [www.wago.com](http://www.wago.com)

Do you have any questions about our products?

We are always happy to take your call at +49 (571) 887-44222.