



IP44
RATED

LETO


ADJUSTABLE WALL LIGHT

TECHNICAL

* Lamps not included

Colour temp	Product code	Wattage	Lamp type
N/A	ZN-26536-SST	35W Max	1 x GU10*
N/A	ZN-26536-BLK		
N/A	ZN-26536-WHT		
N/A	ZN-26536-COP		

Dimensions

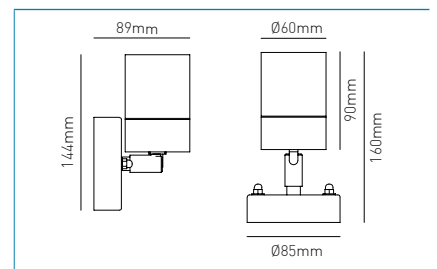

GENERAL

Input voltage	220-240V
Constructional material	Metal
Class	1
IP rating	IP44
Weight (kg)	0.46kg
Fixings & Instructions supplied	Yes

Energy efficiency rating

PRODUCT DATA

Product code	Description	Colour	EAN
ZN-26536-SST	Leto Adjustable Wall Light	Stainless Steel	5020024512087
ZN-26536-BLK	Leto Adjustable Wall Light	Black	5020024704017
ZN-26536-WHT	Leto Adjustable Wall Light	White	5020024704024
ZN-26536-COP	Leto Adjustable Wall Light	Copper	5020024703706