



Simple to butt connect fittings together

IP20
RATED

LED

NO DRIVER
REQUIRED


BUDE

UNDER CABINET LINK LIGHT

TECHNICAL

Colour temp	Product code	Length	Weight	Wattage	lm	lm/W
WW / 3000K	ELA-28418-WHT	320mm	N/A	4W	400	100
WW / 3000K	ELA-28419-WHT	480mm	N/A	7W	700	100
WW / 3000K	ELA-28420-WHT	880mm	N/A	12W	1000	83
WW / 3000K	ELA-28421-WHT	1180mm	N/A	14W	1200	85
CW / 4000K	ELA-28414-WHT	320mm	N/A	4W	400	100
CW / 4000K	ELA-28415-WHT	480mm	N/A	7W	700	100
CW / 4000K	ELA-28416-WHT	880mm	N/A	12W	1000	83
CW / 4000K	ELA-28417-WHT	1180mm	N/A	14W	1200	85

Dimensions

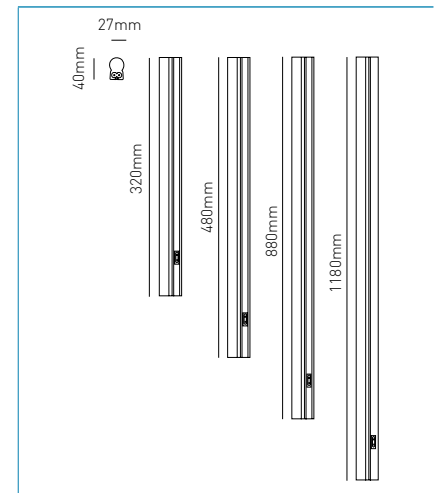

GENERAL

Input voltage	220-240V
Constructional material	Plastic
Class	2
IP rating	IP20
Fixings & Instructions supplied	Yes

Energy efficiency rating

This luminaire is compatible with bulbs of the energy classes: A++, A+, A

LED

874/2012

PRODUCT DATA

Product code	Description	Colour	EAN
ELA-28418-WHT	Bude 320mm LED Link Light Warm White	White/Opal	5020024703928
ELA-28419-WHT	Bude 480mm LED Link Light Warm White	White/Opal	5020024703935
ELA-28420-WHT	Bude 880mm LED Link Light Warm White	White/Opal	5020024703942
ELA-28421-WHT	Bude 1180mm LED Link Light Warm White	White/Opal	5020024703959
ELA-28414-WHT	Bude 320mm LED Link Light Natural White	White/Opal	5020024703881
ELA-28415-WHT	Bude 480mm LED Link Light Natural White	White/Opal	5020024703898
ELA-28416-WHT	Bude 880mm LED Link Light Natural White	White/Opal	5020024703904
ELA-28417-WHT	Bude 1180mm LED Link Light Natural White	White/Opal	5020024703911