




**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

FREQUENCY

11.059200MHz

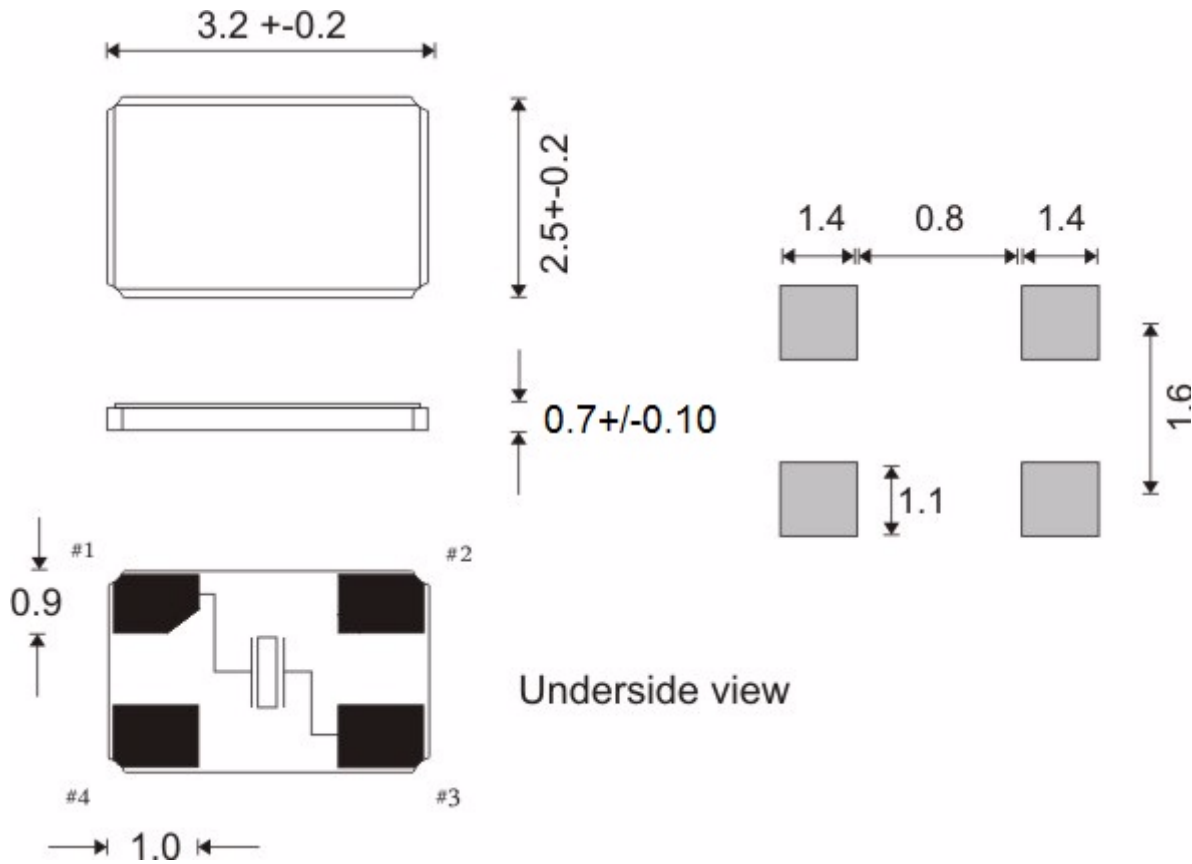

Holder Style	3X25X06 4-Pad
Mode	Fundamental
Adjustment Tolerance	± 10 PPM at 25°C
Temperature Stability	± 20 PPM
Operating Temp. Range	-40°C to +85°C
Load Capacitance	18 pF
ESR	100 Max Ohm
Static Capacitance (C0)	Unspecified pF
Ageing	+/-5ppm 1st Year Max
Marking	A11.05 WW/YY

Amdt Date	Change Note	AEL Code
7 JUN 13	Marking Updated	X11M059200S055
		Issue Ref B