




**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

FREQUENCY
27.120000MHz

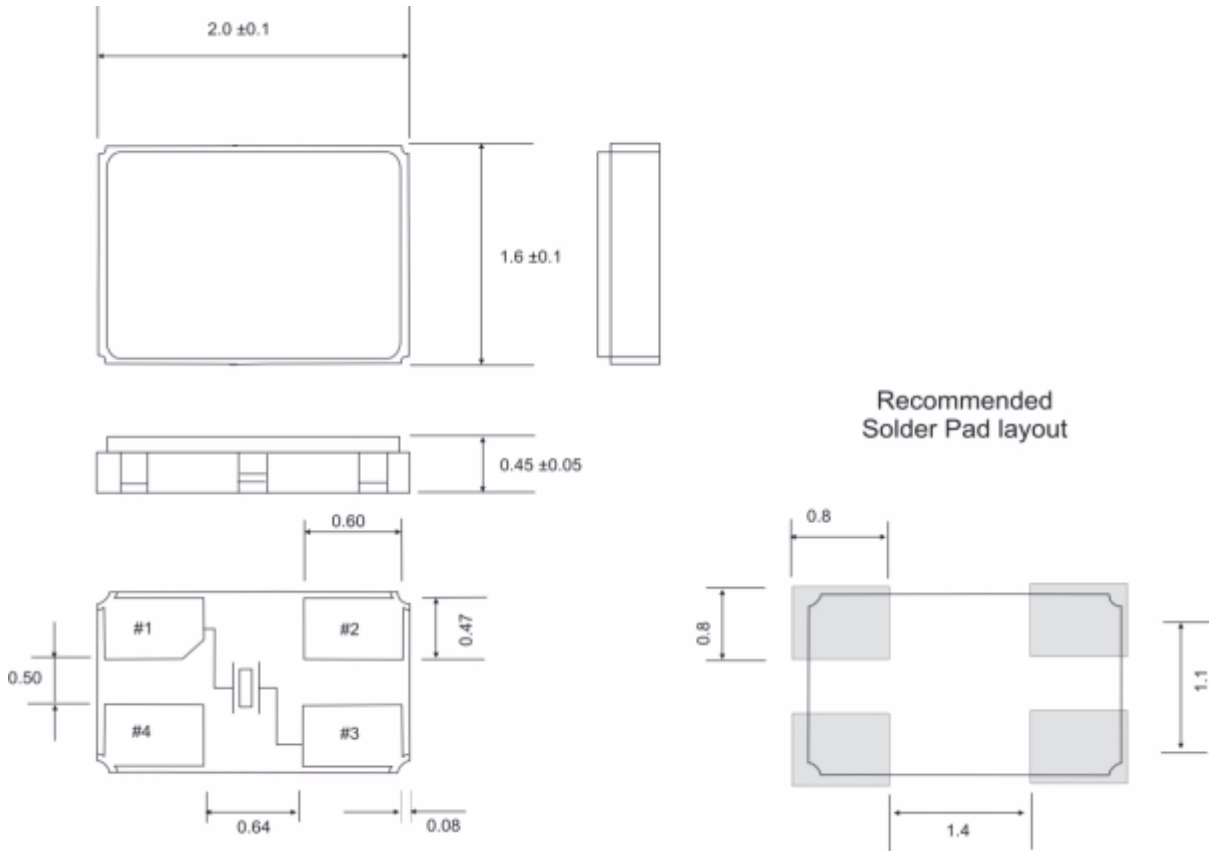

Holder Style	2x16x05 4-pad
Mode	Fundamental
Adjustment Tolerance	± 10PPM at 25°C
Temperature Stability	± 10 PPM
Operating Temp. Range	-20°C to +70°C
Load Capacitance	10 pF
ESR	80 Ohm
Drive Level	100uW Max mW
Static Capacitance (C0)	7pF Max pF
Ageing	5PPM/Year
Marking	AEL27.12

Amdt Date	Change Note	AEL Code
		X27M120000S003
		Issue Ref A