




**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

**FREQUENCY
32.768000kHz**

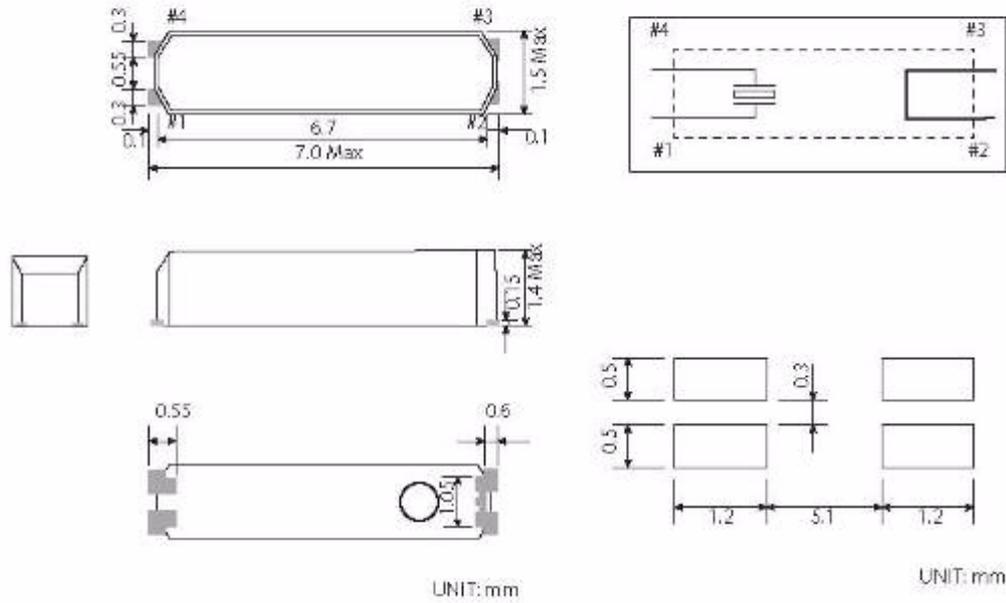

Holder Style	7x1,5 SMD
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Operating Temp. Range	-40°C to +85°C
Load Capacitance	7.0 pF
ESR	65,000 Ohm
Static Capacitance (C0)	Unspecified pF
Ageing	+/-5ppm 1st Year Max
Marking	AEL32.768

Amdt Date	Change Note	AEL Code
7 AUG 17	Carrier tape pitch changed to 4.0mm from 15/08/17	X32K768S038
		Issue Ref B