




SPECIFICATION CONTROL DRAWING Crystal Resonator

FREQUENCY
52.000000MHz

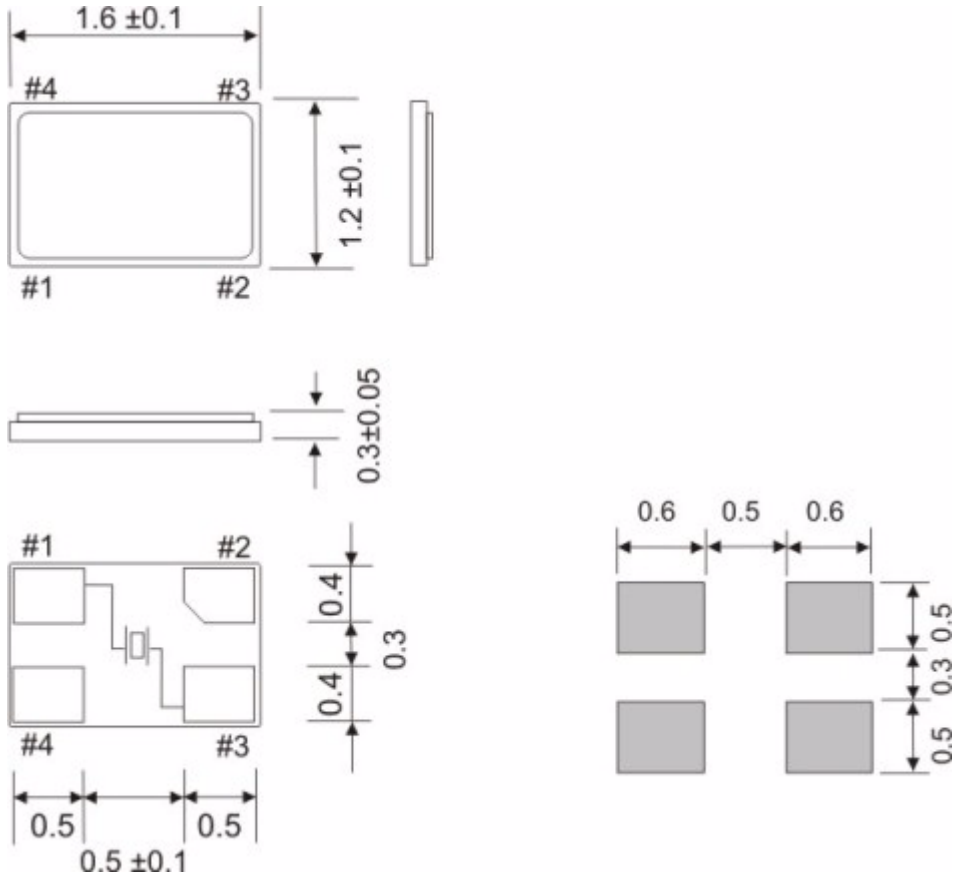

Holder Style Mode Adjustment Tolerance Temperature Stability Operating Temp. Range Load Capacitance ESR Drive Level Static Capacitance (C0) Ageing Marking	1,6 x 1,2mm 4P Fundamental ± 10 PPM at 25°C ± 10 PPM -10°C to +60°C 8 pF 100Max Ohm 100uW Max mW Unspecified pF +/-3ppm 1st Year Max 52 / YM
--	--

Amdt Date	Change Note	AEL Code		
17 JUN 16	Marking Updated	X52M000000S001		
		<table border="1" style="width: 100%; border-collapse: collapse;"> <tr> <td style="width: 70%; background-color: #cccccc;">Issue Ref</td> <td style="text-align: center;">B</td> </tr> </table>	Issue Ref	B
Issue Ref	B			