

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [1512072209](#)  
**Status:** **Active**  
**Overview:** CP Wire-to-Board and Wire-to-Wire Connector Systems  
**Description:** CP-6.5 Receptacle Housing, Glow-Wire Capable, 6.50mm Pitch, Dual Row, 2 Circuits, Red

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Test Summary 1512070001-TS-000 (PDF)</a>
<a href="#">Product Specification 2034380001-PS-000 (PDF)</a>	<a href="#">Test Summary 2034380001-TS-000 (PDF)</a>
<a href="#">Product Specification 2035550001-PS-000 (PDF)</a>	<a href="#">Test Summary 2035550001-TS-000 (PDF)</a>
<a href="#">Product Specification PS-151048-0001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Packaging Specification 1512070001-PK-000 (PDF)</a>	

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">151207</a>
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	See Product Specification for maximum current rating by circuit size and wire AWG, See Product Specification for maximum current rating by circuit size and wire AWG
Datasheet Order No	987651-1601
Overview	<a href="#">CP Wire-to-Board and Wire-to-Wire Connector Systems</a>
Product Name	CP-6.5
UPC	191128439756

**Physical**

Circuits (maximum)	2
Color - Resin	Red
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.007/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	6.50mm
Pitch - Termination Interface	6.50mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C


**Solder Process Data**

Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	1512070001-PK-000
Product Specification	2034380001-PS-000, 2035550001-PS-000, PS-151048-0001-001
Sales Drawing	1512070001-SD-000

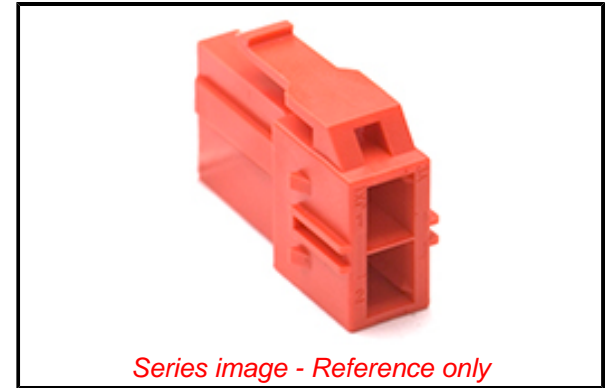

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/71/2019 (16 July 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[151207 Series](#)

**Mates With**

CP-6.5 Headers [1510481209](#) , [1510482209](#) , [2035552012](#) , [2035552022](#) , [2035551012](#) , [2035551022](#) , CP-6.5 Plug Housing [2034382209](#)

**Use With**

CP-6.5 Female Terminal [50597](#) , [50598](#) , TPA Retainer [511430105](#)

This document was generated on 09/17/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**