

Thick Film Chip Resistors 1206

multicomp PRO




Features

- Small size and light weight
- Suitable for both wave and reflow soldering
- Reduction of assembly costs

Performance Specification

Temperature Coefficient	: 1Ω to 10Ω ±400PPM/°C 11Ω to 100Ω ±200PPM/°C >100Ω ±100PPM/°C
Short Time Overload	: ±5% : ±(2% +0.1Ω)Max. ±1% : ±(1% +0.1Ω)Max.
Insulation Resistance	: Min. 1,000MΩ
Dielectric Withstanding Voltage	: No evidence of flashover, mechanical damage, arcing or insulation breakdown.
Terminal Bending	: ±(1% +0.05Ω) Max.
Soldering Heat	: ±(1% +0.05Ω) Max.
Solderability	: Min. 95% coverage
Temperature Cycling	: ±5% : ±(1% +0.05Ω) Max. ±1% : ±(0.5% +0.05Ω) Max.
Humidity (Steady State)	: ±5% : ±(3% +0.1Ω) Max. ±1% : ±(0.5% +0.1Ω) Max.
Load Life in Humidity	: ±5% : ±(3% +0.1Ω) Max. ±1% : ±(1% +0.1Ω) Max.
Load Life	: ±5% : ±(3% +0.1Ω) Max. ±1% : ±(1% +0.1Ω) Max.


Derating Curve

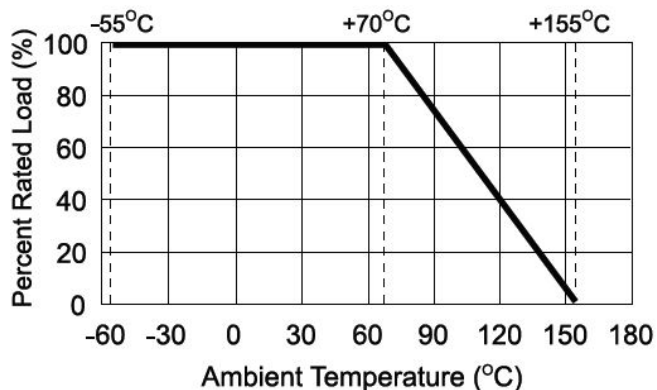

Thick Film Chip Resistors 1206

multicomp PRO

Dimension

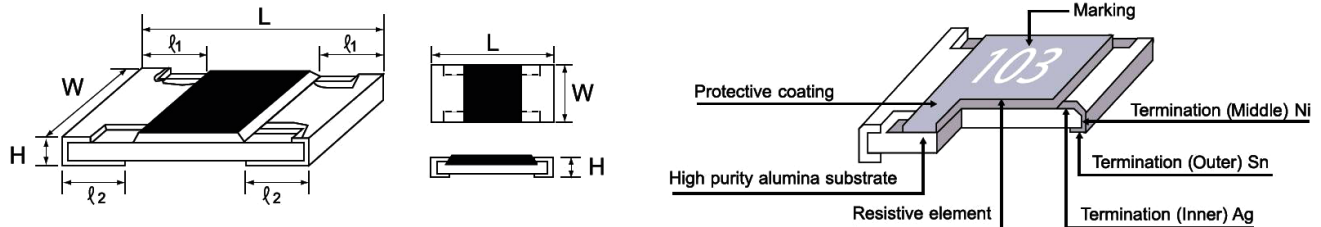

Type	Dimension (mm)				
	L	W	H	ℓ ₁	ℓ ₂
1206	3.1 ±0.15	1.55 ^{+0.15} / _{+0.1}	0.55 ±0.1	0.45 ±0.2	0.45 ±0.2

Type	Power Rating at 70°C	Max. Working Voltage	Max. Overload Voltage	Dielectric Withstanding Voltage	Tolerance %	Resistance Range
1206	1/4W-S 1/8W	2A	4A	-	Jumper	<50mΩ
		200V	400V	500V	±1%	10Ω to 1MΩ
					±2%	1Ω to 10MΩ
					±5%	1Ω to 10MΩ

Part Number Table

Description	Part Number
Resistor, 1K, 0.125W, 1%, 1206, Reel	MC0125W120611K
Resistor, 1K, 0.125W, 1%, 1206	MC0125W120611K
Resistor, 1M, 0.125W, 1%, 1206, Reel	MC0125W120611M
Resistor, 1M, 0.125W, 1%, 1206	MC0125W120611M
Resistor, 1R, 0.125W, 1%, 1206, Reel	MC0125W120611R0
Resistor, 1R, 0.125W, 1%, 1206	MC0125W120611R0
Resistor, 1K05, 0.125W, 1%, 1206, Reel	MC0125W120611K05
Resistor, 1K05, 0.125W, 1%, 1206	MC0125W120611K05
Resistor, 1K1, 0.125W, 1%, 1206, Reel	MC0125W120611K1
Resistor, 1K1, 0.125W, 1%, 1206	MC0125W120611K1
Resistor, 1M1, 0.125W, 1%, 1206, Reel	MC0125W120611M10
Resistor, 1M1, 0.125W, 1%, 1206	MC0125W120611M10
Resistor, 1R1, 0.125W, 1%, 1206, Reel	MC0125W120611R10
Resistor, 1R1, 0.125W, 1%, 1206	MC0125W120611R10
Resistor, 1K15, 0.125W, 1%, 1206, Reel	MC0125W120611K15
Resistor, 1K15, 0.125W, 1%, 1206	MC0125W120611K15
Resistor, 1M15, 0.125W, 1%, 1206, Reel	MC0125W120611M15

Description	Part Number
Resistor, 1M15, 0.125W, 1%, 1206	MC0125W120611M15
Resistor, 1R15, 0.125W, 1%, 1206, Reel	MC0125W120611R15
Resistor, 1R15, 0.125W, 1%, 1206	MC0125W120611R15
Resistor, 1K2, 0.125W, 1%, 1206, Reel	MC0125W120611K2
Resistor, 1K2, 0.125W, 1%, 1206	MC0125W120611K2
Resistor, 1M2, 0.125W, 1%, 1206, Reel	MC0125W120611M20
Resistor, 1M2, 0.125W, 1%, 1206	MC0125W120611M20
Resistor, 1R2, 0.125W, 1%, 1206, Reel	MC0125W120611R20
Resistor, 1R2, 0.125W, 1%, 1206	MC0125W120611R20
Resistor, 1K21, 0.125W, 1%, 1206, Reel	MC0125W120611K21
Resistor, 1K21, 0.125W, 1%, 1206	MC0125W120611K21
Resistor, 1M21, 0.125W, 1%, 1206, Reel	MC0125W120611M21
Resistor, 1M21, 0.125W, 1%, 1206	MC0125W120611M21
Resistor, 1R21, 0.125W, 1%, 1206, Reel	MC0125W120611R21
Resistor, 1R21, 0.125W, 1%, 1206	MC0125W120611R21
Resistor, 1K27, 0.125W, 1%, 1206, Reel	MC0125W120611K27
Resistor, 1K27, 0.125W, 1%, 1206	MC0125W120611K27

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 1R27, 0.125W, 1%, 1206, Reel	MC0125W120611R27
Resistor, 1R27, 0.125W, 1%, 1206	MC0125W120611R27
Resistor, 1K3, 0.125W, 1%, 1206, Reel	MC0125W120611K3
Resistor, 1K3, 0.125W, 1%, 1206	MC0125W120611K3
Resistor, 1M3, 0.125W, 1%, 1206, Reel	MC0125W120611M30
Resistor, 1M3, 0.125W, 1%, 1206	MC0125W120611M30
Resistor, 1R3, 0.125W, 1%, 1206, Reel	MC0125W120611R30
Resistor, 1R3, 0.125W, 1%, 1206	MC0125W120611R30
Resistor, 1K33, 0.125W, 1%, 1206, Reel	MC0125W120611K33
Resistor, 1K33, 0.125W, 1%, 1206	MC0125W120611K33
Resistor, 1R33, 0.125W, 1%, 1206, Reel	MC0125W120611R33
Resistor, 1R33, 0.125W, 1%, 1206	MC0125W120611R33
Resistor, 1K4, 0.125W, 1%, 1206, Reel	MC0125W120611K40
Resistor, 1K4, 0.125W, 1%, 1206	MC0125W120611K40
Resistor, 1M4, 0.125W, 1%, 1206, Reel	MC0125W120611M40
Resistor, 1M4, 0.125W, 1%, 1206	MC0125W120611M40
Resistor, 1R4, 0.125W, 1%, 1206, Reel	MC0125W120611R40
Resistor, 1R4, 0.125W, 1%, 1206	MC0125W120611R40
Resistor, 1K47, 0.125W, 1%, 1206, Reel	MC0125W120611K47
Resistor, 1K47, 0.125W, 1%, 1206	MC0125W120611K47
Resistor, 1M47, 0.125W, 1%, 1206, Reel	MC0125W120611M47
Resistor, 1M47, 0.125W, 1%, 1206	MC0125W120611M47
Resistor, 1R47, 0.125W, 1%, 1206, Reel	MC0125W120611R47
Resistor, 1R47, 0.125W, 1%, 1206	MC0125W120611R47
Resistor, 1K5, 0.125W, 1%, 1206, Reel	MC0125W120611K5
Resistor, 1K5, 0.125W, 1%, 1206	MC0125W120611K5
Resistor, 1M5, 0.125W, 1%, 1206, Reel	MC0125W120611M50
Resistor, 1M5, 0.125W, 1%, 1206	MC0125W120611M50
Resistor, 1R5, 0.125W, 1%, 1206, Reel	MC0125W120611R50
Resistor, 1R5, 0.125W, 1%, 1206	MC0125W120611R5
Resistor, 1R5, 0.125W, 1%, 1206	MC0125W120611R50
Resistor, 1K54, 0.125W, 1%, 1206, Reel	MC0125W120611K54
Resistor, 1K54, 0.125W, 1%, 1206	MC0125W120611K54
Resistor, 1R54, 0.125W, 1%, 1206, Reel	MC0125W120611R54
Resistor, 1R54, 0.125W, 1%, 1206	MC0125W120611R54
Resistor, 1K6, 0.125W, 1%, 1206, Reel	MC0125W120611K6
Resistor, 1K6, 0.125W, 1%, 1206	MC0125W120611K6
Resistor, 1M6, 0.125W, 1%, 1206, Reel	MC0125W120611M60
Resistor, 1M6, 0.125W, 1%, 1206	MC0125W120611M60

Description	Part Number
Resistor, 1R6, 0.125W, 1%, 1206, Reel	MC0125W120611R60
Resistor, 1R6, 0.125W, 1%, 1206	MC0125W120611R60
Resistor, 1K62, 0.125W, 1%, 1206, Reel	MC0125W120611K62
Resistor, 1K62, 0.125W, 1%, 1206	MC0125W120611K62
Resistor, 1M62, 0.125W, 1%, 1206, Reel	MC0125W120611M62
Resistor, 1M62, 0.125W, 1%, 1206	MC0125W120611M62
Resistor, 1R62, 0.125W, 1%, 1206, Reel	MC0125W120611R62
Resistor, 1R62, 0.125W, 1%, 1206	MC0125W120611R62
Resistor, 1K69, 0.125W, 1%, 1206, Reel	MC0125W120611K69
Resistor, 1K69, 0.125W, 1%, 1206	MC0125W120611K69
Resistor, 1M69, 0.125W, 1%, 1206, Reel	MC0125W120611M69
Resistor, 1M69, 0.125W, 1%, 1206	MC0125W120611M69
Resistor, 1R69, 0.125W, 1%, 1206, Reel	MC0125W120611R69
Resistor, 1R69, 0.125W, 1%, 1206	MC0125W120611R69
Resistor, 1K78, 0.125W, 1%, 1206, Reel	MC0125W120611K78
Resistor, 1K78, 0.125W, 1%, 1206	MC0125W120611K78
Resistor, 1M78, 0.125W, 1%, 1206, Reel	MC0125W120611M78
Resistor, 1M78, 0.125W, 1%, 1206	MC0125W120611M78
Resistor, 1R78, 0.125W, 1%, 1206, Reel	MC0125W120611R78
Resistor, 1R78, 0.125W, 1%, 1206	MC0125W120611R78
Resistor, 1K8, 0.125W, 1%, 1206, Reel	MC0125W120611K8
Resistor, 1K8, 0.125W, 1%, 1206	MC0125W120611K8
Resistor, 1M8, 0.125W, 1%, 1206, Reel	MC0125W120611M80
Resistor, 1M8, 0.125W, 1%, 1206	MC0125W120611M80
Resistor, 1R8, 0.125W, 1%, 1206, Reel	MC0125W120611R80
Resistor, 1R8, 0.125W, 1%, 1206	MC0125W120611R80
Resistor, 1K87, 0.125W, 1%, 1206, Reel	MC0125W120611K87
Resistor, 1K87, 0.125W, 1%, 1206	MC0125W120611K87
Resistor, 1R87, 0.125W, 1%, 1206, Reel	MC0125W120611R87
Resistor, 1R87, 0.125W, 1%, 1206	MC0125W120611R87
Resistor, 1K96, 0.125W, 1%, 1206, Reel	MC0125W120611K96
Resistor, 1K96, 0.125W, 1%, 1206	MC0125W120611K96
Resistor, 1R96, 0.125W, 1%, 1206, Reel	MC0125W120611R96
Resistor, 1R96, 0.125W, 1%, 1206	MC0125W120611R96
Resistor, 10K, 0.125W, 1%, 1206, Reel	MC0125W1206110K
Resistor, 10K, 0.125W, 1%, 1206	MC0125W1206110K
Resistor, 10M, 0.125W, 1%, 1206, Reel	MC0125W1206110M0
Resistor, 10M, 0.125W, 1%, 1206	MC0125W1206110M0
Resistor, 10R, 0.125W, 1%, 1206, Reel	MC0125W1206110R

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 10R, 0.125W, 1%, 1206	MC0125W1206110R
Resistor, 10K5, 0.125W, 1%, 1206, Reel	MC0125W1206110K5
Resistor, 10K5, 0.125W, 1%, 1206	MC0125W1206110K5
Resistor, 10R5, 0.125W, 1%, 1206, Reel	MC0125W1206110R5
Resistor, 10R5, 0.125W, 1%, 1206	MC0125W1206110R5
Resistor, 100K, 0.125W, 1%, 1206, Reel	MC0125W12061100K
Resistor, 100K, 0.125W, 1%, 1206	MC0125W12061100K
Resistor, 100R, 0.125W, 1%, 1206, Reel	MC0125W12061100R
Resistor, 100R, 0.125W, 1%, 1206	MC0125W12061100R
Resistor, 105K, 0.125W, 1%, 1206, Reel	MC0125W12061105K
Resistor, 105K, 0.125W, 1%, 1206	MC0125W12061105K
Resistor, 105R, 0.125W, 1%, 1206, Reel	MC0125W12061105R
Resistor, 105R, 0.125W, 1%, 1206	MC0125W12061105R
Resistor, 11K, 0.125W, 1%, 1206, Reel	MC0125W1206111K
Resistor, 11K, 0.125W, 1%, 1206	MC0125W1206111K
Resistor, 11R, 0.125W, 1%, 1206, Reel	MC0125W1206111R
Resistor, 11R, 0.125W, 1%, 1206	MC0125W1206111R
Resistor, 11K5, 0.125W, 1%, 1206, Reel	MC0125W1206111K5
Resistor, 11K5, 0.125W, 1%, 1206	MC0125W1206111K5
Resistor, 11R5, 0.125W, 1%, 1206, Reel	MC0125W1206111R5
Resistor, 11R5, 0.125W, 1%, 1206	MC0125W1206111R5
Resistor, 110K, 0.125W, 1%, 1206, Reel	MC0125W12061110K
Resistor, 110K, 0.125W, 1%, 1206	MC0125W12061110K
Resistor, 110R, 0.125W, 1%, 1206, Reel	MC0125W12061110R
Resistor, 110R, 0.125W, 1%, 1206	MC0125W12061110R
Resistor, 115K, 0.125W, 1%, 1206, Reel	MC0125W12061115K
Resistor, 115K, 0.125W, 1%, 1206	MC0125W12061115K
Resistor, 115R, 0.125W, 1%, 1206, Reel	MC0125W12061115R
Resistor, 115R, 0.125W, 1%, 1206	MC0125W12061115R
Resistor, 12K, 0.125W, 1%, 1206, Reel	MC0125W1206112K
Resistor, 12K, 0.125W, 1%, 1206	MC0125W1206112K
Resistor, 12R, 0.125W, 1%, 1206, Reel	MC0125W1206112R
Resistor, 12R, 0.125W, 1%, 1206	MC0125W1206112R
Resistor, 12K1, 0.125W, 1%, 1206, Reel	MC0125W1206112K1
Resistor, 12K1, 0.125W, 1%, 1206	MC0125W1206112K1
Resistor, 12R1, 0.125W, 1%, 1206, Reel	MC0125W1206112R1
Resistor, 12R1, 0.125W, 1%, 1206	MC0125W1206112R1
Resistor, 12K4, 0.125W, 1%, 1206, Reel	MC0125W1206112K4
Resistor, 12K4, 0.125W, 1%, 1206	MC0125W1206112K4

Description	Part Number
Resistor, 12K7, 0.125W, 1%, 1206, Reel	MC0125W1206112K7
Resistor, 12K7, 0.125W, 1%, 1206	MC0125W1206112K7
Resistor, 12R7, 0.125W, 1%, 1206, Reel	MC0125W1206112R7
Resistor, 12R7, 0.125W, 1%, 1206	MC0125W1206112R7
Resistor, 120K, 0.125W, 1%, 1206, Reel	MC0125W12061120K
Resistor, 120K, 0.125W, 1%, 1206	MC0125W12061120K
Resistor, 120R, 0.125W, 1%, 1206, Reel	MC0125W12061120R
Resistor, 120R, 0.125W, 1%, 1206	MC0125W12061120R
Resistor, 121K, 0.125W, 1%, 1206, Reel	MC0125W12061121K
Resistor, 121K, 0.125W, 1%, 1206	MC0125W12061121K
Resistor, 121R, 0.125W, 1%, 1206, Reel	MC0125W12061121R
Resistor, 121R, 0.125W, 1%, 1206	MC0125W12061121R
Resistor, 127K, 0.125W, 1%, 1206, Reel	MC0125W12061127K
Resistor, 127K, 0.125W, 1%, 1206	MC0125W12061127K
Resistor, 127R, 0.125W, 1%, 1206, Reel	MC0125W12061127R
Resistor, 127R, 0.125W, 1%, 1206	MC0125W12061127R
Resistor, 13K, 0.125W, 1%, 1206, Reel	MC0125W1206113K
Resistor, 13K, 0.125W, 1%, 1206	MC0125W1206113K
Resistor, 13R, 0.125W, 1%, 1206, Reel	MC0125W1206113R0
Resistor, 13R, 0.125W, 1%, 1206	MC0125W1206113R0
Resistor, 13K3, 0.125W, 1%, 1206, Reel	MC0125W1206113K3
Resistor, 13K3, 0.125W, 1%, 1206	MC0125W1206113K3
Resistor, 13R3, 0.125W, 1%, 1206, Reel	MC0125W1206113R3
Resistor, 13R3, 0.125W, 1%, 1206	MC0125W1206113R3
Resistor, 130K, 0.125W, 1%, 1206, Reel	MC0125W12061130K
Resistor, 130K, 0.125W, 1%, 1206	MC0125W12061130K
Resistor, 130R, 0.125W, 1%, 1206, Reel	MC0125W12061130R
Resistor, 130R, 0.125W, 1%, 1206	MC0125W12061130R
Resistor, 133K, 0.125W, 1%, 1206, Reel	MC0125W12061133K
Resistor, 133K, 0.125W, 1%, 1206	MC0125W12061133K
Resistor, 133R, 0.125W, 1%, 1206, Reel	MC0125W12061133R
Resistor, 133R, 0.125W, 1%, 1206	MC0125W12061133R
Resistor, 14K, 0.125W, 1%, 1206, Reel	MC0125W1206114K0
Resistor, 14K, 0.125W, 1%, 1206	MC0125W1206114K0
Resistor, 14R, 0.125W, 1%, 1206, Reel	MC0125W1206114R0
Resistor, 14R, 0.125W, 1%, 1206	MC0125W1206114R0
Resistor, 14K7, 0.125W, 1%, 1206, Reel	MC0125W1206114K7
Resistor, 14K7, 0.125W, 1%, 1206	MC0125W1206114K7
Resistor, 14R7, 0.125W, 1%, 1206, Reel	MC0125W1206114R7

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 14R7, 0.125W, 1%, 1206	MC0125W1206114R7
Resistor, 140K, 0.125W, 1%, 1206, Reel	MC0125W12061140K
Resistor, 140K, 0.125W, 1%, 1206	MC0125W12061140K
Resistor, 140R, 0.125W, 1%, 1206, Reel	MC0125W12061140R
Resistor, 140R, 0.125W, 1%, 1206	MC0125W12061140R
Resistor, 147K, 0.125W, 1%, 1206, Reel	MC0125W12061147K
Resistor, 147K, 0.125W, 1%, 1206	MC0125W12061147K
Resistor, 147R, 0.125W, 1%, 1206, Reel	MC0125W12061147R
Resistor, 147R, 0.125W, 1%, 1206	MC0125W12061147R
Resistor, 15K, 0.125W, 1%, 1206, Reel	MC0125W1206115K
Resistor, 15K, 0.125W, 1%, 1206	MC0125W1206115K
Resistor, 15R, 0.125W, 1%, 1206, Reel	MC0125W1206115R
Resistor, 15R, 0.125W, 1%, 1206	MC0125W1206115R
Resistor, 15K4, 0.125W, 1%, 1206, Reel	MC0125W1206115K4
Resistor, 15K4, 0.125W, 1%, 1206	MC0125W1206115K4
Resistor, 15R4, 0.125W, 1%, 1206, Reel	MC0125W1206115R4
Resistor, 15R4, 0.125W, 1%, 1206	MC0125W1206115R4
Resistor, 150K, 0.125W, 1%, 1206, Reel	MC0125W12061150K
Resistor, 150K, 0.125W, 1%, 1206	MC0125W12061150K
Resistor, 150R, 0.125W, 1%, 1206, Reel	MC0125W12061150R
Resistor, 150R, 0.125W, 1%, 1206	MC0125W12061150R
Resistor, 154R, 0.125W, 1%, 1206, Reel	MC0125W12061154R
Resistor, 154R, 0.125W, 1%, 1206	MC0125W12061154R
Resistor, 16K, 0.125W, 1%, 1206, Reel	MC0125W1206116K
Resistor, 16K, 0.125W, 1%, 1206	MC0125W1206116K
Resistor, 16R, 0.125W, 1%, 1206, Reel	MC0125W1206116R
Resistor, 16R, 0.125W, 1%, 1206	MC0125W1206116R
Resistor, 16K2, 0.125W, 1%, 1206, Reel	MC0125W1206116K2
Resistor, 16K2, 0.125W, 1%, 1206	MC0125W1206116K2
Resistor, 16R2, 0.125W, 1%, 1206, Reel	MC0125W1206116R2
Resistor, 16R2, 0.125W, 1%, 1206	MC0125W1206116R2
Resistor, 16K9, 0.125W, 1%, 1206, Reel	MC0125W1206116K9
Resistor, 16K9, 0.125W, 1%, 1206	MC0125W1206116K9
Resistor, 16R9, 0.125W, 1%, 1206, Reel	MC0125W1206116R9
Resistor, 16R9, 0.125W, 1%, 1206	MC0125W1206116R9
Resistor, 160K, 0.125W, 1%, 1206, Reel	MC0125W12061160K
Resistor, 160K, 0.125W, 1%, 1206	MC0125W12061160K
Resistor, 160R, 0.125W, 1%, 1206, Reel	MC0125W12061160R
Resistor, 160R, 0.125W, 1%, 1206	MC0125W12061160R

Description	Part Number
Resistor, 162K, 0.125W, 1%, 1206, Reel	MC0125W12061162K
Resistor, 162K, 0.125W, 1%, 1206	MC0125W12061162K
Resistor, 162R, 0.125W, 1%, 1206, Reel	MC0125W12061162R
Resistor, 162R, 0.125W, 1%, 1206	MC0125W12061162R
Resistor, 169K, 0.125W, 1%, 1206, Reel	MC0125W12061169K
Resistor, 169K, 0.125W, 1%, 1206	MC0125W12061169K
Resistor, 169R, 0.125W, 1%, 1206, Reel	MC0125W12061169R
Resistor, 169R, 0.125W, 1%, 1206	MC0125W12061169R
Resistor, 17K8, 0.125W, 1%, 1206, Reel	MC0125W1206117K8
Resistor, 17K8, 0.125W, 1%, 1206	MC0125W1206117K8
Resistor, 17R8, 0.125W, 1%, 1206, Reel	MC0125W1206117R8
Resistor, 17R8, 0.125W, 1%, 1206	MC0125W1206117R8
Resistor, 178K, 0.125W, 1%, 1206, Reel	MC0125W12061178K
Resistor, 178K, 0.125W, 1%, 1206	MC0125W12061178K
Resistor, 178R, 0.125W, 1%, 1206, Reel	MC0125W12061178R
Resistor, 178R, 0.125W, 1%, 1206	MC0125W12061178R
Resistor, 18K, 0.125W, 1%, 1206, Reel	MC0125W1206118K
Resistor, 18K, 0.125W, 1%, 1206	MC0125W1206118K
Resistor, 18R, 0.125W, 1%, 1206, Reel	MC0125W1206118R
Resistor, 18R, 0.125W, 1%, 1206	MC0125W1206118R
Resistor, 18K7, 0.125W, 1%, 1206, Reel	MC0125W1206118K7
Resistor, 18K7, 0.125W, 1%, 1206	MC0125W1206118K7
Resistor, 18R7, 0.125W, 1%, 1206, Reel	MC0125W1206118R7
Resistor, 18R7, 0.125W, 1%, 1206	MC0125W1206118R7
Resistor, 180K, 0.125W, 1%, 1206, Reel	MC0125W12061180K
Resistor, 180K, 0.125W, 1%, 1206	MC0125W12061180K
Resistor, 180R, 0.125W, 1%, 1206, Reel	MC0125W12061180R
Resistor, 180R, 0.125W, 1%, 1206	MC0125W12061180R
Resistor, 187K, 0.125W, 1%, 1206, Reel	MC0125W12061187K
Resistor, 187K, 0.125W, 1%, 1206	MC0125W12061187K
Resistor, 187R, 0.125W, 1%, 1206, Reel	MC0125W12061187R
Resistor, 187R, 0.125W, 1%, 1206	MC0125W12061187R
Resistor, 19K6, 0.125W, 1%, 1206, Reel	MC0125W1206119K6
Resistor, 19K6, 0.125W, 1%, 1206	MC0125W1206119K6
Resistor, 19R6, 0.125W, 1%, 1206, Reel	MC0125W1206119R6
Resistor, 19R6, 0.125W, 1%, 1206	MC0125W1206119R6
Resistor, 196R, 0.125W, 1%, 1206, Reel	MC0125W12061196R
Resistor, 196R, 0.125W, 1%, 1206	MC0125W12061196R
Resistor, 2K, 0.125W, 1%, 1206, Reel	MC0125W120612K

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 2K, 0.125W, 1%, 1206	MC0125W120612K
Resistor, 2M, 0.125W, 1%, 1206, Reel	MC0125W120612M00
Resistor, 2M, 0.125W, 1%, 1206	MC0125W120612M00
Resistor, 2R, 0.125W, 1%, 1206, Reel	MC0125W120612R0
Resistor, 2R, 0.125W, 1%, 1206	MC0125W120612R0
Resistor, 2K05, 0.125W, 1%, 1206, Reel	MC0125W120612K05
Resistor, 2K05, 0.125W, 1%, 1206	MC0125W120612K05
Resistor, 2K15, 0.125W, 1%, 1206, Reel	MC0125W120612K15
Resistor, 2K15, 0.125W, 1%, 1206	MC0125W120612K15
Resistor, 2R15, 0.125W, 1%, 1206, Reel	MC0125W120612R15
Resistor, 2R15, 0.125W, 1%, 1206	MC0125W120612R15
Resistor, 2K2, 0.125W, 1%, 1206, Reel	MC0125W120612K2
Resistor, 2K2, 0.125W, 1%, 1206	MC0125W120612K2
Resistor, 2M2, 0.125W, 1%, 1206, Reel	MC0125W120612M20
Resistor, 2M2, 0.125W, 1%, 1206	MC0125W120612M20
Resistor, 2R2, 0.125W, 1%, 1206, Reel	MC0125W120612R20
Resistor, 2R2, 0.125W, 1%, 1206	MC0125W120612R20
Resistor, 2K26, 0.125W, 1%, 1206, Reel	MC0125W120612K26
Resistor, 2K26, 0.125W, 1%, 1206	MC0125W120612K26
Resistor, 2M26, 0.125W, 1%, 1206, Reel	MC0125W120612M26
Resistor, 2M26, 0.125W, 1%, 1206	MC0125W120612M26
Resistor, 2R26, 0.125W, 1%, 1206, Reel	MC0125W120612R26
Resistor, 2R26, 0.125W, 1%, 1206	MC0125W120612R26
Resistor, 2K37, 0.125W, 1%, 1206, Reel	MC0125W120612K37
Resistor, 2K37, 0.125W, 1%, 1206	MC0125W120612K37
Resistor, 2R37, 0.125W, 1%, 1206, Reel	MC0125W120612R37
Resistor, 2R37, 0.125W, 1%, 1206	MC0125W120612R37
Resistor, 2K4, 0.125W, 1%, 1206, Reel	MC0125W120612K4
Resistor, 2K4, 0.125W, 1%, 1206	MC0125W120612K4
Resistor, 2M4, 0.125W, 1%, 1206, Reel	MC0125W120612M40
Resistor, 2M4, 0.125W, 1%, 1206	MC0125W120612M40
Resistor, 2R4, 0.125W, 1%, 1206, Reel	MC0125W120612R40
Resistor, 2R4, 0.125W, 1%, 1206	MC0125W120612R40
Resistor, 2K49, 0.125W, 1%, 1206, Reel	MC0125W120612K49
Resistor, 2K49, 0.125W, 1%, 1206	MC0125W120612K49
Resistor, 2R49, 0.125W, 1%, 1206, Reel	MC0125W120612R49
Resistor, 2R49, 0.125W, 1%, 1206	MC0125W120612R49
Resistor, 2K61, 0.125W, 1%, 1206, Reel	MC0125W120612K61
Resistor, 2K61, 0.125W, 1%, 1206	MC0125W120612K61

Description	Part Number
Resistor, 2M61, 0.125W, 1%, 1206, Reel	MC0125W120612M61
Resistor, 2M61, 0.125W, 1%, 1206	MC0125W120612M61
Resistor, 2R61, 0.125W, 1%, 1206, Reel	MC0125W120612R61
Resistor, 2R61, 0.125W, 1%, 1206	MC0125W120612R61
Resistor, 2K7, 0.125W, 1%, 1206, Reel	MC0125W120612K7
Resistor, 2K7, 0.125W, 1%, 1206	MC0125W120612K7
Resistor, 2M7, 0.125W, 1%, 1206, Reel	MC0125W120612M70
Resistor, 2M7, 0.125W, 1%, 1206	MC0125W120612M70
Resistor, 2R7, 0.125W, 1%, 1206, Reel	MC0125W120612R70
Resistor, 2R7, 0.125W, 1%, 1206	MC0125W120612R70
Resistor, 2K74, 0.125W, 1%, 1206, Reel	MC0125W120612K74
Resistor, 2K74, 0.125W, 1%, 1206	MC0125W120612K74
Resistor, 2M74, 0.125W, 1%, 1206, Reel	MC0125W120612M74
Resistor, 2M74, 0.125W, 1%, 1206	MC0125W120612M74
Resistor, 2R74, 0.125W, 1%, 1206, Reel	MC0125W120612R74
Resistor, 2R74, 0.125W, 1%, 1206	MC0125W120612R74
Resistor, 2K87, 0.125W, 1%, 1206, Reel	MC0125W120612K87
Resistor, 2K87, 0.125W, 1%, 1206	MC0125W120612K87
Resistor, 2M87, 0.125W, 1%, 1206, Reel	MC0125W120612M87
Resistor, 2M87, 0.125W, 1%, 1206	MC0125W120612M87
Resistor, 2R87, 0.125W, 1%, 1206, Reel	MC0125W120612R87
Resistor, 2R87, 0.125W, 1%, 1206	MC0125W120612R87
Resistor, 20K, 0.125W, 1%, 1206, Reel	MC0125W1206120K
Resistor, 20K, 0.125W, 1%, 1206	MC0125W1206120K
Resistor, 20R, 0.125W, 1%, 1206, Reel	MC0125W1206120R
Resistor, 20R, 0.125W, 1%, 1206	MC0125W1206120R
Resistor, 20K5, 0.125W, 1%, 1206, Reel	MC0125W1206120K5
Resistor, 20K5, 0.125W, 1%, 1206	MC0125W1206120K5
Resistor, 20R5, 0.125W, 1%, 1206, Reel	MC0125W1206120R5
Resistor, 20R5, 0.125W, 1%, 1206	MC0125W1206120R5
Resistor, 200K, 0.125W, 1%, 1206, Reel	MC0125W12061200K
Resistor, 200K, 0.125W, 1%, 1206	MC0125W12061200K
Resistor, 200R, 0.125W, 1%, 1206, Reel	MC0125W12061200R
Resistor, 200R, 0.125W, 1%, 1206	MC0125W12061200R
Resistor, 205K, 0.125W, 1%, 1206, Reel	MC0125W12061205K
Resistor, 205K, 0.125W, 1%, 1206	MC0125W12061205K
Resistor, 205R, 0.125W, 1%, 1206, Reel	MC0125W12061205R
Resistor, 205R, 0.125W, 1%, 1206	MC0125W12061205R
Resistor, 21K5, 0.125W, 1%, 1206, Reel	MC0125W1206121K5

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 21K5, 0.125W, 1%, 1206	MC0125W1206121K5
Resistor, 21R5, 0.125W, 1%, 1206, Reel	MC0125W1206121R5
Resistor, 21R5, 0.125W, 1%, 1206	MC0125W1206121R5
Resistor, 215K, 0.125W, 1%, 1206, Reel	MC0125W12061215K
Resistor, 215K, 0.125W, 1%, 1206	MC0125W12061215K
Resistor, 215R, 0.125W, 1%, 1206, Reel	MC0125W12061215R
Resistor, 215R, 0.125W, 1%, 1206	MC0125W12061215R
Resistor, 22K, 0.125W, 1%, 1206, Reel	MC0125W1206122K
Resistor, 22K, 0.125W, 1%, 1206	MC0125W1206122K
Resistor, 22R, 0.125W, 1%, 1206, Reel	MC0125W1206122R
Resistor, 22R, 0.125W, 1%, 1206	MC0125W1206122R
Resistor, 22K6, 0.125W, 1%, 1206, Reel	MC0125W1206122K6
Resistor, 22K6, 0.125W, 1%, 1206	MC0125W1206122K6
Resistor, 22R6, 0.125W, 1%, 1206, Reel	MC0125W1206122R6
Resistor, 22R6, 0.125W, 1%, 1206	MC0125W1206122R6
Resistor, 220K, 0.125W, 1%, 1206, Reel	MC0125W12061220K
Resistor, 220K, 0.125W, 1%, 1206	MC0125W12061220K
Resistor, 220R, 0.125W, 1%, 1206, Reel	MC0125W12061220R
Resistor, 220R, 0.125W, 1%, 1206	MC0125W12061220R
Resistor, 226K, 0.125W, 1%, 1206, Reel	MC0125W12061226K
Resistor, 226K, 0.125W, 1%, 1206	MC0125W12061226K
Resistor, 226R, 0.125W, 1%, 1206, Reel	MC0125W12061226R
Resistor, 226R, 0.125W, 1%, 1206	MC0125W12061226R
Resistor, 23K7, 0.125W, 1%, 1206, Reel	MC0125W1206123K7
Resistor, 23K7, 0.125W, 1%, 1206	MC0125W1206123K7
Resistor, 23R7, 0.125W, 1%, 1206, Reel	MC0125W1206123R7
Resistor, 23R7, 0.125W, 1%, 1206	MC0125W1206123R7
Resistor, 237K, 0.125W, 1%, 1206, Reel	MC0125W12061237K
Resistor, 237K, 0.125W, 1%, 1206	MC0125W12061237K
Resistor, 237R, 0.125W, 1%, 1206, Reel	MC0125W12061237R
Resistor, 237R, 0.125W, 1%, 1206	MC0125W12061237R
Resistor, 24K, 0.125W, 1%, 1206, Reel	MC0125W1206124K
Resistor, 24K, 0.125W, 1%, 1206	MC0125W1206124K
Resistor, 24R, 0.125W, 1%, 1206, Reel	MC0125W1206124R
Resistor, 24R, 0.125W, 1%, 1206	MC0125W1206124R
Resistor, 24K9, 0.125W, 1%, 1206, Reel	MC0125W1206124K9
Resistor, 24K9, 0.125W, 1%, 1206	MC0125W1206124K9
Resistor, 24R9, 0.125W, 1%, 1206, Reel	MC0125W1206124R9
Resistor, 24R9, 0.125W, 1%, 1206	MC0125W1206124R9

Description	Part Number
Resistor, 240K, 0.125W, 1%, 1206, Reel	MC0125W12061240K
Resistor, 240K, 0.125W, 1%, 1206	MC0125W12061240K
Resistor, 240R, 0.125W, 1%, 1206, Reel	MC0125W12061240R
Resistor, 240R, 0.125W, 1%, 1206	MC0125W12061240R
Resistor, 249K, 0.125W, 1%, 1206, Reel	MC0125W12061249K
Resistor, 249K, 0.125W, 1%, 1206	MC0125W12061249K
Resistor, 249R, 0.125W, 1%, 1206, Reel	MC0125W12061249R
Resistor, 249R, 0.125W, 1%, 1206	MC0125W12061249R
Resistor, 26K1, 0.125W, 1%, 1206, Reel	MC0125W1206126K1
Resistor, 26K1, 0.125W, 1%, 1206	MC0125W1206126K1
Resistor, 26R1, 0.125W, 1%, 1206, Reel	MC0125W1206126R1
Resistor, 26R1, 0.125W, 1%, 1206	MC0125W1206126R1
Resistor, 261K, 0.125W, 1%, 1206, Reel	MC0125W12061261K
Resistor, 261K, 0.125W, 1%, 1206	MC0125W12061261K
Resistor, 261R, 0.125W, 1%, 1206, Reel	MC0125W12061261R
Resistor, 261R, 0.125W, 1%, 1206	MC0125W12061261R
Resistor, 27K, 0.125W, 1%, 1206, Reel	MC0125W1206127K
Resistor, 27K, 0.125W, 1%, 1206	MC0125W1206127K
Resistor, 27R, 0.125W, 1%, 1206, Reel	MC0125W1206127R
Resistor, 27R, 0.125W, 1%, 1206	MC0125W1206127R
Resistor, 27K4, 0.125W, 1%, 1206, Reel	MC0125W1206127K4
Resistor, 27K4, 0.125W, 1%, 1206	MC0125W1206127K4
Resistor, 27R4, 0.125W, 1%, 1206, Reel	MC0125W1206127R4
Resistor, 27R4, 0.125W, 1%, 1206	MC0125W1206127R4
Resistor, 270K, 0.125W, 1%, 1206, Reel	MC0125W12061270K
Resistor, 270K, 0.125W, 1%, 1206	MC0125W12061270K
Resistor, 270R, 0.125W, 1%, 1206, Reel	MC0125W12061270R
Resistor, 270R, 0.125W, 1%, 1206	MC0125W12061270R
Resistor, 274K, 0.125W, 1%, 1206, Reel	MC0125W12061274K
Resistor, 274K, 0.125W, 1%, 1206	MC0125W12061274K
Resistor, 274R, 0.125W, 1%, 1206, Reel	MC0125W12061274R
Resistor, 274R, 0.125W, 1%, 1206	MC0125W12061274R
Resistor, 28K7, 0.125W, 1%, 1206, Reel	MC0125W1206128K7
Resistor, 28K7, 0.125W, 1%, 1206	MC0125W1206128K7
Resistor, 28R7, 0.125W, 1%, 1206, Reel	MC0125W1206128R7
Resistor, 28R7, 0.125W, 1%, 1206	MC0125W1206128R7
Resistor, 287K, 0.125W, 1%, 1206, Reel	MC0125W12061287K
Resistor, 287K, 0.125W, 1%, 1206	MC0125W12061287K
Resistor, 287R, 0.125W, 1%, 1206, Reel	MC0125W12061287R

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 287R, 0.125W, 1%, 1206	MC0125W12061287R
Resistor, 3K, 0.125W, 1%, 1206, Reel	MC0125W120613K
Resistor, 3K, 0.125W, 1%, 1206	MC0125W120613K
Resistor, 3M, 0.125W, 1%, 1206, Reel	MC0125W120613M00
Resistor, 3M, 0.125W, 1%, 1206	MC0125W120613M00
Resistor, 3R, 0.125W, 1%, 1206, Reel	MC0125W120613R0
Resistor, 3R, 0.125W, 1%, 1206	MC0125W120613R0
Resistor, 3K01, 0.125W, 1%, 1206, Reel	MC0125W120613K01
Resistor, 3K01, 0.125W, 1%, 1206	MC0125W120613K01
Resistor, 3M01, 0.125W, 1%, 1206, Reel	MC0125W120613M01
Resistor, 3M01, 0.125W, 1%, 1206	MC0125W120613M01
Resistor, 3K16, 0.125W, 1%, 1206, Reel	MC0125W120613K16
Resistor, 3K16, 0.125W, 1%, 1206	MC0125W120613K16
Resistor, 3M16, 0.125W, 1%, 1206, Reel	MC0125W120613M16
Resistor, 3M16, 0.125W, 1%, 1206	MC0125W120613M16
Resistor, 3R16, 0.125W, 1%, 1206, Reel	MC0125W120613R16
Resistor, 3R16, 0.125W, 1%, 1206	MC0125W120613R16
Resistor, 3K3, 0.125W, 1%, 1206, Reel	MC0125W120613K3
Resistor, 3K3, 0.125W, 1%, 1206	MC0125W120613K3
Resistor, 3M3, 0.125W, 1%, 1206, Reel	MC0125W120613M30
Resistor, 3M3, 0.125W, 1%, 1206	MC0125W120613M30
Resistor, 3R3, 0.125W, 1%, 1206, Reel	MC0125W120613R30
Resistor, 3R3, 0.125W, 1%, 1206	MC0125W120613R30
Resistor, 3K32, 0.125W, 1%, 1206, Reel	MC0125W120613K32
Resistor, 3K32, 0.125W, 1%, 1206	MC0125W120613K32
Resistor, 3M32, 0.125W, 1%, 1206, Reel	MC0125W120613M32
Resistor, 3M32, 0.125W, 1%, 1206	MC0125W120613M32
Resistor, 3R32, 0.125W, 1%, 1206, Reel	MC0125W120613R32
Resistor, 3R32, 0.125W, 1%, 1206	MC0125W120613R32
Resistor, 3K48, 0.125W, 1%, 1206, Reel	MC0125W120613K48
Resistor, 3K48, 0.125W, 1%, 1206	MC0125W120613K48
Resistor, 3M48, 0.125W, 1%, 1206, Reel	MC0125W120613M48
Resistor, 3M48, 0.125W, 1%, 1206	MC0125W120613M48
Resistor, 3R48, 0.125W, 1%, 1206, Reel	MC0125W120613R48
Resistor, 3R48, 0.125W, 1%, 1206	MC0125W120613R48
Resistor, 3K6, 0.125W, 1%, 1206, Reel	MC0125W120613K6
Resistor, 3K6, 0.125W, 1%, 1206	MC0125W120613K6
Resistor, 3M6, 0.125W, 1%, 1206, Reel	MC0125W120613M60
Resistor, 3M6, 0.125W, 1%, 1206	MC0125W120613M60

Description	Part Number
Resistor, 3R6, 0.125W, 1%, 1206, Reel	MC0125W120613R60
Resistor, 3R6, 0.125W, 1%, 1206	MC0125W120613R60
Resistor, 3K65, 0.125W, 1%, 1206, Reel	MC0125W120613K65
Resistor, 3K65, 0.125W, 1%, 1206	MC0125W120613K65
Resistor, 3M65, 0.125W, 1%, 1206, Reel	MC0125W120613M65
Resistor, 3M65, 0.125W, 1%, 1206	MC0125W120613M65
Resistor, 3R65, 0.125W, 1%, 1206, Reel	MC0125W120613R65
Resistor, 3R65, 0.125W, 1%, 1206	MC0125W120613R65
Resistor, 3K83, 0.125W, 1%, 1206, Reel	MC0125W120613K83
Resistor, 3K83, 0.125W, 1%, 1206	MC0125W120613K83
Resistor, 3M83, 0.125W, 1%, 1206, Reel	MC0125W120613M83
Resistor, 3M83, 0.125W, 1%, 1206	MC0125W120613M83
Resistor, 3K9, 0.125W, 1%, 1206, Reel	MC0125W120613K9
Resistor, 3K9, 0.125W, 1%, 1206	MC0125W120613K9
Resistor, 3M9, 0.125W, 1%, 1206, Reel	MC0125W120613M90
Resistor, 3M9, 0.125W, 1%, 1206	MC0125W120613M90
Resistor, 3R9, 0.125W, 1%, 1206, Reel	MC0125W120613R90
Resistor, 3R9, 0.125W, 1%, 1206	MC0125W120613R90
Resistor, 30K, 0.125W, 1%, 1206, Reel	MC0125W1206130K
Resistor, 30K, 0.125W, 1%, 1206	MC0125W1206130K
Resistor, 30R, 0.125W, 1%, 1206, Reel	MC0125W1206130R
Resistor, 30R, 0.125W, 1%, 1206	MC0125W1206130R
Resistor, 30K1, 0.125W, 1%, 1206, Reel	MC0125W1206130K1
Resistor, 30K1, 0.125W, 1%, 1206	MC0125W1206130K1
Resistor, 30R1, 0.125W, 1%, 1206, Reel	MC0125W1206130R1
Resistor, 30R1, 0.125W, 1%, 1206	MC0125W1206130R1
Resistor, 300K, 0.125W, 1%, 1206, Reel	MC0125W12061300K
Resistor, 300K, 0.125W, 1%, 1206	MC0125W12061300K
Resistor, 300R, 0.125W, 1%, 1206, Reel	MC0125W12061300R
Resistor, 300R, 0.125W, 1%, 1206	MC0125W12061300R
Resistor, 301K, 0.125W, 1%, 1206, Reel	MC0125W12061301K
Resistor, 301K, 0.125W, 1%, 1206	MC0125W12061301K
Resistor, 301R, 0.125W, 1%, 1206, Reel	MC0125W12061301R
Resistor, 301R, 0.125W, 1%, 1206	MC0125W12061301R
Resistor, 31K6, 0.125W, 1%, 1206, Reel	MC0125W1206131K6
Resistor, 31K6, 0.125W, 1%, 1206	MC0125W1206131K6
Resistor, 31R6, 0.125W, 1%, 1206, Reel	MC0125W1206131R6
Resistor, 31R6, 0.125W, 1%, 1206	MC0125W1206131R6
Resistor, 316K, 0.125W, 1%, 1206, Reel	MC0125W12061316K

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 316K, 0.125W, 1%, 1206	MC0125W12061316K
Resistor, 316R, 0.125W, 1%, 1206, Reel	MC0125W12061316R
Resistor, 316R, 0.125W, 1%, 1206	MC0125W12061316R
Resistor, 33K, 0.125W, 1%, 1206, Reel	MC0125W1206133K
Resistor, 33K, 0.125W, 1%, 1206	MC0125W1206133K
Resistor, 33R, 0.125W, 1%, 1206, Reel	MC0125W1206133R
Resistor, 33R, 0.125W, 1%, 1206	MC0125W1206133R
Resistor, 33K2, 0.125W, 1%, 1206, Reel	MC0125W1206133K2
Resistor, 33K2, 0.125W, 1%, 1206	MC0125W1206133K2
Resistor, 33R2, 0.125W, 1%, 1206, Reel	MC0125W1206133R2
Resistor, 33R2, 0.125W, 1%, 1206	MC0125W1206133R2
Resistor, 330K, 0.125W, 1%, 1206, Reel	MC0125W12061330K
Resistor, 330K, 0.125W, 1%, 1206	MC0125W12061330K
Resistor, 330R, 0.125W, 1%, 1206, Reel	MC0125W12061330R
Resistor, 330R, 0.125W, 1%, 1206	MC0125W12061330R
Resistor, 332K, 0.125W, 1%, 1206, Reel	MC0125W12061332K
Resistor, 332K, 0.125W, 1%, 1206	MC0125W12061332K
Resistor, 332R, 0.125W, 1%, 1206, Reel	MC0125W12061332R
Resistor, 332R, 0.125W, 1%, 1206	MC0125W12061332R
Resistor, 34K8, 0.125W, 1%, 1206, Reel	MC0125W1206134K8
Resistor, 34K8, 0.125W, 1%, 1206	MC0125W1206134K8
Resistor, 34R8, 0.125W, 1%, 1206, Reel	MC0125W1206134R8
Resistor, 34R8, 0.125W, 1%, 1206	MC0125W1206134R8
Resistor, 348K, 0.125W, 1%, 1206, Reel	MC0125W12061348K
Resistor, 348K, 0.125W, 1%, 1206	MC0125W12061348K
Resistor, 348R, 0.125W, 1%, 1206, Reel	MC0125W12061348R
Resistor, 348R, 0.125W, 1%, 1206	MC0125W12061348R
Resistor, 36K, 0.125W, 1%, 1206, Reel	MC0125W1206136K
Resistor, 36K, 0.125W, 1%, 1206	MC0125W1206136K
Resistor, 36R, 0.125W, 1%, 1206, Reel	MC0125W1206136R
Resistor, 36R, 0.125W, 1%, 1206	MC0125W1206136R
Resistor, 36K5, 0.125W, 1%, 1206, Reel	MC0125W1206136K5
Resistor, 36K5, 0.125W, 1%, 1206	MC0125W1206136K5
Resistor, 36R5, 0.125W, 1%, 1206, Reel	MC0125W1206136R5
Resistor, 36R5, 0.125W, 1%, 1206	MC0125W1206136R5
Resistor, 360K, 0.125W, 1%, 1206, Reel	MC0125W12061360K
Resistor, 360K, 0.125W, 1%, 1206	MC0125W12061360K
Resistor, 360R, 0.125W, 1%, 1206, Reel	MC0125W12061360R
Resistor, 360R, 0.125W, 1%, 1206	MC0125W12061360R

Description	Part Number
Resistor, 365K, 0.125W, 1%, 1206, Reel	MC0125W12061365K
Resistor, 365K, 0.125W, 1%, 1206	MC0125W12061365K
Resistor, 365R, 0.125W, 1%, 1206, Reel	MC0125W12061365R
Resistor, 365R, 0.125W, 1%, 1206	MC0125W12061365R
Resistor, 38K3, 0.125W, 1%, 1206, Reel	MC0125W1206138K3
Resistor, 38K3, 0.125W, 1%, 1206	MC0125W1206138K3
Resistor, 38R3, 0.125W, 1%, 1206, Reel	MC0125W1206138R3
Resistor, 38R3, 0.125W, 1%, 1206	MC0125W1206138R3
Resistor, 383K, 0.125W, 1%, 1206, Reel	MC0125W12061383K
Resistor, 383K, 0.125W, 1%, 1206	MC0125W12061383K
Resistor, 383R, 0.125W, 1%, 1206, Reel	MC0125W12061383R
Resistor, 383R, 0.125W, 1%, 1206	MC0125W12061383R
Resistor, 39K, 0.125W, 1%, 1206, Reel	MC0125W1206139K
Resistor, 39K, 0.125W, 1%, 1206	MC0125W1206139K
Resistor, 39R, 0.125W, 1%, 1206, Reel	MC0125W1206139R
Resistor, 39R, 0.125W, 1%, 1206	MC0125W1206139R
Resistor, 390K, 0.125W, 1%, 1206, Reel	MC0125W12061390K
Resistor, 390K, 0.125W, 1%, 1206	MC0125W12061390K
Resistor, 390R, 0.125W, 1%, 1206, Reel	MC0125W12061390R
Resistor, 390R, 0.125W, 1%, 1206	MC0125W12061390R
Resistor, 4K02, 0.125W, 1%, 1206, Reel	MC0125W120614K02
Resistor, 4K02, 0.125W, 1%, 1206	MC0125W120614K02
Resistor, 4M02, 0.125W, 1%, 1206, Reel	MC0125W120614M02
Resistor, 4M02, 0.125W, 1%, 1206	MC0125W120614M02
Resistor, 4K22, 0.125W, 1%, 1206, Reel	MC0125W120614K22
Resistor, 4K22, 0.125W, 1%, 1206	MC0125W120614K22
Resistor, 4R22, 0.125W, 1%, 1206, Reel	MC0125W120614R22
Resistor, 4R22, 0.125W, 1%, 1206	MC0125W120614R22
Resistor, 4K3, 0.125W, 1%, 1206, Reel	MC0125W120614K3
Resistor, 4K3, 0.125W, 1%, 1206	MC0125W120614K3
Resistor, 4M3, 0.125W, 1%, 1206, Reel	MC0125W120614M30
Resistor, 4M3, 0.125W, 1%, 1206	MC0125W120614M30
Resistor, 4R3, 0.125W, 1%, 1206, Reel	MC0125W120614R30
Resistor, 4R3, 0.125W, 1%, 1206	MC0125W120614R30
Resistor, 4K42, 0.125W, 1%, 1206, Reel	MC0125W120614K42
Resistor, 4K42, 0.125W, 1%, 1206	MC0125W120614K42
Resistor, 4R42, 0.125W, 1%, 1206, Reel	MC0125W120614R42
Resistor, 4R42, 0.125W, 1%, 1206	MC0125W120614R42
Resistor, 4K64, 0.125W, 1%, 1206, Reel	MC0125W120614K64

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 4K64, 0.125W, 1%, 1206	MC0125W120614K64
Resistor, 4R64, 0.125W, 1%, 1206, Reel	MC0125W120614R64
Resistor, 4R64, 0.125W, 1%, 1206	MC0125W120614R64
Resistor, 4K7, 0.125W, 1%, 1206, Reel	MC0125W120614K7
Resistor, 4K7, 0.125W, 1%, 1206	MC0125W120614K7
Resistor, 4M7, 0.125W, 1%, 1206, Reel	MC0125W120614M70
Resistor, 4M7, 0.125W, 1%, 1206	MC0125W120614M70
Resistor, 4R7, 0.125W, 1%, 1206, Reel	MC0125W120614R70
Resistor, 4R7, 0.125W, 1%, 1206	MC0125W120614R70
Resistor, 4K75, 0.125W, 1%, 1206, Reel	MC0125W120614K75
Resistor, 4K75, 0.125W, 1%, 1206	MC0125W120614K75
Resistor, 4K87, 0.125W, 1%, 1206, Reel	MC0125W120614K87
Resistor, 4K87, 0.125W, 1%, 1206	MC0125W120614K87
Resistor, 4M87, 0.125W, 1%, 1206, Reel	MC0125W120614M87
Resistor, 4M87, 0.125W, 1%, 1206	MC0125W120614M87
Resistor, 4K99, 0.125W, 1%, 1206, Reel	MC0125W120614K99
Resistor, 4K99, 0.125W, 1%, 1206	MC0125W120614K99
Resistor, 40K2, 0.125W, 1%, 1206, Reel	MC0125W1206140K2
Resistor, 40K2, 0.125W, 1%, 1206	MC0125W1206140K2
Resistor, 40R2, 0.125W, 1%, 1206, Reel	MC0125W1206140R2
Resistor, 40R2, 0.125W, 1%, 1206	MC0125W1206140R2
Resistor, 402K, 0.125W, 1%, 1206, Reel	MC0125W12061402K
Resistor, 402K, 0.125W, 1%, 1206	MC0125W12061402K
Resistor, 402R, 0.125W, 1%, 1206, Reel	MC0125W12061402R
Resistor, 402R, 0.125W, 1%, 1206	MC0125W12061402R
Resistor, 42K2, 0.125W, 1%, 1206, Reel	MC0125W1206142K2
Resistor, 42K2, 0.125W, 1%, 1206	MC0125W1206142K2
Resistor, 42R2, 0.125W, 1%, 1206, Reel	MC0125W1206142R2
Resistor, 42R2, 0.125W, 1%, 1206	MC0125W1206142R2
Resistor, 422K, 0.125W, 1%, 1206, Reel	MC0125W12061422K
Resistor, 422K, 0.125W, 1%, 1206	MC0125W12061422K
Resistor, 422R, 0.125W, 1%, 1206, Reel	MC0125W12061422R
Resistor, 422R, 0.125W, 1%, 1206	MC0125W12061422R
Resistor, 43K, 0.125W, 1%, 1206, Reel	MC0125W1206143K
Resistor, 43K, 0.125W, 1%, 1206	MC0125W1206143K
Resistor, 43R, 0.125W, 1%, 1206, Reel	MC0125W1206143R0
Resistor, 43R, 0.125W, 1%, 1206	MC0125W1206143R0
Resistor, 430K, 0.125W, 1%, 1206, Reel	MC0125W12061430K
Resistor, 430K, 0.125W, 1%, 1206	MC0125W12061430K

Description	Part Number
Resistor, 430R, 0.125W, 1%, 1206, Reel	MC0125W12061430R
Resistor, 430R, 0.125W, 1%, 1206	MC0125W12061430R
Resistor, 44K2, 0.125W, 1%, 1206, Reel	MC0125W1206144K2
Resistor, 44K2, 0.125W, 1%, 1206	MC0125W1206144K2
Resistor, 44R2, 0.125W, 1%, 1206, Reel	MC0125W1206144R2
Resistor, 44R2, 0.125W, 1%, 1206	MC0125W1206144R2
Resistor, 442K, 0.125W, 1%, 1206, Reel	MC0125W12061442K
Resistor, 442K, 0.125W, 1%, 1206	MC0125W12061442K
Resistor, 442R, 0.125W, 1%, 1206, Reel	MC0125W12061442R
Resistor, 442R, 0.125W, 1%, 1206	MC0125W12061442R
Resistor, 46K4, 0.125W, 1%, 1206, Reel	MC0125W1206146K4
Resistor, 46K4, 0.125W, 1%, 1206	MC0125W1206146K4
Resistor, 46R4, 0.125W, 1%, 1206, Reel	MC0125W1206146R4
Resistor, 46R4, 0.125W, 1%, 1206	MC0125W1206146R4
Resistor, 464K, 0.125W, 1%, 1206, Reel	MC0125W12061464K
Resistor, 464K, 0.125W, 1%, 1206	MC0125W12061464K
Resistor, 464R, 0.125W, 1%, 1206, Reel	MC0125W12061464R
Resistor, 464R, 0.125W, 1%, 1206	MC0125W12061464R
Resistor, 47K, 0.125W, 1%, 1206, Reel	MC0125W1206147K
Resistor, 47K, 0.125W, 1%, 1206	MC0125W1206147K
Resistor, 47R, 0.125W, 1%, 1206, Reel	MC0125W1206147R
Resistor, 47R, 0.125W, 1%, 1206	MC0125W1206147R
Resistor, 47K5, 0.125W, 1%, 1206, Reel	MC0125W1206147K5
Resistor, 47K5, 0.125W, 1%, 1206	MC0125W1206147K5
Resistor, 470K, 0.125W, 1%, 1206, Reel	MC0125W12061470K
Resistor, 470K, 0.125W, 1%, 1206	MC0125W12061470K
Resistor, 470R, 0.125W, 1%, 1206, Reel	MC0125W12061470R
Resistor, 470R, 0.125W, 1%, 1206	MC0125W12061470R
Resistor, 475R, 0.125W, 1%, 1206, Reel	MC0125W12061475R
Resistor, 475R, 0.125W, 1%, 1206	MC0125W12061475R
Resistor, 48K7, 0.125W, 1%, 1206, Reel	MC0125W1206148K7
Resistor, 48K7, 0.125W, 1%, 1206	MC0125W1206148K7
Resistor, 48R7, 0.125W, 1%, 1206, Reel	MC0125W1206148R7
Resistor, 48R7, 0.125W, 1%, 1206	MC0125W1206148R7
Resistor, 487K, 0.125W, 1%, 1206, Reel	MC0125W12061487K
Resistor, 487K, 0.125W, 1%, 1206	MC0125W12061487K
Resistor, 487R, 0.125W, 1%, 1206, Reel	MC0125W12061487R
Resistor, 487R, 0.125W, 1%, 1206	MC0125W12061487R
Resistor, 49K9, 0.125W, 1%, 1206, Reel	MC0125W1206149K9

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 49K9, 0.125W, 1%, 1206	MC0125W1206149K9
Resistor, 49R9, 0.125W, 1%, 1206, Reel	MC0125W1206149R9
Resistor, 49R9, 0.125W, 1%, 1206	MC0125W1206149R9
Resistor, 499K, 0.125W, 1%, 1206, Reel	MC0125W12061499K
Resistor, 499K, 0.125W, 1%, 1206	MC0125W12061499K
Resistor, 5K1, 0.125W, 1%, 1206, Reel	MC0125W120615K1
Resistor, 5K1, 0.125W, 1%, 1206	MC0125W120615K1
Resistor, 5M1, 0.125W, 1%, 1206, Reel	MC0125W120615M10
Resistor, 5M1, 0.125W, 1%, 1206	MC0125W120615M10
Resistor, 5R1, 0.125W, 1%, 1206, Reel	MC0125W120615R10
Resistor, 5R1, 0.125W, 1%, 1206	MC0125W120615R10
Resistor, 5K11, 0.125W, 1%, 1206, Reel	MC0125W120615K11
Resistor, 5K11, 0.125W, 1%, 1206	MC0125W120615K11
Resistor, 5M11, 0.125W, 1%, 1206, Reel	MC0125W120615M11
Resistor, 5M11, 0.125W, 1%, 1206	MC0125W120615M11
Resistor, 5R11, 0.125W, 1%, 1206, Reel	MC0125W120615R11
Resistor, 5R11, 0.125W, 1%, 1206	MC0125W120615R11
Resistor, 5K36, 0.125W, 1%, 1206, Reel	MC0125W120615K36
Resistor, 5K36, 0.125W, 1%, 1206	MC0125W120615K36
Resistor, 5M36, 0.125W, 1%, 1206, Reel	MC0125W120615M36
Resistor, 5M36, 0.125W, 1%, 1206	MC0125W120615M36
Resistor, 5R36, 0.125W, 1%, 1206, Reel	MC0125W120615R36
Resistor, 5R36, 0.125W, 1%, 1206	MC0125W120615R36
Resistor, 5K6, 0.125W, 1%, 1206, Reel	MC0125W120615K6
Resistor, 5K6, 0.125W, 1%, 1206	MC0125W120615K6
Resistor, 5M6, 0.125W, 1%, 1206, Reel	MC0125W120615M60
Resistor, 5M6, 0.125W, 1%, 1206	MC0125W120615M60
Resistor, 5R6, 0.125W, 1%, 1206, Reel	MC0125W120615R60
Resistor, 5R6, 0.125W, 1%, 1206	MC0125W120615R60
Resistor, 5K62, 0.125W, 1%, 1206, Reel	MC0125W120615K62
Resistor, 5K62, 0.125W, 1%, 1206	MC0125W120615K62
Resistor, 5R62, 0.125W, 1%, 1206, Reel	MC0125W120615R62
Resistor, 5R62, 0.125W, 1%, 1206	MC0125W120615R62
Resistor, 5K9, 0.125W, 1%, 1206, Reel	MC0125W120615K90
Resistor, 5K9, 0.125W, 1%, 1206	MC0125W120615K90
Resistor, 5R9, 0.125W, 1%, 1206, Reel	MC0125W120615R90
Resistor, 5R9, 0.125W, 1%, 1206	MC0125W120615R90
Resistor, 51K, 0.125W, 1%, 1206, Reel	MC0125W1206151K
Resistor, 51K, 0.125W, 1%, 1206	MC0125W1206151K

Description	Part Number
Resistor, 51R, 0.125W, 1%, 1206, Reel	MC0125W1206151R
Resistor, 51R, 0.125W, 1%, 1206	MC0125W1206151R
Resistor, 51K1, 0.125W, 1%, 1206, Reel	MC0125W1206151K1
Resistor, 51K1, 0.125W, 1%, 1206	MC0125W1206151K1
Resistor, 51R1, 0.125W, 1%, 1206, Reel	MC0125W1206151R1
Resistor, 51R1, 0.125W, 1%, 1206	MC0125W1206151R1
Resistor, 510K, 0.125W, 1%, 1206, Reel	MC0125W12061510K
Resistor, 510K, 0.125W, 1%, 1206	MC0125W12061510K
Resistor, 510R, 0.125W, 1%, 1206, Reel	MC0125W12061510R
Resistor, 510R, 0.125W, 1%, 1206	MC0125W12061510R
Resistor, 511K, 0.125W, 1%, 1206, Reel	MC0125W12061511K
Resistor, 511K, 0.125W, 1%, 1206	MC0125W12061511K
Resistor, 511R, 0.125W, 1%, 1206, Reel	MC0125W12061511R
Resistor, 53K6, 0.125W, 1%, 1206, Reel	MC0125W1206153K6
Resistor, 53K6, 0.125W, 1%, 1206	MC0125W1206153K6
Resistor, 53R6, 0.125W, 1%, 1206, Reel	MC0125W1206153R6
Resistor, 53R6, 0.125W, 1%, 1206	MC0125W1206153R6
Resistor, 536K, 0.125W, 1%, 1206, Reel	MC0125W12061536K
Resistor, 536K, 0.125W, 1%, 1206	MC0125W12061536K
Resistor, 536R, 0.125W, 1%, 1206, Reel	MC0125W12061536R
Resistor, 536R, 0.125W, 1%, 1206	MC0125W12061536R
Resistor, 56K, 0.125W, 1%, 1206, Reel	MC0125W1206156K
Resistor, 56K, 0.125W, 1%, 1206	MC0125W1206156K
Resistor, 56R, 0.125W, 1%, 1206, Reel	MC0125W1206156R
Resistor, 56R, 0.125W, 1%, 1206	MC0125W1206156R
Resistor, 56K2, 0.125W, 1%, 1206, Reel	MC0125W1206156K2
Resistor, 56K2, 0.125W, 1%, 1206	MC0125W1206156K2
Resistor, 56R2, 0.125W, 1%, 1206, Reel	MC0125W1206156R2
Resistor, 56R2, 0.125W, 1%, 1206	MC0125W1206156R2
Resistor, 560K, 0.125W, 1%, 1206, Reel	MC0125W12061560K
Resistor, 560K, 0.125W, 1%, 1206	MC0125W12061560K
Resistor, 560R, 0.125W, 1%, 1206, Reel	MC0125W12061560R
Resistor, 560R, 0.125W, 1%, 1206	MC0125W12061560R
Resistor, 562K, 0.125W, 1%, 1206, Reel	MC0125W12061562K
Resistor, 562K, 0.125W, 1%, 1206	MC0125W12061562K
Resistor, 562R, 0.125W, 1%, 1206, Reel	MC0125W12061562R
Resistor, 562R, 0.125W, 1%, 1206	MC0125W12061562R
Resistor, 59K, 0.125W, 1%, 1206, Reel	MC0125W1206159K0
Resistor, 59K, 0.125W, 1%, 1206	MC0125W1206159K0

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 59R, 0.125W, 1%, 1206, Reel	MC0125W1206159R0
Resistor, 59R, 0.125W, 1%, 1206	MC0125W1206159R0
Resistor, 590K, 0.125W, 1%, 1206, Reel	MC0125W12061590K
Resistor, 590K, 0.125W, 1%, 1206	MC0125W12061590K
Resistor, 590R, 0.125W, 1%, 1206, Reel	MC0125W12061590R
Resistor, 590R, 0.125W, 1%, 1206	MC0125W12061590R
Resistor, 6K04, 0.125W, 1%, 1206, Reel	MC0125W120616K04
Resistor, 6K04, 0.125W, 1%, 1206	MC0125W120616K04
Resistor, 6K19, 0.125W, 1%, 1206, Reel	MC0125W120616K19
Resistor, 6K19, 0.125W, 1%, 1206	MC0125W120616K19
Resistor, 6M19, 0.125W, 1%, 1206, Reel	MC0125W120616M19
Resistor, 6M19, 0.125W, 1%, 1206	MC0125W120616M19
Resistor, 6R19, 0.125W, 1%, 1206, Reel	MC0125W120616R19
Resistor, 6R19, 0.125W, 1%, 1206	MC0125W120616R19
Resistor, 6K2, 0.125W, 1%, 1206, Reel	MC0125W120616K2
Resistor, 6K2, 0.125W, 1%, 1206	MC0125W120616K2
Resistor, 6M2, 0.125W, 1%, 1206, Reel	MC0125W120616M20
Resistor, 6M2, 0.125W, 1%, 1206	MC0125W120616M20
Resistor, 6R2, 0.125W, 1%, 1206, Reel	MC0125W120616R20
Resistor, 6R2, 0.125W, 1%, 1206	MC0125W120616R20
Resistor, 6K49, 0.125W, 1%, 1206, Reel	MC0125W120616K49
Resistor, 6K49, 0.125W, 1%, 1206	MC0125W120616K49
Resistor, 6K8, 0.125W, 1%, 1206, Reel	MC0125W120616K8
Resistor, 6K8, 0.125W, 1%, 1206	MC0125W120616K8
Resistor, 6M8, 0.125W, 1%, 1206, Reel	MC0125W120616M80
Resistor, 6M8, 0.125W, 1%, 1206	MC0125W120616M80
Resistor, 6R8, 0.125W, 1%, 1206, Reel	MC0125W120616R80
Resistor, 6R8, 0.125W, 1%, 1206	MC0125W120616R80
Resistor, 6K81, 0.125W, 1%, 1206, Reel	MC0125W120616K81
Resistor, 6K81, 0.125W, 1%, 1206	MC0125W120616K81
Resistor, 6M81, 0.125W, 1%, 1206, Reel	MC0125W120616M81
Resistor, 6M81, 0.125W, 1%, 1206	MC0125W120616M81
Resistor, 6R81, 0.125W, 1%, 1206, Reel	MC0125W120616R81
Resistor, 6R81, 0.125W, 1%, 1206	MC0125W120616R81
Resistor, 61K9, 0.125W, 1%, 1206, Reel	MC0125W1206161K9
Resistor, 61K9, 0.125W, 1%, 1206	MC0125W1206161K9
Resistor, 61R9, 0.125W, 1%, 1206, Reel	MC0125W1206161R9
Resistor, 61R9, 0.125W, 1%, 1206	MC0125W1206161R9
Resistor, 619K, 0.125W, 1%, 1206, Reel	MC0125W12061619K

Description	Part Number
Resistor, 619K, 0.125W, 1%, 1206	MC0125W12061619K
Resistor, 619R, 0.125W, 1%, 1206, Reel	MC0125W12061619R
Resistor, 619R, 0.125W, 1%, 1206	MC0125W12061619R
Resistor, 62K, 0.125W, 1%, 1206, Reel	MC0125W1206162K
Resistor, 62K, 0.125W, 1%, 1206	MC0125W1206162K
Resistor, 62R, 0.125W, 1%, 1206, Reel	MC0125W1206162R
Resistor, 62R, 0.125W, 1%, 1206	MC0125W1206162R
Resistor, 620K, 0.125W, 1%, 1206, Reel	MC0125W12061620K
Resistor, 620K, 0.125W, 1%, 1206	MC0125W12061620K
Resistor, 620R, 0.125W, 1%, 1206, Reel	MC0125W12061620R
Resistor, 620R, 0.125W, 1%, 1206	MC0125W12061620R
Resistor, 64K9, 0.125W, 1%, 1206, Reel	MC0125W1206164K9
Resistor, 64K9, 0.125W, 1%, 1206	MC0125W1206164K9
Resistor, 64R9, 0.125W, 1%, 1206, Reel	MC0125W1206164R9
Resistor, 64R9, 0.125W, 1%, 1206	MC0125W1206164R9
Resistor, 649K, 0.125W, 1%, 1206, Reel	MC0125W12061649K
Resistor, 649K, 0.125W, 1%, 1206	MC0125W12061649K
Resistor, 649R, 0.125W, 1%, 1206, Reel	MC0125W12061649R
Resistor, 649R, 0.125W, 1%, 1206	MC0125W12061649R
Resistor, 68K, 0.125W, 1%, 1206, Reel	MC0125W1206168K
Resistor, 68K, 0.125W, 1%, 1206	MC0125W1206168K
Resistor, 68R, 0.125W, 1%, 1206, Reel	MC0125W1206168R
Resistor, 68R, 0.125W, 1%, 1206	MC0125W1206168R
Resistor, 68K1, 0.125W, 1%, 1206, Reel	MC0125W1206168K1
Resistor, 68K1, 0.125W, 1%, 1206	MC0125W1206168K1
Resistor, 68R1, 0.125W, 1%, 1206, Reel	MC0125W1206168R1
Resistor, 68R1, 0.125W, 1%, 1206	MC0125W1206168R1
Resistor, 680K, 0.125W, 1%, 1206, Reel	MC0125W12061680K
Resistor, 680K, 0.125W, 1%, 1206	MC0125W12061680K
Resistor, 680R, 0.125W, 1%, 1206, Reel	MC0125W12061680R
Resistor, 680R, 0.125W, 1%, 1206	MC0125W12061680R
Resistor, 681K, 0.125W, 1%, 1206, Reel	MC0125W12061681K
Resistor, 681K, 0.125W, 1%, 1206	MC0125W12061681K
Resistor, 681R, 0.125W, 1%, 1206, Reel	MC0125W12061681R
Resistor, 681R, 0.125W, 1%, 1206	MC0125W12061681R
Resistor, 7K15, 0.125W, 1%, 1206, Reel	MC0125W120617K15
Resistor, 7K15, 0.125W, 1%, 1206	MC0125W120617K15
Resistor, 7R15, 0.125W, 1%, 1206, Reel	MC0125W120617R15
Resistor, 7R15, 0.125W, 1%, 1206	MC0125W120617R15

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 7K5, 0.125W, 1%, 1206, Reel	MC0125W120617K5
Resistor, 7K5, 0.125W, 1%, 1206	MC0125W120617K5
Resistor, 7M5, 0.125W, 1%, 1206, Reel	MC0125W120617M50
Resistor, 7M5, 0.125W, 1%, 1206	MC0125W120617M50
Resistor, 7R5, 0.125W, 1%, 1206, Reel	MC0125W120617R50
Resistor, 7R5, 0.125W, 1%, 1206	MC0125W120617R50
Resistor, 7K87, 0.125W, 1%, 1206, Reel	MC0125W120617K87
Resistor, 7K87, 0.125W, 1%, 1206	MC0125W120617K87
Resistor, 7R87, 0.125W, 1%, 1206, Reel	MC0125W120617R87
Resistor, 7R87, 0.125W, 1%, 1206	MC0125W120617R87
Resistor, 71K5, 0.125W, 1%, 1206, Reel	MC0125W1206171K5
Resistor, 71K5, 0.125W, 1%, 1206	MC0125W1206171K5
Resistor, 71R5, 0.125W, 1%, 1206, Reel	MC0125W1206171R5
Resistor, 71R5, 0.125W, 1%, 1206	MC0125W1206171R5
Resistor, 715K, 0.125W, 1%, 1206, Reel	MC0125W12061715K
Resistor, 715K, 0.125W, 1%, 1206	MC0125W12061715K
Resistor, 715R, 0.125W, 1%, 1206, Reel	MC0125W12061715R
Resistor, 715R, 0.125W, 1%, 1206	MC0125W12061715R
Resistor, 75K, 0.125W, 1%, 1206, Reel	MC0125W1206175K
Resistor, 75K, 0.125W, 1%, 1206	MC0125W1206175K
Resistor, 75R, 0.125W, 1%, 1206, Reel	MC0125W1206175R
Resistor, 75R, 0.125W, 1%, 1206	MC0125W1206175R
Resistor, 750K, 0.125W, 1%, 1206, Reel	MC0125W12061750K
Resistor, 750K, 0.125W, 1%, 1206	MC0125W12061750K
Resistor, 750R, 0.125W, 1%, 1206, Reel	MC0125W12061750R
Resistor, 750R, 0.125W, 1%, 1206	MC0125W12061750R
Resistor, 78K7, 0.125W, 1%, 1206, Reel	MC0125W1206178K7
Resistor, 78K7, 0.125W, 1%, 1206	MC0125W1206178K7
Resistor, 78R7, 0.125W, 1%, 1206, Reel	MC0125W1206178R7
Resistor, 78R7, 0.125W, 1%, 1206	MC0125W1206178R7
Resistor, 787K, 0.125W, 1%, 1206, Reel	MC0125W12061787K
Resistor, 787K, 0.125W, 1%, 1206	MC0125W12061787K
Resistor, 787R, 0.125W, 1%, 1206, Reel	MC0125W12061787R
Resistor, 787R, 0.125W, 1%, 1206	MC0125W12061787R
Resistor, 8K2, 0.125W, 1%, 1206, Reel	MC0125W120618K2
Resistor, 8K2, 0.125W, 1%, 1206	MC0125W120618K2
Resistor, 8M2, 0.125W, 1%, 1206, Reel	MC0125W120618M20
Resistor, 8M2, 0.125W, 1%, 1206	MC0125W120618M20
Resistor, 8R2, 0.125W, 1%, 1206, Reel	MC0125W120618R20

Description	Part Number
Resistor, 8R2, 0.125W, 1%, 1206	MC0125W120618R20
Resistor, 8K25, 0.125W, 1%, 1206, Reel	MC0125W120618K25
Resistor, 8K25, 0.125W, 1%, 1206	MC0125W120618K25
Resistor, 8R25, 0.125W, 1%, 1206, Reel	MC0125W120618R25
Resistor, 8R25, 0.125W, 1%, 1206	MC0125W120618R25
Resistor, 8K66, 0.125W, 1%, 1206, Reel	MC0125W120618K66
Resistor, 8K66, 0.125W, 1%, 1206	MC0125W120618K66
Resistor, 8R66, 0.125W, 1%, 1206, Reel	MC0125W120618R66
Resistor, 8R66, 0.125W, 1%, 1206	MC0125W120618R66
Resistor, 82K, 0.125W, 1%, 1206, Reel	MC0125W1206182K
Resistor, 82K, 0.125W, 1%, 1206	MC0125W1206182K
Resistor, 82R, 0.125W, 1%, 1206, Reel	MC0125W1206182R
Resistor, 82R, 0.125W, 1%, 1206	MC0125W1206182R
Resistor, 82K5, 0.125W, 1%, 1206, Reel	MC0125W1206182K5
Resistor, 82K5, 0.125W, 1%, 1206	MC0125W1206182K5
Resistor, 82R5, 0.125W, 1%, 1206, Reel	MC0125W1206182R5
Resistor, 82R5, 0.125W, 1%, 1206	MC0125W1206182R5
Resistor, 820K, 0.125W, 1%, 1206, Reel	MC0125W12061820K
Resistor, 820K, 0.125W, 1%, 1206	MC0125W12061820K
Resistor, 820R, 0.125W, 1%, 1206, Reel	MC0125W12061820R
Resistor, 820R, 0.125W, 1%, 1206	MC0125W12061820R
Resistor, 825K, 0.125W, 1%, 1206, Reel	MC0125W12061825K
Resistor, 825K, 0.125W, 1%, 1206	MC0125W12061825K
Resistor, 825R, 0.125W, 1%, 1206, Reel	MC0125W12061825R
Resistor, 825R, 0.125W, 1%, 1206	MC0125W12061825R
Resistor, 86K6, 0.125W, 1%, 1206, Reel	MC0125W1206186K6
Resistor, 86K6, 0.125W, 1%, 1206	MC0125W1206186K6
Resistor, 86R6, 0.125W, 1%, 1206, Reel	MC0125W1206186R6
Resistor, 86R6, 0.125W, 1%, 1206	MC0125W1206186R6
Resistor, 866K, 0.125W, 1%, 1206, Reel	MC0125W12061866K
Resistor, 866K, 0.125W, 1%, 1206	MC0125W12061866K
Resistor, 866R, 0.125W, 1%, 1206, Reel	MC0125W12061866R
Resistor, 866R, 0.125W, 1%, 1206	MC0125W12061866R
Resistor, 9K09, 0.125W, 1%, 1206, Reel	MC0125W120619K09
Resistor, 9K09, 0.125W, 1%, 1206	MC0125W120619K09
Resistor, 9K1, 0.125W, 1%, 1206, Reel	MC0125W120619K1
Resistor, 9K1, 0.125W, 1%, 1206	MC0125W120619K1
Resistor, 9M1, 0.125W, 1%, 1206, Reel	MC0125W120619M10
Resistor, 9M1, 0.125W, 1%, 1206	MC0125W120619M10

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO

Thick Film Chip Resistors 1206

multicomp PRO

Description	Part Number
Resistor, 9R1, 0.125W, 1%, 1206, Reel	MC0125W120619R10
Resistor, 9R1, 0.125W, 1%, 1206	MC0125W120619R10
Resistor, 9K53, 0.125W, 1%, 1206, Reel	MC0125W120619K53
Resistor, 9K53, 0.125W, 1%, 1206	MC0125W120619K53
Resistor, 9R53, 0.125W, 1%, 1206, Reel	MC0125W120619R53
Resistor, 9R53, 0.125W, 1%, 1206	MC0125W120619R53
Resistor, 90K9, 0.125W, 1%, 1206, Reel	MC0125W1206190K9
Resistor, 90K9, 0.125W, 1%, 1206	MC0125W1206190K9
Resistor, 90R9, 0.125W, 1%, 1206, Reel	MC0125W1206190R9
Resistor, 90R9, 0.125W, 1%, 1206	MC0125W1206190R9
Resistor, 909K, 0.125W, 1%, 1206, Reel	MC0125W12061909K
Resistor, 909K, 0.125W, 1%, 1206	MC0125W12061909K
Resistor, 909R, 0.125W, 1%, 1206, Reel	MC0125W12061909R
Resistor, 909R, 0.125W, 1%, 1206	MC0125W12061909R
Resistor, 91K, 0.125W, 1%, 1206, Reel	MC0125W1206191K

Description	Part Number
Resistor, 91K, 0.125W, 1%, 1206	MC0125W1206191K
Resistor, 91R, 0.125W, 1%, 1206, Reel	MC0125W1206191R
Resistor, 91R, 0.125W, 1%, 1206	MC0125W1206191R
Resistor, 910K, 0.125W, 1%, 1206, Reel	MC0125W12061910K
Resistor, 910K, 0.125W, 1%, 1206	MC0125W12061910K
Resistor, 910R, 0.125W, 1%, 1206, Reel	MC0125W12061910R
Resistor, 910R, 0.125W, 1%, 1206	MC0125W12061910R
Resistor, 95K3, 0.125W, 1%, 1206, Reel	MC0125W1206195K3
Resistor, 95K3, 0.125W, 1%, 1206	MC0125W1206195K3
Resistor, 95R3, 0.125W, 1%, 1206, Reel	MC0125W1206195R3
Resistor, 95R3, 0.125W, 1%, 1206	MC0125W1206195R3
Resistor, 953K, 0.125W, 1%, 1206, Reel	MC0125W12061953K
Resistor, 953K, 0.125W, 1%, 1206	MC0125W12061953K
Resistor, 953R, 0.125W, 1%, 1206, Reel	MC0125W12061953R
Resistor, 953R, 0.125W, 1%, 1206	MC0125W12061953R

Important Notice : This data sheet and its contents (the "Information") belong to the members of the AVNET group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. Multicomp Pro is the registered trademark of Premier Farnell Limited 2019.

Newark.com/multicomp-pro
Farnell.com/multicomp-pro
Element14.com/multicomp-pro

multicomp PRO